



45°エルボ (45° L)

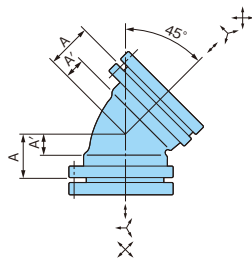

単位：mm

呼 び	端面～中心		管つき当たり部 ～中心
	A	A'	
1 1/4	33	15	
1 1/2	36	17	
2	42	20	
2 1/2	50	25	
3	56	28	
4	68	35	
5	79	43	
6	89	50	
8	106	58	


15°エルボ (15° L)

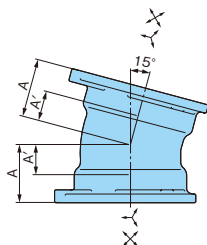

単位：mm

呼 び	端面～中心		管つき当たり部 ～中心
	A	A'	
3	56	28	
4	68	35	
5	79	43	
6	89	50	
8	106	58	

90° Y (ST)

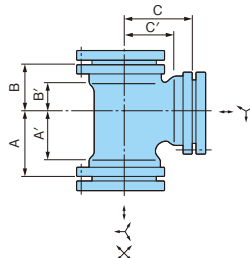

単位：mm

呼 び	端面～中心			管つき当たり部 ～中心		
	A	B	C	A'	B'	C'
1 1/4	57	40	56	39	22	38
1 1/2	63	44	62	44	25	43
1 1/2 x 1 1/4	58	41	59	39	22	41
2	76	53	75	54	31	53
2 x 1 1/4	61	45	65	39	23	47
2 x 1 1/2	66	48	68	44	26	49
2 1/2	92	64	91	67	39	66
2 1/2 x 1 1/2	69	51	75	44	26	56
2 1/2 x 2	79	57	83	54	32	61
3	106	74	104	78	46	76
3 x 1 1/4	70	52	82	42	24	64
3 x 1 1/2	72	55	82	44	27	63
3 x 2	82	60	89	54	32	67
3 x 2 1/2	95	68	98	67	40	73
4	132	92	130	99	59	97
4 x 1 1/2	77	61	94	44	28	75
4 x 2	87	66	101	54	33	79
4 x 2 1/2	100	74	110	67	41	85
4 x 3	111	80	116	78	47	88
5	158	110	155	122	74	119
5 x 1 1/2	80	63	107	44	27	88
5 x 2	90	70	114	54	34	92
5 x 2 1/2	103	78	123	67	42	98
5 x 3	114	84	129	78	48	101
5 x 4	135	96	143	99	60	110
6	182	125	179	143	86	140
6 x 2	93	74	126	54	35	104
6 x 3	117	88	141	78	49	113
6 x 4	138	101	155	99	62	122
6 x 5	161	115	167	122	76	131
8 x 4	147	112	182	99	64	149