



ねじれ半月ドリル 超硬  
Spiral Gun Barrel Drill Carbide

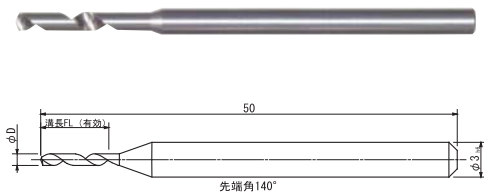

ねじれ半月ドリル 超硬 DLCコーティング  
Spiral Gun Barrel Drill Carbide DLC coating

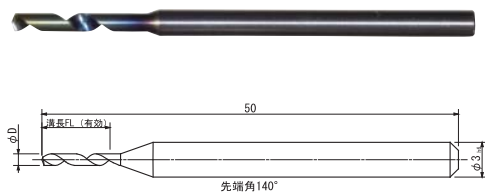

超硬 シャープ 1枚刃 右刃 140°

超硬 DLC シャープ 1枚刃 右刃 140°

VAN Code No.	単位/寸法:mm 価格:円 Unit/Size:mm Price:JPY			
	直径φD	有効溝長FL	在庫 Stock	参考価格 Price
SHD0.1CB	0.1	0.6	●	¥6,000
SHD0.11CB	0.11	0.6	●	¥6,000
SHD0.12CB	0.12	0.7	●	¥6,000
SHD0.13CB	0.13	0.7	●	¥6,000
SHD0.14CB	0.14	0.7	●	¥6,000
SHD0.15CB	0.15	0.9	●	¥5,500
SHD0.16CB	0.16	0.9	●	¥5,500
SHD0.17CB	0.17	1	●	¥5,500
SHD0.18CB	0.18	1	●	¥5,500
SHD0.19CB	0.19	1	●	¥5,500
SHD0.2CB	0.2	1.2	●	¥5,000
SHD0.21CB	0.21	1.2	●	¥5,000
SHD0.22CB	0.22	1.2	●	¥5,000
SHD0.23CB	0.23	1.2	●	¥5,000
SHD0.24CB	0.24	1.2	●	¥5,000
SHD0.25CB	0.25	1.5	●	¥5,000
SHD0.26CB	0.26	1.5	●	¥5,000
SHD0.27CB	0.27	1.5	●	¥5,000
SHD0.28CB	0.28	1.5	●	¥5,000
SHD0.29CB	0.29	1.5	●	¥5,000
SHD0.3CB	0.3	1.8	●	¥4,000
SHD0.31CB	0.31	1.8	□	
SHD0.32CB	0.32	1.8	□	
SHD0.33CB	0.33	1.8	□	
SHD0.34CB	0.34	1.8	□	
SHD0.35CB	0.35	2.1	●	¥4,000
SHD0.36CB	0.36	2.1	□	
SHD0.37CB	0.37	2.1	□	
SHD0.38CB	0.38	2.1	□	
SHD0.39CB	0.39	2.1	□	
SHD0.4CB	0.4	2.4	●	¥4,000
SHD0.41CB	0.41	2.4	□	
SHD0.42CB	0.42	2.4	□	

VAN Code No.	単位/寸法:mm 価格:円 Unit/Size:mm Price:JPY			
	直径φD	有効溝長FL	在庫 Stock	参考価格 Price
SHD0.43CB	0.43	2.4	□	
SHD0.44CB	0.44	2.4	□	
SHD0.45CB	0.45	2.7	●	¥4,000
SHD0.46CB	0.46	2.7	□	
SHD0.47CB	0.47	2.7	□	
SHD0.48CB	0.48	2.7	□	
SHD0.49CB	0.49	2.7	□	
SHD0.5CB	0.5	3	●	¥4,000
SHD0.6CB	0.6	3.6	●	¥4,000
SHD0.7CB	0.7	4.2	●	¥4,000
SHD0.8CB	0.8	4.8	●	¥4,000
SHD0.9CB	0.9	5.4	●	¥4,000
SHD1.0CB	1	6	●	¥4,000
SHD1.1CB	1.1	6.6	●	¥4,000
SHD1.2CB	1.2	7.2	●	¥4,000
SHD1.3CB	1.3	7.8	●	¥4,000
SHD1.4CB	1.4	8.4	●	¥4,000
SHD1.5CB	1.5	9	●	¥4,000
SHD1.6CB	1.6	9.6	●	¥4,000
SHD1.7CB	1.7	10.2	●	¥4,000
SHD1.8CB	1.8	10.8	●	¥4,000
SHD1.9CB	1.9	11.4	●	¥4,000
SHD2.0CB	2	12	●	¥4,000
SHD2.1CB	2.1	12	●	¥4,000
SHD2.2CB	2.2	13.2	●	¥4,000
SHD2.3CB	2.3	13.2	●	¥4,000
SHD2.4CB	2.4	14.4	●	¥4,000
SHD2.5CB	2.5	14.4	●	¥4,000
SHD2.6CB	2.6	15.6	●	¥4,000
SHD2.7CB	2.7	15.6	●	¥4,000
SHD2.8CB	2.8	16.8	●	¥4,000
SHD2.9CB	2.9	16.8	●	¥4,000
SHD3.0CB	3	16.8	●	¥4,000

VAN Code No.	単位/寸法:mm 価格:円 Unit/Size:mm Price:JPY			
	直径φD	有効溝長FL	在庫 Stock	参考価格 Price
SHD0.1CBDLC	0.1	0.6	●	¥10,667
SHD0.11CBDLC	0.11	0.6	●	¥10,667
SHD0.12CBDLC	0.12	0.7	●	¥10,500
SHD0.13CBDLC	0.13	0.7	●	¥10,500
SHD0.14CBDLC	0.14	0.7	●	¥10,500
SHD0.15CBDLC	0.15	0.9	●	¥9,667
SHD0.16CBDLC	0.16	0.9	●	¥9,667
SHD0.17CBDLC	0.17	1	●	¥9,667
SHD0.18CBDLC	0.18	1	●	¥9,667
SHD0.19CBDLC	0.19	1	●	¥9,667
SHD0.2CBDLC	0.2	1.2	●	¥8,667
SHD0.21CBDLC	0.21	1.2	●	¥8,667
SHD0.22CBDLC	0.22	1.2	●	¥8,667
SHD0.23CBDLC	0.23	1.2	●	¥8,667
SHD0.24CBDLC	0.24	1.2	●	¥8,667
SHD0.25CBDLC	0.25	1.5	●	¥8,500
SHD0.26CBDLC	0.26	1.5	●	¥8,500
SHD0.27CBDLC	0.27	1.5	●	¥8,500
SHD0.28CBDLC	0.28	1.5	●	¥8,500
SHD0.29CBDLC	0.29	1.5	●	¥8,500
SHD0.3CBDLC	0.3	1.8	●	¥7,333
SHD0.31CBDLC	0.31	1.8	□	
SHD0.32CBDLC	0.32	1.8	□	
SHD0.33CBDLC	0.33	1.8	□	
SHD0.34CBDLC	0.34	1.8	□	
SHD0.35CBDLC	0.35	2.1	●	¥7,333
SHD0.36CBDLC	0.36	2.1	□	
SHD0.37CBDLC	0.37	2.1	□	
SHD0.38CBDLC	0.38	2.1	□	
SHD0.39CBDLC	0.39	2.1	□	
SHD0.4CBDLC	0.4	2.4	●	¥7,333
SHD0.41CBDLC	0.41	2.4	□	
SHD0.42CBDLC	0.42	2.4	□	

VAN Code No.	単位/寸法:mm 価格:円 Unit/Size:mm Price:JPY			
	直径φD	有効溝長FL	在庫 Stock	参考価格 Price
SHD0.43CBDLC	0.43	2.4	□	
SHD0.44CBDLC	0.44	2.4	□	
SHD0.45CBDLC	0.45	2.7	●	¥7,333
SHD0.46CBDLC	0.46	2.7	□	
SHD0.47CBDLC	0.47	2.7	□	
SHD0.48CBDLC	0.48	2.7	□	
SHD0.49CBDLC	0.49	2.7	□	
SHD0.5CBDLC	0.5	3	●	¥7,000
SHD0.6CBDLC	0.6	3.6	●	¥7,000
SHD0.7CBDLC	0.7	4.2	●	¥7,000
SHD0.8CBDLC	0.8	4.8	●	¥7,000
SHD0.9CBDLC	0.9	5.4	●	¥7,000
SHD1.0CBDLC	1	6	●	¥7,000
SHD1.1CBDLC	1.1	6.6	●	¥7,000
SHD1.2CBDLC	1.2	7.2	●	¥7,000
SHD1.3CBDLC	1.3	7.8	●	¥7,000
SHD1.4CBDLC	1.4	8.4	●	¥7,000
SHD1.5CBDLC	1.5	9	●	¥7,000
SHD1.6CBDLC	1.6	9.6	●	¥7,000
SHD1.7CBDLC	1.7	10.2	●	¥7,000
SHD1.8CBDLC	1.8	10.8	●	¥7,000
SHD1.9CBDLC	1.9	11.4	●	¥7,000
SHD2.0CBDLC	2	12	●	¥7,000
SHD2.1CBDLC	2.1	12	●	¥7,000
SHD2.2CBDLC	2.2	13.2	●	¥7,000
SHD2.3CBDLC	2.3	13.2	●	¥7,000
SHD2.4CBDLC	2.4	14.4	●	¥7,000
SHD2.5CBDLC	2.5	14.4	●	¥7,000
SHD2.6CBDLC	2.6	15.6	●	¥7,000
SHD2.7CBDLC	2.7	15.6	●	¥7,000
SHD2.8CBDLC	2.8	16.8	●	¥7,000
SHD2.9CBDLC	2.9	16.8	●	¥7,000
SHD3.0CBDLC	3	16.8	●	¥7,000

Stock ●...標準在庫品 / Stocked  
Stock □...特定商社在庫品 / Stocked by Specific Distributors

被削材適合性

Suitability for Work Materials

◎...最適 The most suitable ○...適 Suitable △...可 Possible 無印...不可 Impossible

製品区分 Product	軟鋼 Mild Steel	炭素鋼 Carbon Steel	合金鋼 Alloy Steel	調質鋼 Hardened Steel	工具鋼 Tool Steel	焼入れ鋼 Quenched & Tempered Steel	ステンレス鋼 Stainless Steel	鑄鉄 Cast Iron	タタリ鉄 Ductile Cast Iron	チタン合金 Titanium Alloy	アルミ合金 Aluminium Alloy	銅 Copper	プラスチック Plastic	セラミック etc. Ceramics etc.	
	SS	S45C	SCM SCR	SKD SKS	~40 HRC	~45 HRC	45~ HRC	SUS	FC	FDC	Al	Cu		マシナブル Machinable	ジルコニア ガラス Zirconia Glass
SHD-CB	◎	○	△		△						○	○	◎	◎	
SHD-CBDLC											○	◎	◎	◎	

SP CENTER

CENTER DRILL

GP DRILL

TFD

SPIRAL GUN BARREL DRILL

TOGLON SHARP SP

TOGLON HARD

CORNER ROUNDING CUTTER

JIT

SUBMARINE GATE DRILL

MICRO TOOL

TECHNICAL INFORMATION

CUSTOMIZED TOOL SEMIORDER TOOL

INSTRUCTION

COMPANY PROFILE