



■オープンピンヘッダ ストレートスルーホールタイプ

単位：mm


●1列型：PS-※PE-S4T1-PN1

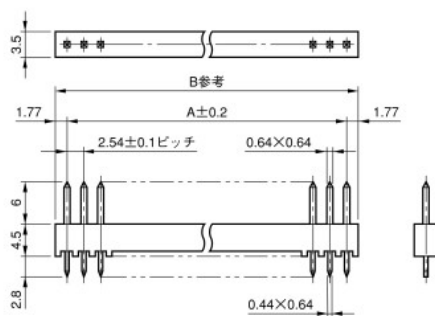


基板取付穴寸法(参考)

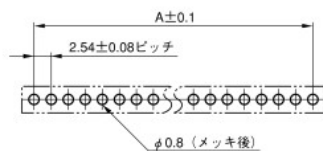

●2列型：PS-※PE-D4T1-PN1

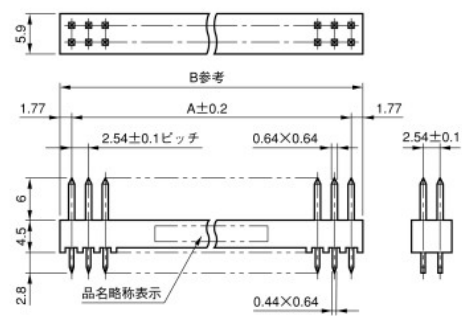

基板取付穴寸法(参考)

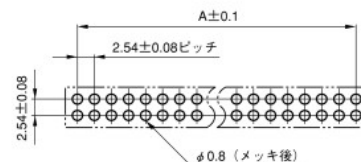

■品名／寸法

極数		品 名		A	B
1列	2列	1列型	2列型		
5	10	PS-5PE-S4T1-PN1	PS-10PE-D4T1-PN1	10.16	13.70
—	16	—	PS-16PE-D4T1-PN1	17.78	21.32
10	20	PS-10PE-S4T1-PN1	PS-20PE-D4T1-PN1	22.86	26.40
—	26	—	PS-26PE-D4T1-PN1	30.48	34.02
15	30	PS-15PE-S4T1-PN1	PS-30PE-D4T1-PN1	35.56	39.10
—	34	—	PS-34PE-D4T1-PN1	40.64	44.18
20	40	PS-20PE-S4T1-PN1	PS-40PE-D4T1-PN1	48.26	51.80
—	50	—	PS-50PE-D4T1-PN1	60.96	64.50
—	60	—	PS-60PE-D4T1-PN1	73.66	77.20