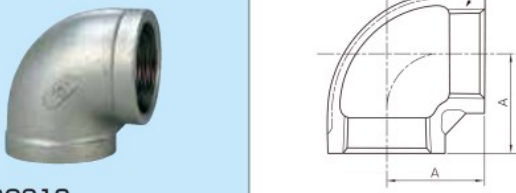
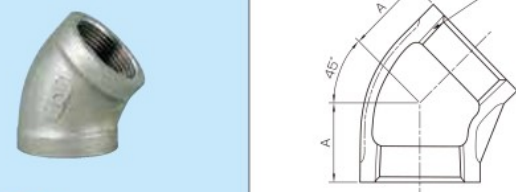
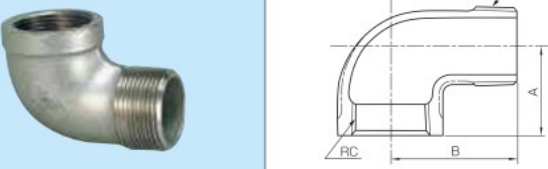
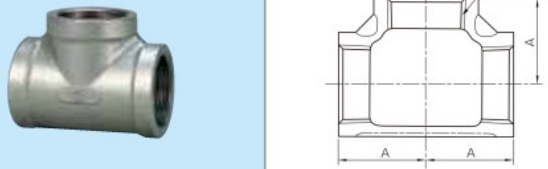


種類



エルボ	1/8 1/4	(略号: L)					
		材質: SCS13		呼び(B)	A	呼び(B)	A
				1/8	17	1 1/4	46
				1/4	19	1 1/2	48
				3/8	23	2	57
				1/2	28	2 1/2	69
				3/4	32	3	78
				1	38	4	97

45°エルボ	1/8 1/4	(略号: 45°L)					
		材質: SCS13		呼び(B)	A	呼び(B)	A
				1/8	18	1 1/4	34
				1/4	18	1 1/2	37
				3/8	19	2	43
				1/2	22	2 1/2	49
				3/4	25	3	55
				1	29	4	65

ストリートエルボ	1/8 1/2	(略号: SL)							
		材質: SCS13		呼び(B)	A	B	呼び(B)	A	B
				1/8	18	27	1	38	54
				1/4	19	30	1 1/4	46	64
				3/8	23	35	1 1/2	50	70
				1/2	29	40	2	57	85
				3/4	32	49			

チー	1/8 1/4	(略号: T)					
		材質: SCS13		呼び(B)	A	呼び(B)	A
				1/8	17	1 1/4	46
				1/4	19	1 1/2	48
				3/8	23	2	57
				1/2	29	2 1/2	69
				3/4	33	3	78
				1	38	4	97

ソケット(テーパ)	1/8 1/4	(略号: S)							
		材質: SCS13 又は SUS304		呼び(B)	D	A	呼び(B)	D	A
				1/8	14	25	1 1/4	54.6	51
				1/4	19	30	1 1/2	61.7	54
				3/8	22	30	2	75.2	64
				1/2	30	38	2 1/2	90	73
				3/4	37	40	3	106	81
				1	45	46	4	132	94

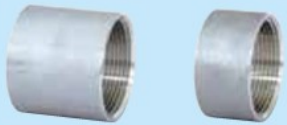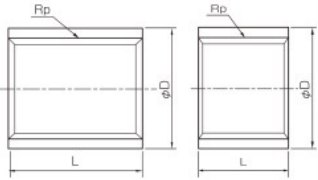ストレートソケット ストレートハーフソケット	1/8 1/4			ストレート ソケット	呼び(B)	D	L	Rp	呼び(B)	D	L	Rp
					1/8	14	20	Rp 1/8	1 1/4	47	48	Rp 1 1/4
					1/4	17	25	Rp 1/4	1 1/2	53	48	Rp 1 1/2
					3/8	21	26	Rp 3/8	2	66	56	Rp 2
					1/2	25	33	Rp 1/2	2 1/2	82	65	Rp 2 1/2
					3/4	31	36	Rp 3/4	3	95	70	Rp 3
					1	38	43	Rp 1	4	121	84	Rp 4
				ストレート ハーフソケット	呼び(B)	D	L	Rp	呼び(B)	D	L	Rp
					1/8	14	12	Rp 1/8	1 1/4	47	28	Rp 1 1/4
					1/4	17	15	Rp 1/4	1 1/2	53	28	Rp 1 1/2
					3/8	21	16	Rp 3/8	2	66	34	Rp 2
					1/2	25	20	Rp 1/2	2 1/2	82	39	Rp 2 1/2
					3/4	31	21	Rp 3/4	3	95	42	Rp 3
					1	38	25	Rp 1	4	121	50	Rp 4