


スラスト自動調心ころ軸受

d 60 ~ 160 mm

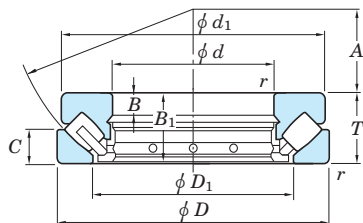

d	主要寸法 (mm)			基本定格荷重 (kN)		疲労限荷重 (kN)	許容回転速度 (min^{-1})	呼び番号	
	D	T	r (最小)	C_a	C_{0a}	C_u	油潤滑		
60	130	42	1.5	399	884	73.7	2 700	29412R	
65	140	45	2	450	1 020	73.4	2 500	29413R	
70	150	48	2	485	1 100	105	2 300	29414R	
75	160	51	2	584	1 360	102	2 100	29415R	
80	170	54	2.1	631	1 480	128	2 000	29416R	
	180	58	2.1	714	1 700	124	1 900	29317R 29417R	
90	155	39	1.5	412	1 050	103	2 500	29318R	
	190	60	2.1	821	2 010	158	1 800	29418R	
100	170	42	1.5	481	1 270	118	2 300	29320R	
	210	67	3	911	2 220	166	1 650	29420R	
110	190	48	2	628	1 690	147	2 000	29322R	
	230	73	3	1 120	2 810	203	1 500	29422R	
120	210	54	2.1	759	2 030	182	1 800	29324R	
	250	78	4	1 300	3 270	241	1 350	29424R	
130	225	58	2.1	894	2 440	209	1 700	29326R	
	270	85	4	1 490	3 870	270	1 250	29426R	
140	240	60	2.1	898	2 490	206	1 600	29328R	
	280	85	4	1 560	4 080	289	1 250	29428R	
150	250	60	2.1	965	2 740	233	1 550	29330R	
	300	90	4	1 730	4 620	334	1 100	29430R	
160	270	67	3	1 150	3 070	272	1 400	29332R	
	320	95	5	1 990	5 370	375	1 050	29432R	