


## スリーブ (Hyper型)

シャンク径φ16 ~ 25.4

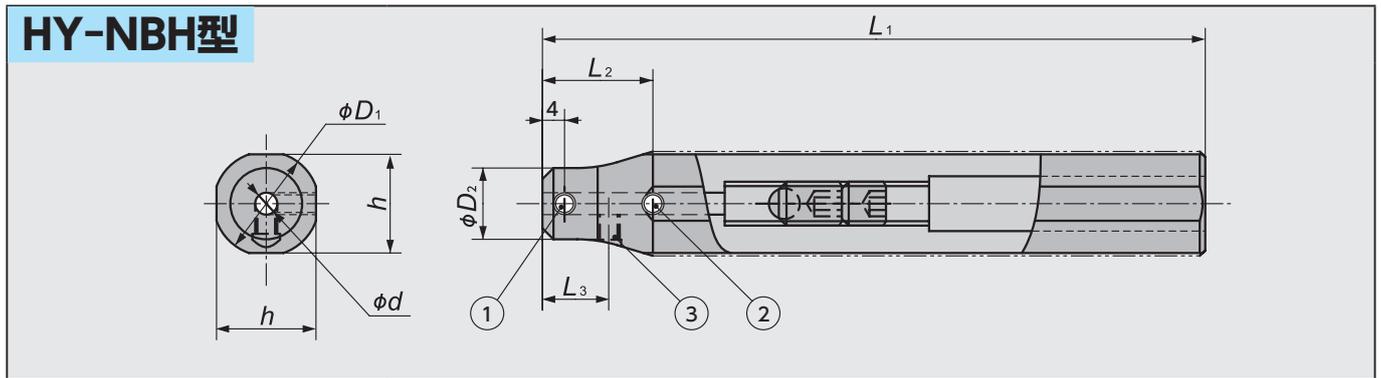

### ホルダ寸法

コードNo.	ホルダ品番	在庫	寸法(mm)							クランプスクリュ		
			φd	φD1	φD2	h	L1	L2	L3	①	②	③
5709894	HY-NBH02016H	●	2.0	16	11	15	100	15	9.5	SS04045FS	SS0406F	SS0404F
5709902	02516H	●	2.5		11.5							
5709910	03016H	●	3.0		12							
5709936	03516H	●	3.5		12.5							
5709944	04016H	●	4.0		13							
5709951	05016H	●	5.0		14							
5709969	HY-NBH02019K	●	2.0	19.05	11	18	125	15	9.5	SS04045FS	SS0406F	SS0404F
5709977	02519K	●	2.5		11.5							
5709985	03019K	●	3.0		12							
5709993	03519K	●	3.5		12.5							
5710009	04019K	●	4.0		13							
5710017	05019K	●	5.0		14							
5712708	HY-NBH02020K	●	2.0	20	11	19	125	15	9.5	SS04045FS	SS0406F	SS0404F
5712716	02520K	●	2.5		11.5							
5712724	03020K	●	3.0		12							
5712740	03520K	●	3.5		12.5							
5712757	04020K	●	4.0		13							
5712765	05020K	●	5.0		14							
5712773	HY-NBH02022K	●	2.0	22	11	21	125	15	9.5	SS04045FS	SS0406F	SS0404F
5712799	02522K	●	2.5		11.5							
5712831	03022K	●	3.0		12							
5712856	03522K	●	3.5		12.5							
5712872	04022K	●	4.0		13							
5712914	05022K	●	5.0		14							
5712732	HY-NBH02025K-MET	●	2.0	25	11	24	125	15	9.5	SS04045FS	SS0406F	SS0404F
5712823	02525K-MET	●	2.5		11.5							
5712849	03025K-MET	●	3.0		12							
5712864	03525K-MET	●	3.5		12.5							
5712898	04025K-MET	●	4.0		13							
5712922	05025K-MET	●	5.0		14							
5713003	HY-NBH02025K	●	2.0	25.4	11	24	125	15	9.5	SS04045FS	SS0406F	SS0404F
5713029	02525K	●	2.5		11.5							
5713045	03025K	●	3.0		12							
5713060	03525K	●	3.5		12.5							
5713086	04025K	●	4.0		13							
5713102	05025K	●	5.0		14							

### 部品

品名	品番	六角穴の二面幅
全長位置決め用ボールスクリュ	SS0812R	4.0
ボールスクリュ固定用スクリュ	SS0808F	4.0
クランプスクリュ用レンチ	LW-2	—

- A 新製品
- B 工具材種・選択ガイド
- C 加工ミニ
- D 超微粒子硬
- E 在庫一覧
- F 外径
- G Sスライド小部品型
- H 溝入れ
- I ねじ切り
- J シェーパ
- K 内径
- L オリジナルツール
- M エンドミル
- N 各種ドリル
- O フライスカッタ
- P 技術資料
- Q 索引