


BN

ニップル

RoHS対応品

部品番号	適用チューブ 外径×内径 (mm)	T (R・M)	φd (mm)	L ₁ (mm)	L ₂ (mm)	S 六角対辺 (mm)	重量 (g)	有効断面積 (mm ²)
BN-4×2.5-M5-BSN	4×2.5	M5	1.4	18.0	8	8	3	1.0
BN-4×2.5-PT1/8-BSN	4×2.5	1/8	1.5	21.0	8	10	6	1.3
BN-6×4-M5-BSN	6×4	M5	2.2	18.0	8	8	4	3.3
BN-6×4-PT1/8-BSN	6×4	1/8	3.0	21.0	8	10	6	5.0
BN-6×4-PT1/4-BSN	6×4	1/4	3.0	24.5	8	14	15	6.7

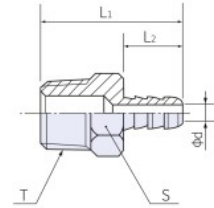


BL

エルボ

RoHS対応品

部品番号	適用チューブ 外径×内径 (mm)	T (R・M)	φd (mm)	L ₁ (mm)	L ₂ (mm)	S 六角対辺 (mm)	重量 (g)	有効断面積 (mm ²)
BL-4×2.5-M5-BSN	4×2.5	M5	1.4	12.9	15.0	10	10	1.1
BL-4×2.5-PT1/8-BSN	4×2.5	1/8	1.4	12.9	18.0	10	11	1.2
BL-6×4-M5-BSN	6×4	M5	2.9	12.9	15.0	10	10	3.3
BL-6×4-PT1/8-BSN	6×4	1/8	2.9	12.9	18.0	10	12	4.2
BL-6×4-PT1/4-BSN	6×4	1/4	2.9	12.9	21.5	14	20	4.0

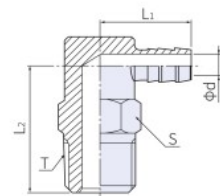

BLD

二連エルボ

RoHS対応品

部品番号	適用チューブ 外径×内径 (mm)	T (R)	φd (mm)	L ₁ (mm)	L ₂ (mm)	L ₃ (mm)	S 六角対辺 (mm)	重量 (g)	有効断面積 (mm ²)
BLD-4×2.5-2-PT1/8-BSN	4×2.5	1/8	1.4	12.9	10	18	10	16.0	1.6
BLD-6×4-2-PT1/8-BSN	6×4	1/8	2.9	12.9	10	18	10	18.5	4.9

