


## ARカフス

材質：EPDM(黒)

単位：mm

型番	呼称	A	B	C	D	E	F	L
CFS-AR-038	38	43.0	38.0	40.5	52.5	30	9.5	75
CFS-AR-050	50	56.0	51.0	53.6	66.3	23	10.0	81
CFS-AR-065	65	69.0	63.0	65.4	78.1	31	12.0	87
CFS-AR-075	75	84.0	77.0	79.8	92.5	38	13.0	98
CFS-AR-090	90	97.0	89.0	92.3	105.8	46	13.5	107
CFS-AR-100	100	110.0	102.0	105.0	118.3	43	15.0	111
CFS-AR-125	125	134.0	126.0	129.3	144.8	52	21.0	146
CFS-AR-150	150	161.0	153.0	155.8	172.3	78	20.0	162
CFS-AR-200	200	214.0	204.0	207.1	223.6	112	22.5	235

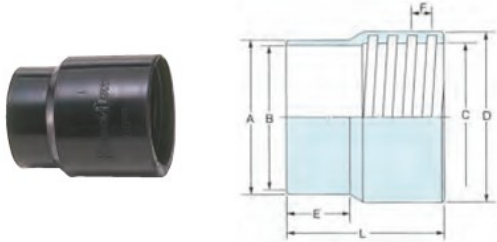


## フレキT型カフス

材質：EPDM(アイボリー)

単位：mm

型番	呼称	A	B	C	D	E	F
CFS-T-038	38	44.0	38.0	48.0	35.0	35.0	9.0
CFS-T-050	50	57.0	50.0	64.0	35.0	35.0	10.5
CFS-T-065	65	69.0	63.0	78.0	35.0	41.0	12.0
CFS-T-075	75	81.0	75.0	88.0	40.0	45.0	13.0
CFS-T-090	90	97.0	90.0	100.0	45.0	50.0	13.5
CFS-T-100	100	106.0	101.0	115.0	45.0	50.0	14.0
CFS-T-125	125	133.0	125.0	139.0	45.0	50.0	15.0
CFS-T-150	150	160.0	150.0	164.0	50.0	63.0	19.0
CFS-T-200	200	210.0	200.0	214.0	55.0	70.0	20.0

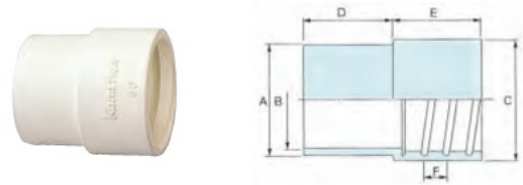


## ダクトN.S.D.用カフス

材質：EVA

単位：mm

型番	呼称	A	B	C	D	E	F	L
CFS-NS-D-032	φ32	36.0	32.0	33.8	42.0	35.0	7.5	70
CFS-NS-D-038	φ38	43.0	38.0	40.5	48.0	35.0	8.6	80
CFS-NS-D-050	φ50	56.3	50.8	53.0	65.5	35.0	10.5	82
CFS-NS-D-065	φ65	69.0	63.0	65.0	78.5	33.0	11.5	86
CFS-NS-D-075	φ75	83.2	76.2	78.5	92.5	37.0	12.3	94
CFS-NS-D-090	φ90	96.9	88.9	91.5	106.5	40.0	12.8	99
CFS-NS-D-100	φ100	109.6	101.3	105.0	119.8	42.0	15.0	110
CFS-NS-D-125	φ125	135.0	127.0	129.3	146.3	50.0	21.0	142
CFS-NS-D-150	φ150	160.0	152.0	155.5	173.3	65.0	20.0	160
CFS-NS-D-200	φ200	213.0	203.0	207.0	224.5	110.0	22.5	233

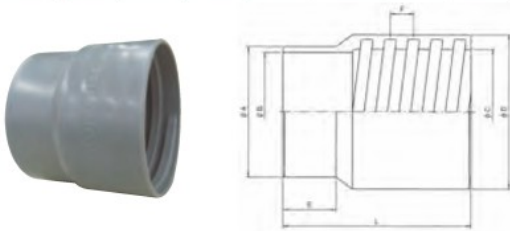

## アダプター継手・ダクト継手

アダプター継手  
材質：PE(グレー)

単位：mm

型番	呼称 (mm)	A	B	C	D
S-AD-100	100	100	98	111	116
S-AD-150	150	150	148	161	166
S-AD-200	200	200	198	211	216

※カナアルミダクト・カナアルミⅡ型

ダクト継手  
材質：PE(グレー)

単位：mm

型番	呼称 (mm)	A	B
S-DC-075	75	75	73
S-DC-100	100	100	98
S-DC-125	125	125	123
S-DC-150	150	150	148
S-DC-200	200	200	195

※カナアルミダクト・カナアルミⅡ型・断熱ダクトS・W(φ75~φ150)