


KSV-2

超硬センターVエンドミル
Tungsten Carbide Center V Endmill

■先端角30° 45° 60° 70° 80° 90° 120° を
小径サイズ(Φ0.5~Φ6)で揃えました
line-upped small diameter with edge angle
30° 45° 60° 70° 80° 90° 120°

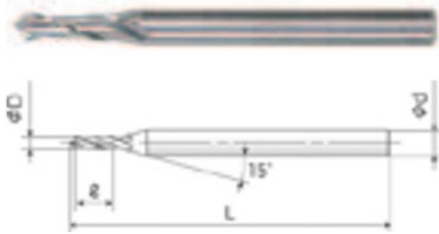

超微粒子合金 Micro Grain Tungsten Carbide



刃径の許容差 Flute Diameter Tolerance
D 0~-0.01



柄径の許容差 Shank Diameter Tolerance
d=3 0~-0.006
3<d≤6 0~-0.008



ネジレ角30° Twist Angle 30°

- 切削条件表はP197に記載
- Cutting conditions are recommended on page 197.

単位[寸法:mm/価格:円]
Unit [size:mm/Retail Price:JPY]

KSV-2-90°形



先端角度90° +30°
-0°

品番 Code No.	刃径 D Flute Diameter	刃長 ℓ Flute Length	全長 L Total Length	柄径 d Shank Diameter	先端フラット径 Edge Flat Diameter	標準価格 Retail Price
KSV-29005	0.5	1	40	3	0.06	8,500
KSV-29006	0.6	1.2	40	3	0.06	8,500
KSV-29007	0.7	1.4	40	3	0.06	7,800
KSV-29008	0.8	1.6	40	3	0.06	7,800
KSV-29009	0.9	2	40	3	0.06	7,500
KSV-29010	1	2	45	4	0.1	7,000
KSV-29011	1.1	2.5	45	4	0.1	7,000
KSV-29012	1.2	2.5	45	4	0.1	7,000
KSV-29013	1.3	3	45	4	0.1	7,000
KSV-29014	1.4	3	45	4	0.1	7,000
KSV-29015	1.5	3	45	4	0.1	7,000
KSV-29016	1.6	3.5	45	4	0.1	7,000
KSV-29017	1.7	3.5	45	4	0.1	7,000
KSV-29018	1.8	4	45	4	0.1	7,000
KSV-29019	1.9	4	45	4	0.1	7,000
KSV-29020	2	4	45	4	0.2	7,000
KSV-29021	2.1	4.5	45	4	0.2	7,800
KSV-29022	2.2	4.5	45	4	0.2	7,800
KSV-29023	2.3	5	45	4	0.2	7,800
KSV-29024	2.4	5	45	4	0.2	7,800

KSV-2-90°形



先端角度90° +30°
-0°

品番 Code No.	刃径 D Flute Diameter	刃長 ℓ Flute Length	全長 L Total Length	柄径 d Shank Diameter	先端フラット径 Edge Flat Diameter	標準価格 Retail Price
KSV-29025	2.5	5	45	4	0.2	7,800
KSV-29026	2.6	6	45	4	0.2	7,800
KSV-29027	2.7	6	45	4	0.2	7,800
KSV-29028	2.8	6	45	4	0.2	7,800
KSV-29029	2.9	6	45	4	0.2	7,800
KSV-29030	3	6	45	4	0.2	7,800
KSV-29035	3.5	7	50	6	0.2	10,100
KSV-29040	4	8	50	6	0.2	10,100
KSV-29045	4.5	9	50	6	0.3	11,700
KSV-29050	5	10	60	6	0.3	11,700
KSV-29055	5.5	11	60	6	0.3	12,800
KSV-29060	6	12	60	6	0.3	12,800

KSV-2-60°形



先端角度60° +30°
-0°

品番 Code No.	刃径 D Flute Diameter	刃長 ℓ Flute Length	全長 L Total Length	柄径 d Shank Diameter	先端フラット径 Edge Flat Diameter	標準価格 Retail Price
KSV-26005	0.5	1	40	3	0.06	9,400
KSV-26006	0.6	1.2	40	3	0.06	9,400
KSV-26007	0.7	1.4	40	3	0.06	9,400
KSV-26008	0.8	1.6	40	3	0.06	8,500
KSV-26009	0.9	2	40	3	0.06	8,200
KSV-26010	1	2	45	4	0.08	7,800
KSV-26011	1.1	2.5	45	4	0.08	7,800
KSV-26012	1.2	2.5	45	4	0.08	7,800
KSV-26013	1.3	3	45	4	0.08	7,800
KSV-26014	1.4	3	45	4	0.08	7,800
KSV-26015	1.5	3	45	4	0.08	7,800
KSV-26016	1.6	3.5	45	4	0.08	7,800
KSV-26017	1.7	3.5	45	4	0.08	7,800
KSV-26018	1.8	4	45	4	0.08	7,800
KSV-26019	1.9	4	45	4	0.08	7,800
KSV-26020	2	4	45	4	0.1	7,800
KSV-26021	2.1	4.5	45	4	0.1	8,500
KSV-26022	2.2	4.5	45	4	0.1	8,500
KSV-26023	2.3	5	45	4	0.1	8,500
KSV-26024	2.4	5	45	4	0.1	8,500
KSV-26025	2.5	5	45	4	0.1	8,500
KSV-26026	2.6	6	45	4	0.1	8,500
KSV-26027	2.7	6	45	4	0.1	8,500
KSV-26028	2.8	6	45	4	0.1	8,500
KSV-26029	2.9	6	45	4	0.1	8,500
KSV-26030	3	6	45	4	0.1	8,500
KSV-26040	4	8	50	6	0.15	11,200
KSV-26050	5	10	60	6	0.2	12,900
KSV-26060	6	12	60	6	0.2	14,000