


RMC

RB-1

Male Connector
おねじコネクタ



Cd ≤ 75ppm

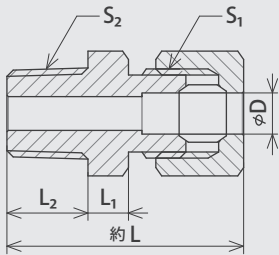

品番	旧品番	呼称 φD × S ₂	対辺寸法		適合管外径 φD	適合ねじ S ₁ (G)	適用ねじ S ₂ (R)	寸法情報			
			本体	ナット				約L	L ₁	L ₂	最小穴径
RMC 03818	RP-40	3 × 1/8	12	12	3.0	1/8	1/8	28.0	5.0	9.0	2.8
RMC 03828		3 × 1/4	14	12	3.0	1/8	1/4	32.0	6.0	12.0	2.8
RMC 04818	RP-41	4 × 1/8	12	12	4.0	1/8	1/8	28.0	5.0	9.0	3.0
RMC 04828		4 × 1/4	14	12	4.0	1/8	1/4	32.0	6.0	12.0	3.0
RMC 05818	RP-42	5 × 1/8	12	12	5.0	1/8	1/8	28.0	5.0	9.0	4.0
RMC 05828		5 × 1/4	14	12	5.0	1/8	1/4	32.0	6.0	12.0	4.0
Ⓟ RMC 06818	RP-104	6 × 1/8	14	16	6.0	1/4	1/8	33.0	6.0	9.0	5.0
Ⓟ RMC 06828	RP-105	6 × 1/4	16	16	6.0	1/4	1/4	36.0	6.0	12.0	5.0
Ⓟ RMC 06838	RP-43	6 × 3/8	19	16	6.0	1/4	3/8	39.0	8.0	13.0	5.0
Ⓟ RMC 08818	RP-114	8 × 1/8	14	16	8.0	1/4	1/8	33.0	6.0	9.0	5.0
Ⓟ RMC 08828	RP-107	8 × 1/4	16	16	8.0	1/4	1/4	36.0	6.0	12.0	6.5
Ⓟ RMC 08838	RP-108	8 × 3/8	19	16	8.0	1/4	3/8	39.0	8.0	13.0	6.5
Ⓟ RMC 10828	RP-123	10 × 1/4	19	19	10.0	3/8	1/4	40.0	8.0	12.0	6.5
Ⓟ RMC 10838	RP-111	10 × 3/8	19	19	10.0	3/8	3/8	41.0	8.0	13.0	8.0
Ⓟ RMC 10848		10 × 1/2	22	19	10.0	3/8	1/2	46.0	10.0	16.0	8.0
Ⓟ RMC 12838	RP-124	12 × 3/8	22	24	12.0	1/2	3/8	47.0	10.0	13.0	10.0
Ⓟ RMC 12848	RP-112	12 × 1/2	24	24	12.0	1/2	1/2	50.0	10.0	16.0	10.0
RMC 14838		14 × 3/8	22	24	14.0	1/2	3/8	48.0	10.0	13.0	10.0
RMC 14848	RP-45	14 × 1/2	24	24	14.0	1/2	1/2	51.0	10.0	16.0	12.0
RMC 15838		15 × 3/8	24	27	15.0	5/8	3/8	50.0	10.0	13.0	10.0
RMC 15848	RP-46	15 × 1/2	27	27	15.0	5/8	1/2	54.0	11.0	16.0	12.0
RMC 16838		16 × 3/8	24	27	16.0	5/8	3/8	50.0	10.0	13.0	10.0
RMC 16848	RP-47	16 × 1/2	27	27	16.0	5/8	1/2	54.0	11.0	16.0	12.0
RMC 81818	RP-101	1/8 × 1/8	12	12	1/8	1/8	1/8	28.0	5.0	9.0	2.8
RMC 81828		1/8 × 1/4	14	12	1/8	1/8	1/4	32.0	6.0	12.0	2.8
Ⓟ RMC 82818	RP-121	1/4 × 1/8	14	16	1/4	1/4	1/8	33.0	6.0	9.0	5.0
Ⓟ RMC 82828	RP-106	1/4 × 1/4	16	16	1/4	1/4	1/4	36.0	6.0	12.0	5.0
Ⓟ RMC 82838	RP-44	1/4 × 3/8	19	16	1/4	1/4	3/8	39.0	8.0	13.0	5.0
Ⓟ RMC 83828	RP-122	3/8 × 1/4	19	19	3/8	3/8	1/4	41.0	8.0	12.0	6.5
Ⓟ RMC 83838	RP-109	3/8 × 3/8	19	19	3/8	3/8	3/8	42.0	8.0	13.0	8.0
Ⓟ RMC 83848		3/8 × 1/2	22	19	3/8	3/8	1/2	47.0	10.0	16.0	8.0
Ⓟ RMC 84838	RP-125	1/2 × 3/8	22	24	1/2	1/2	3/8	48.0	10.0	13.0	10.0
Ⓟ RMC 84848	RP-113	1/2 × 1/2	24	24	1/2	1/2	1/2	51.0	10.0	16.0	10.0
RMC 85838		5/8 × 3/8	24	27	5/8	5/8	3/8	50.0	10.0	13.0	10.0
RMC 85848	RP-911	5/8 × 1/2	27	27	5/8	5/8	1/2	54.0	11.0	16.0	12.0

Ⓟ マークのついた製品には、なまし銅管等を接続するためのインサートリング（ピン）の設定があります。P.22 をご参照ください。