




ジョイントシリーズ

単位 mm

ロング水口M

金型冷却用ホース継手

ホース口 二段溝

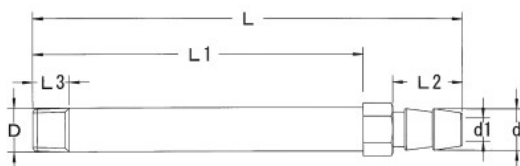


規 格	ホース口 d	ネジ D	六角 対辺	L	L1	L2	L3	d1
LM1/8 × 50	12.5	R1/8	14	80	50	21	9	6
LM1/8 × 70				100	70			
LM1/8 × 100				130	100			
LM1/8 × 130				160	130			
LM1/8 × 150				180	150			
LM1/8 × 170				200	170			
LM1/8 × 200				230	200			
LM1/4 × 50	12.5	R1/4	14	80	50	21	11	7
LM1/4 × 70				100	70			
LM1/4 × 100				130	100			
LM1/4 × 130				160	130			
LM1/4 × 150				180	150			
LM1/4 × 170				200	170			
LM1/4 × 200				230	200			

ロング水口M使用材料
■黄銅棒

ロングニップル

金型冷却用延長継手

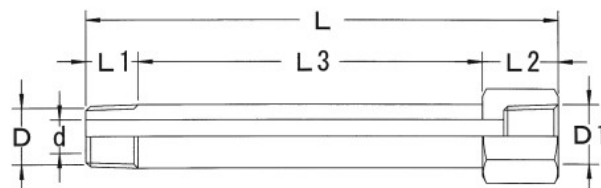

規 格	オネジ D	メネジ D1	L	L1	L2	L3	d	六角 対辺	規 格	オネジ D	メネジ D1	L	L1	L2	L3	d	六角 対辺
LN1/8 × 50	R1/8	Rc1/8	50	9	13	28	6	14	LN1/4 × 50	R1/4	Rc1/4	50	11	16	23	7	17
LN1/8 × 60			60			38			LN1/4 × 60			60			33		
LN1/8 × 70			70			48			LN1/4 × 70			70			43		
LN1/8 × 80			80			58			LN1/4 × 80			80			53		
LN1/8 × 90			90			68			LN1/4 × 90			90			63		
LN1/8 × 100			100			78			LN1/4 × 100			100			73		
LN1/8 × 110			110			88			LN1/4 × 110			110			83		
LN1/8 × 120			120			98			LN1/4 × 120			120			93		
LN1/8 × 130			130			108			LN1/4 × 130			130			103		
LN1/8 × 140			140			118			LN1/4 × 140			140			113		
LN1/8 × 150			150			128			LN1/4 × 150			150			123		
LN1/8 × 160			160			138			LN1/4 × 160			160			133		
LN1/8 × 170			170			148			LN1/4 × 170			170			143		
LN1/8 × 180			180			158			LN1/4 × 180			180			153		
LN1/8 × 190			190			168			LN1/4 × 190			190			163		
LN1/8 × 200			200			178			LN1/4 × 200			200			173		

ロングニップル使用材料
■黄銅棒