


KANA NK60B

●ご注文方法 商品コード
NK60B 20
TYPE 歯数

- チェーンNo.60
- チェーンピッチ(P)19.05mm
- ローラリンク内幅(W)12.70mm
- ローラ外径(Dr)11.91mm
- 歯幅(T)11.9(最大) mm

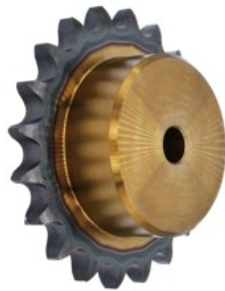

削出仕様



溶接仕様

商品コード	定価 (円)	SEMI-F 定価(円)	外径 Do	ピッチ径 Dp	軸穴径 d			ボス径 BD	ボス長さ BL	形状	歯部	重量 kg
					下穴	最小	最大					
NK60B8	1,100	4,600	58	49.780	12	13	20	★34	32	削出仕様	h m 機械構造用炭素鋼 歯先高周波焼入	0.30
NK60B9	1,000	4,500	64	55.698	12	13	25	★43	32			0.40
NK60B10	1,200	4,700	70	61.647	14	15	30	★49	32			0.49
NK60B11	1,200	4,600	76	67.617	14	15	32	★51	32			0.60
NK60B12	1,300	4,800	83	73.604	14	15	32	51	32			0.69
NK60B13	1,400	4,700	89	79.602	14	15	35	57	32			0.81
NK60B14	1,600	5,200	95	85.610	16	17	40	62	32			0.96
NK60B15	1,700	5,400	101	91.625	16	17	45	68	32			1.10
NK60B16	1,900	5,400	107	97.647	16	17	48	73	32			1.30
NK60B17	2,100	5,800	113	103.674	16	17	48	73	32			1.40
NK60B18	2,700	7,100	119	109.705	16	17	55	83	40			2.00
NK60B19	2,800	7,300	126	115.739	16	17	55	83	40			2.10
NK60B20	2,900	8,400	132	121.776	16	17	55	83	40			2.20
NK60B21	3,200	8,700	138	127.816	16	17	55	83	40			2.30
NK60B22	3,300	8,400	144	133.858	16	17	55	83	40			2.50
NK60B23	3,600	9,400	150	139.902	16	17	55	83	40			2.50
NK60B24	3,700	8,900	156	145.948	18	19	55	83	40			2.60
NK60B25	3,900	9,900	162	151.995	18	19	55	83	40			2.70
NK60B26	4,300	10,500	168	158.043	18	19	55	83	40			2.90
NK60B27	4,800	9,900	174	164.093	18	19	55	83	40			3.00
NK60B28	4,400	10,300	180	170.143	18	19	55	83	40			3.10
NK60B29	5,500	11,300	187	176.195	18	19	55	83	40			3.30
NK60B30	5,100	11,000	193	182.247	18	19	55	83	40			3.40
NK60B31	6,300	13,500	199	188.300	20	21	55	83	40			3.64
NK60B32	6,200	12,900	205	194.354	20	21	55	83	40			3.80
NK60B33	6,800	15,600	211	200.408	20	21	55	83	40			4.00
NK60B34	6,800	14,100	217	206.463	20	21	55	83	40			4.15
NK60B35	7,000	14,600	223	212.518	20	21	55	83	40			4.33
NK60B36	7,400	15,500	229	218.574	20	21	55	83	40			4.52
NK60B37	9,600	18,200	235	224.631	20	21	55	83	40			4.70
NK60B38	8,400	17,300	241	230.687	20	21	55	83	40			4.90
NK60B39	10,400	17,800	247	236.744	20	21	55	83	40			5.10
NK60B40	8,600	17,000	253	242.802	20	21	55	83	40			5.30