


# 40A

## ●ご注文No.表記例

**40A 20**

TYPE 歯数

スプロケットNo.

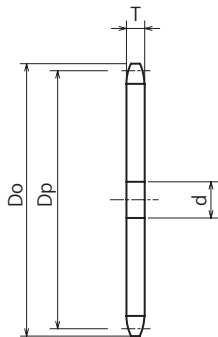

- チェーン .....No.40
- チェーンピッチ .....(P) 12.70mm
- ローラリンク内幅 .....(W) 7.95mm
- ローラ外径 .....(Dr) 7.92mm
- 歯幅 .....(T) 7.2 mm

**m** 普通鋼

TYPE	歯数	外径 Do	ピッチ径 Dp	軸穴径d		重量 kg	¥	Semi-F ¥
				下穴	最小			
40A	10	47	41.10	9	10	0.05	260	シリーズ追加検討中
	11	51	45.08	10	11	0.09	290	
	12	55	49.07	10	11	0.10	310	
	13	59	53.07	12	13	0.12	300	
	14	63	57.07	12	13	0.14	330	
	15	67	61.08	12	13	0.16	360	
	16	71	65.10	13	14	0.18	370	
	17	76	69.12	13	14	0.20	410	
	18	80	73.14	13	14	0.23	440	
	19	84	77.16	14	15	0.26	480	
	20	88	81.18	14	15	0.29	460	
	21	92	85.21	14	15	0.30	490	
	22	96	89.24	14	15	0.35	540	
	23	100	93.27	14	15	0.38	550	
	24	104	97.30	14	15	0.40	580	
	25	108	101.33	14	15	0.45	620	
	26	112	105.36	14	15	0.49	640	
	27	116	109.40	14	15	0.50	670	
	28	120	113.43	14	15	0.56	680	
29	124	117.46	14	15	0.60	830		
30	128	121.50	14	15	0.63	740		
31	133	125.53	14	15	0.65	950		
32	137	129.57	14	15	0.70	820		
33	141	133.61	14	15	0.75	1,000		
34	145	137.64	14	15	0.80	950		
35	149	141.68	14	15	0.85	990		
36	153	145.72	16	17	0.90	1,080		
37	157	149.75	16	17	0.99	1,480		
38	161	153.79	16	17	1.00	1,200		
39	165	157.83	16	17	1.15	1,520		

シリーズ追加検討中