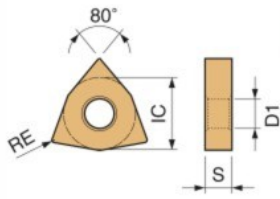


六角形80°・ネガ・穴付き


(mm)				(mm)			
型番	IC	S	D1	型番	IC	S	D1
WN_06T3_	9.525	3.97	3.81	WN_0804_	12.70	4.76	5.16
WN_0604_	9.525	4.76	3.81				

[illegible]



ブレーカ適用範囲

切込みは半径値(片肉)を示す

1

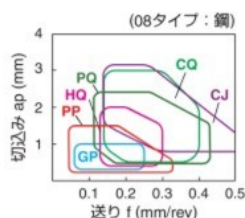

2

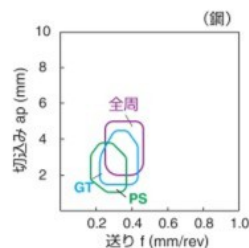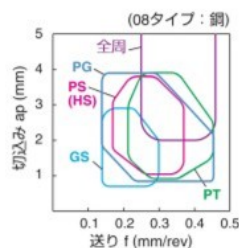

3

