
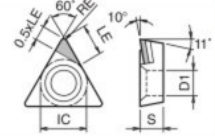

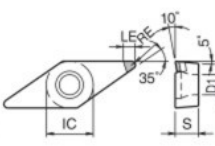
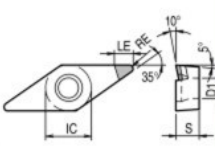

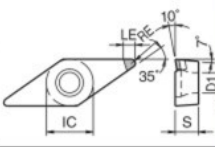
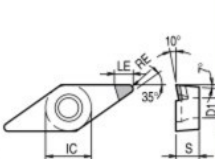


## ポジ

刃先仕様				寸法 (mm)					使用コーナ数	ダイヤモンド				適合ホルダ参照ページ
ダイヤモンド全般	シャープエッジ	IC	S	D1	RE	LE	KPD001	KPD010		KPD230	KPD250			
 	<b>TPMH</b> 110302L-NE 110304L-NE	6.35	3.18	3.3	0.2 0.4	3.8 3.6	1	●				C26 下表参照		
								●						
  	<b>VBMT</b> 110301SE 110302SE 110304SE 110308SE	6.35	3.18	2.8	0.1 0.2 0.4 0.8	2.5 2.3 1.9 1.9	1	●				下表参照		
	●													
	●													
	●													
	<b>VBMT</b> 160401SE 160402SE 160404SE 160408SE	9.525	4.76	4.4	0.1 0.2 0.4 0.8	2.7 2.5 2.1 2.0	1	●						
	●													
	●													
	●													
	<b>VBMT</b> 110301NE 110302NE 110304NE 110308NE	6.35	3.18	2.8	0.1 0.2 0.4 0.8	2.6 2.4 2.0 3.1	1	●						
	●													
	●													
	●													
<b>VBMT</b> 160401NE 160402NE 160404NE 160408NE	9.525	4.76	4.4	0.1 0.2 0.4 0.8	2.8 2.6 2.2 3.0	1	●							
●														
●														
●														
<b>VBMT</b> 110301 110302 110304 110308	6.35	3.18	2.8	0.1 0.2 0.4 0.8	3.0 2.8 2.4 3.5	1	●	●						
●				●										
●				●										
●				●										
<b>VBMT</b> 160401 160402 160404 160408	9.525	4.76	4.4	0.1 0.2 0.4 0.8	3.2 3.0 2.6 3.5	1	●	□						
●				●										
●				●										
●				●										
  	<b>VCMT</b> 080202SE 080204SE 080208SE	4.76	2.38	2.3	0.2 0.4 0.8	1.4 1.4 1.4	1	●				E39 F52 F54 F57		
	●													
	●													
	<b>VCMT</b> 080201NE 080202NE 080204NE 080208NE	4.76	2.38	2.3	0.1 0.2 0.4 0.8	1.7 1.7 1.8 1.9	1	●						
	●													
	●													
	●													
	<b>VCMT</b> 080201 080202 080204 080208	4.76	2.38	2.3	0.1 0.2 0.4 0.8	2.0 2.0 2.1 2.2	1	●	●					
●	●													
●	●													
●	●													

・型番末尾のSEはスモールエッジ、NEはニューバリューエッジを示します。

チップ型番	適合ホルダ参照ページ
VB..1103タイプ	E30,E31,E32,E39,F52,F54,F57
VB..1604タイプ	E31,E32,F52,F54,F57

CBNダイヤモンド

CBN

ダイヤモンド

ポジ

ソリッド

溝入れ