


KGA





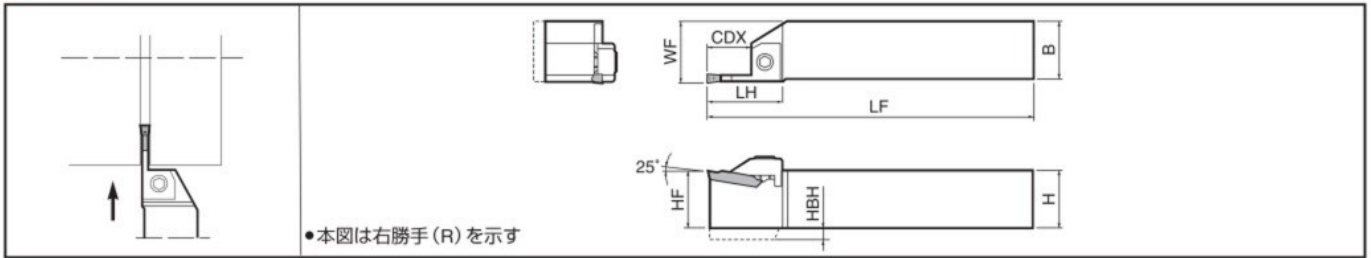

ホルダ寸法

型番	在庫 寸法 (mm)										部品			
	R	L	H	HF	HBH	B	LF	LH	WF	CDX	押え金具	クランプボルト	スプリング	レンチ
KGA ^{R/L} 2020K-3 2525M-3	●	●	20	20	5	20	125	37	21.5	20	CGA-3 ^{R/L}	HH6X20	SP-6	LW-5
	●	●	25	25	-	25	150	37	26.5	20				
2020K-4 2525M-4	●	●	20	20	5	20	125	37	21.5	20	CGA-4 ^{R/L}	HH6X20	SP-6	LW-5
	●	●	25	25	-	25	150	37	26.5	20				
2020K-5 2525M-5	●	●	20	20	5	20	125	42	21.5	25	CGA-5 ^{R/L}	HH6X20	SP-6	LW-5
	●	●	25	25	-	25	150	42	26.5	25				

・CDX：加工可能溝深さを示します。

・押え金具：右勝手 (R) ホルダには CGA-OR、左勝手 (L) ホルダには CGA-OL が適合します。

適合チップ

形状	型番	寸法 (mm)		サーメット										セラミック	適合ホルダ型番	適合ホルダ参照ページ
		CW	RE	TN60	TC40N	TC60M	CR9025	PR930	KW10	A65	AG6N	PT600M				
 研磨ブレード  セラミック	GH	4020-02	4.0	0.2	●	●	●	●	●	●	●	●	●	●	KGH ^{R/L} ...4 KGHS ^{R/L} ...4	G54
		4020-05	4.0	0.5	●	●	●	●	●	●	●	●	●	●		
		4520-02	4.5	0.2	●	●	●	●	●	●	●	●	●	●		
		4520-05	4.5	0.5	●	●	●	●	●	●	●	●	●	●		
		5020-02	5.0	0.2	●	●	●	●	●	●	●	●	●	●		
		5020-05	5.0	0.5	●	●	●	●	●	●	●	●	●	●		
	5520-02	5.5	0.2	●	●	●	●	●	●	●	●	●	●			
	5520-05	5.5	0.5	●	●	●	●	●	●	●	●	●	●			
	6020-02	6.0	0.2	●	●	●	●	●	●	●	●	●	●			
	6020-05	6.0	0.5	●	●	●	●	●	●	●	●	●	●			
	6520-02	6.5	0.2	●	●	●	●	●	●	●	●	●	●			
	6520-05	6.5	0.5	●	●	●	●	●	●	●	●	●	●			
7020-02	7.0	0.2	●	●	●	●	●	●	●	●	●	●				
7020-05	7.0	0.5	●	●	●	●	●	●	●	●	●	●				
7520-02	7.5	0.2	●	●	●	●	●	●	●	●	●	●				
7520-05	7.5	0.5	●	●	●	●	●	●	●	●	●	●				
8020-02	8.0	0.2	●	●	●	●	●	●	●	●	●	●				
8020-05	8.0	0.5	●	●	●	●	●	●	●	●	●	●				
10025-05	10.0	0.5	●	●	●	●	●	●	●	●	●	●				
12025-05	12.0	0.5	●	●	●	●	●	●	●	●	●	●				
 3次元ブレード	GHU	40-20	4.0	0.25	●	●	●	●	●	●	●	●	●	KGH ^{R/L} ...4 KGHS ^{R/L} ...4	G54	
		50-20	5.0	0.30	●	●	●	●	●	●	●	●	●			
		60-20	6.0	0.30	●	●	●	●	●	●	●	●	●			
	GA	30	3.0	0.20	●	●	●	●	●	●	●	●	●	KGA ^{R/L} ...3 KGA ^{R/L} ...4 KGA ^{R/L} ...5	G55	
		40	4.0	0.25	●	●	●	●	●	●	●	●	●			
		50	5.0	0.30	●	●	●	●	●	●	●	●	●			

- ：標準在庫
- ：準標準在庫 (在庫をご確認ください)
- ：次期カタログより抹消予定

推奨切削条件 ● G121~G122

チップの販売個数は、1ケース10個入りです