


外径ねじ切りホルダ [TTチップ用]

KTT

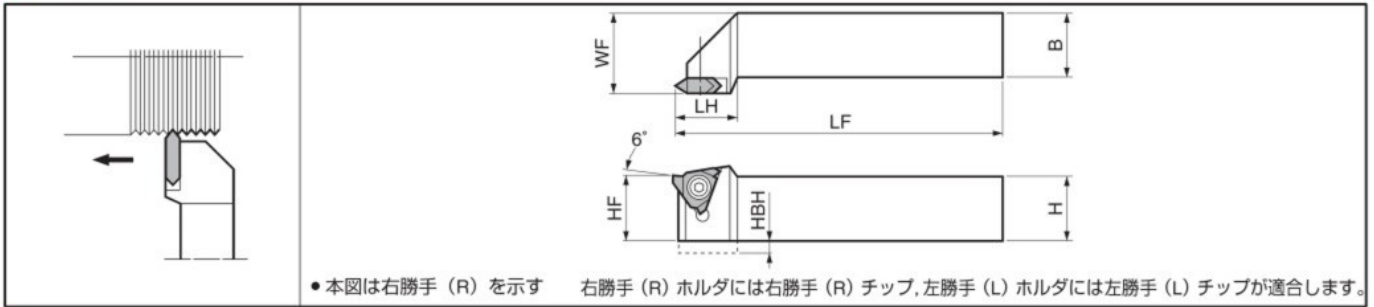

ホルダ寸法

型番	在庫		寸法 (mm)								部品			
	R	L	H	HF	HBH	B	LF	LH	WF	クランプスクリュー		レンチ		
KTT [®]	●	●	10	10	4	10	80	18	12	SB-4070TRS	-	FT-10	-	
	●	●	12	12	2	12	100							16
	●	●	16	16	-	16	100							20
	●	●	20	20	-	20	125	25	25	SB-4TR	-	FT-15	-	
	●	●	25	25	-	25	150							30
	●	●	20	20	-	20	125	25	25	-	GS-50	-	LW-3	
	●	●	25	25	-	25	150							30

適合チップ

型番	IC	S	D1	P	M	K	N	使用分類の目安		切込み量とパス数参照ページ
								●	○	
TT32 [®]	9.525	3.18	4.4	○	○	●	●	●	○	●
TT43 [®]	12.70	4.76	5.5	○	○	●	●	●	○	●

形状	型番	適用ねじ	ピッチ		寸法 (mm)			角度	サメット		PVDコーティング		超硬	適合ホルダ型番			
			mm	山 / inch	RE	PDX	PNA		TC60M	PR930	PR1115	KW10					
			R	L	R	L	R		L	R	L						
ねじ切りなし	TT32 [®]	M UN	6000	0.5-2.5	-	56-10	0.0	-	60°	●	●	●	●	KTT [®] /L...-16	J43		
			6001	1.0-2.5	-	24-10	0.1	-	60°	●	●	●	●				
			6002	1.5-2.5	-	16-10	0.2	-	60°	●	●	●	●				
			6003	2.5	-	11-10	0.3	-	60°	●	●	●	●				
			TT32 [®]	G,PT W	5501	-	28-11	24-10	0.1	-	55°	○	●			●	●
					5502	-	14-11	14-10	0.2	-	55°	○	●			●	●
ねじ付付き	TT43ER	M	100M	1.00	-	-	0.12	0.8	60°	●	●	●	J44				
			125M	1.25	-	-	0.15	0.9	60°	●	●	●					
			150M	1.50	-	-	0.19	1.0	60°	●	●	●					
			200M	2.00	-	-	0.25	1.7	60°	●	●	●					
ねじ切りなし	TT43 [®]	M UN	6001	1.0-3.5	-	24-8	0.1	-	60°	○	●	●	KTT [®] /L...-22	J43			
			6002	1.5-3.5	-	16-8	0.2	-	60°	○	●	●					
			6003	2.5-3.5	-	11-8	0.3	-	60°	○	●	●					
			6004	3.0-3.5	-	8	0.4	-	60°	○	●	●					
	TT43 [®]	G,PT W	5501	-	28-11	24-7	0.1	-	55°	○	●	●					
			5502	-	14-11	16-7	0.2	-	55°	○	●	●					
			5503	-	11	10-7	0.3	-	55°	○	●	●					
			5504	-	8-7	0.4	-	55°	○	●	●						

推奨切削条件 J36

適用ねじ	M:メートルねじ	R (PT)(BSPT): 管用テーパねじ
	UN: ユニファイねじ	W: ウィットねじ
	UNF: ユニファイ細目ねじ	NPT: アメリカ管用テーパねじ
	G(PF): 管用平行ねじ	

●: 標準在庫
○: 次期カタログより抹消予定

PR930/PR1115(ねじ切り)は、1ケース5個入りです

TC60M/KW10(ねじ切り)は、1ケース10個入りです