

旋削用チップ

「旋削用チップ」カタログの見方 B15 参照

ひし形80°・ネガ・穴付き

型番	IC	S	D1	型番	IC	S	D1
CN_0904_	9.525	4.76	3.81	CN_1606_	15.875	6.35	6.35
CN_1204_	12.70	4.76	5.16	CN_1906_	19.05	6.35	7.94

形状	型番	寸法 (mm)				コーティング												DLC		超硬		適用品種参照ページ																								
		RE	TN610	TN620	TN60	CCX	PV710	PV720	PV730	PV90	PV7005	CA510	CA515	CA525	CA530	CA5505	CA5515	CA5525	CA5535	CA6515	CA6525	CA310	CA315	CA320	CA4505	CA4515	PR1705	PR1725	PR930	PR1225	PR005S	PR015S	PR1535	PDL010	PDL025	KW10	SW05	D8	D9	F65	F69	F70				
仕上げ 仕上がり・シャープエッジ	CNGG 120404R-A3 120404L-A3 120408R-A3 120408L-A3	0.4																																												
		0.4																																												
		0.8																																												
		0.8																																												
仕上げ 面粗さ重視・シャープエッジ	CNGG 120404AH 120408AH	0.4																																												
		0.8																																												
仕上げ 面粗さ重視・シャープエッジ	CNMG 120404AH 120408AH	0.4																																												
		0.8																																												
中切削	CNGG 090404L 090408L CNGG 120404R 120404L 120408R 120408L	0.2	●	●	●		●	●																																						
		0.2	●	●	●		●	●																																						
		0.4	●	●	●		●	●																																						
		0.8	●	●	●		●	●																																						
中荒 低抵抗	CNGG 120404R-25R 120404L-25R 120408R-25R 120408L-25R	0.4	●	●	●		●	●																																						
		0.4	●	●	●		●	●																																						
		0.8	●	●	●		●	●																																						
		0.8	●	●	●		●	●																																						
中荒	CNGG 120404Z	0.4			●																																									

B
旋削チップ

ブレード特長
ネガ

C

D

R


S

T

V

W

セラミック

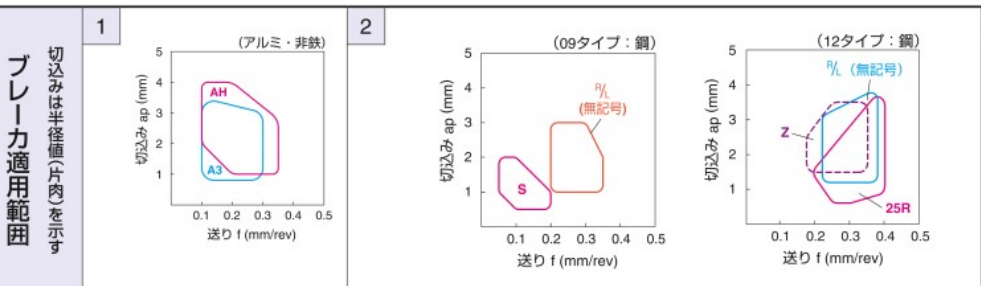

チップの販売個数は、1ケース10個入りです