

旋削用チップ

「旋削用チップ」カタログの見方 B15 参照

ひし形55°・ネガ・穴付き

型番	(mm)			型番	(mm)		
	IC	S	D1		IC	S	D1
DN_1104_	9.525	4.76	3.81	DN_1506_	12.70	6.35	5.16
DN_1504_	12.70	4.76	5.16				

形状	型番	寸法 (mm)	サーメット				CVDコーティング										PVDコーティング				DLC	超硬	適合ホルダ参照ページ	ブレード適用範囲																															
			PVDサーメット				CVDコーティング										PVDコーティング																																						
			RE	TN610	TN620	TN60	CCX	PV710	PV720	PV730	PV90	PV7005	CA510	CA515	CA025P	CA525	CA530	CA505	CA515	CA525					CA535	CA6515	CA6525	CA310	CA315	CA320	CA405	CA4515	PR1705	PR1725	PR930	PR1225	PR005S	PR015S	PR1535	PDL010	PDL025	KW10	SW05												
 铸铁 プレーカなし	DNMA 150404 150408	0.4 0.8																																																		D12 D13 F66 F72 F73			
	DNMA 150604 150608	0.4 0.8																																																				D12 D13 F66	
 アルミ非鉄 仕上げ・中・シャープエッジ	DNGG 150404R-A3 150404L-A3 150408R-A3 150408L-A3	0.4 0.4 0.8 0.8																																																				D12 D13 F66 F72 F73	
	DNGG 150404AH 150408AH	0.4 0.8																																																				D12 D13 F66	1
 アルミ非鉄 中・荒・シャープエッジ	DNGG 150604AH 150608AH	0.4 0.8																																																			D12 D13 F66		
	DNMG 150404AH 150408AH	0.4 0.8																																																			D12 D13 F66 F72 F73		
 仕上げ 図面仕様・シャープエッジ	DNGG 110402R-S 110402L-S 110404R-S 110404L-S 110408R-S 110408L-S	0.2 0.2 0.4 0.4 0.8 0.8																																																			D13 F71		
	DNGG 110404R 110404L 110408R	0.4 0.4 0.8																																																			D12 D13 F66 F72 F73	2	
	DNGG 150404R 150404L 150408R 150408L	0.4 0.4 0.8 0.8																																																				D12 D13 F66 F72 F73	

B
旋削チップ

ブレード
特長

ネガ

C

D

R


S

T

V

W

セラミック

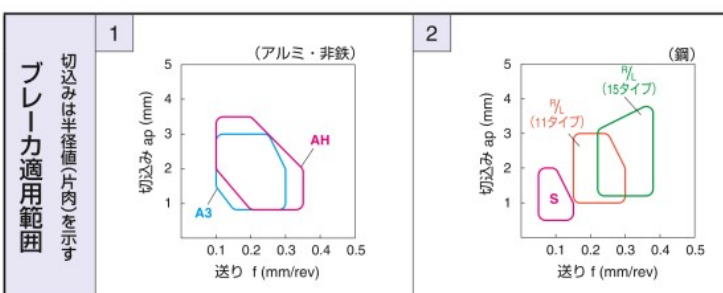

B30 チップの販売個数は、1ケース10個入りです

● : 標準在庫 ▲ : 将来、新製品に置換予定