

旋削用チップ

「旋削用チップ」カタログの見方 B15 参照

(mm)

三角形60°・ネガ・穴付き


型番	IC	S	D1
TN_1103_	6.35	3.18	2.26
TN_1104_	6.35	4.76	2.26

型番	IC	S	D1
TN_1603_	9.525	3.18	3.81
TN_1604_	9.525	4.76	3.81
TN_2204_	12.70	4.76	5.16

B
旋削チップ

形状	型番	寸法 (mm)			サーメット								CVDコーティング										PVDコーティング				DLC	超硬	適合ホルダ参照ページ	ブレイカ適用範囲								
		RE	TN610	TN620	TN60	CCX	PV710	PV720	PV730	PV90	PV7005	CA510	CA515	CA025P	CA525	CA530	CA5505	CA5515	CA5525	CA5535	CA6515	CA6525	CA310	CA315	CA320	CA4505					CA4515	PR1705	PR1725	PR930	PR1225	PR005S	PR015S	PR1535
仕上げ スーパーファイン シャープエッジ精密加工対応	TNEG 160402R-SSF	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D16
	TNEG 160402L-SSF	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D17
	TNEG 160404R-SSF	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D18
	TNEG 160404L-SSF	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F66
	TNEG 160404L-SSF	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F76	
仕上げ 面粗さ重視・シャープエッジ	TNGG 110402R-S	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D16	
	TNGG 110402L-S	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D17	
	TNGG 110404R-S	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F77	
	TNGG 110404L-S	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F77	
	TNGG 110408R-S	0.8	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F77	
	TNGG 110408L-S	0.8	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F77	
	TNGG 160401R-S	0.1	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D16		
	TNGG 160401L-S	0.1	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D17		
	TNGG 160402R-S	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D18	
	TNGG 160404R-S	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F76	
仕立て中	TNGG 110302R-B	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D16	
	TNGG 110302L-B	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D17	
	TNGG 110304R-B	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	-	
	TNGG 110304L-B	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	-	
	TNGG 160402R-B	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D16	
	TNGG 160402L-B	0.2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	D17	
	TNGG 160404R-B	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F66	
	TNGG 160404L-B	0.4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F76	
	TNGG 160408R-B	0.8	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F76	
	TNGG 160408L-B	0.8	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	F77	

- ブレイカ特長
- ネガ
- C
- D
- R
- S
- T
- V
- W
- セラミック

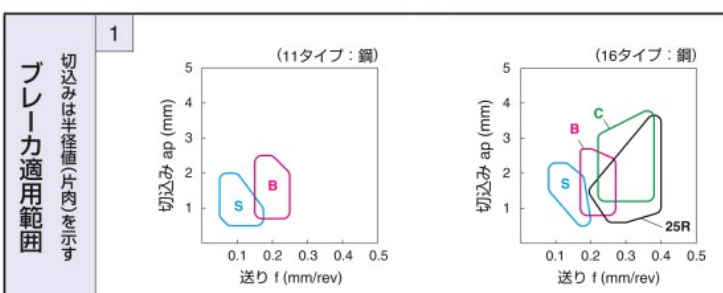

チップの販売個数は、1ケース10個入りです