

旋削用チップ

「旋削用チップ」カタログの見方 **B15** 参照

(mm)

ひし形55°・ポジ・穴付き

チップ型番	適合ホルダ参照ページ
DC..07 タイプ	E28,E29,E32,E33,E44,F45~F47
DC..11 タイプ	E24,E28~E30,E32,E33,E44,F45~F47,F67


型番	IC	S	D1
DC_0702_	6.35	2.38	2.8
DC_11T3_	9.525	3.97	4.4

形状	型番	寸法(mm)				サーメット		CVDコーティング														PVDコーティング			DLC		超硬		適 合 ホ ル ダ 参 照 ペ ー ジ	ブ レ ー カ 適 用 範 圍													
		RE	TN610	TN620	TN60	CXX	PV710	PV720	PV730	PV90	PV7005	CA510	CA515	CA025P	CA525	CA530	CA5505	CA5515	CA5925	CA5535	CA6515	CA6525	CA310	CA315	CA320	CA4505	CA4515	PR1705			PR1725	PR930	PR1225	PR005S	PR015S	PR1535	PDL010	PDL025	KW10	SW05			
微小 穴 付	DCGT 070201MP-CF 070202MP-CF	<0.1 <0.2																											●														
	DCGT 11T301MP-CF 11T302MP-CF	<0.1 <0.2																											●														
微小 穴 付	DCGT 070202CF	0.2																																									
	DCGT 11T302CF	0.2																																									
仕 上 げ	DCGT 070201MFP-GF 070202MFP-GF 070204MFP-GF	<0.1 <0.2 <0.4																																									
	DCGT 11T301MFP-GF 11T302MFP-GF 11T304MFP-GF	<0.1 <0.2 <0.4																																									
	DCGT 070205MFP-SKS 070201MFP-SKS 070202MFP-SKS	<0.05 <0.1 <0.2																																									
仕 上 げ	DCGT 11T3005MFP-SKS 11T301MFP-SKS 11T302MFP-SKS 11T304MFP-SKS	<0.05 <0.1 <0.2 <0.4																																									
	DCGT 070201MFP-SK 070202MFP-SK 070204MFP-SK	<0.1 <0.2 <0.4																																									
	DCGT 11T301MFP-SK 11T302MFP-SK 11T304MFP-SK	<0.1 <0.2 <0.4																																									
仕 上 げ	DCGT 070201MP-CK 070202MP-CK	<0.1 <0.2																																									
	DCGT 11T301MP-CK 11T302MP-CK	<0.1 <0.2																																									
仕 上 げ	DCGT 070201CK 070202CK	0.1 0.2																																									
	DCGT 11T301CK 11T302CK	0.1 0.2																																									

上表参照

1

・ コーナR(RE)寸法が不等号(例: <0.05, <0.1, <0.2 など)で表示されていますチップは、コーナR(RE)がマイナス公差の製品を示します。

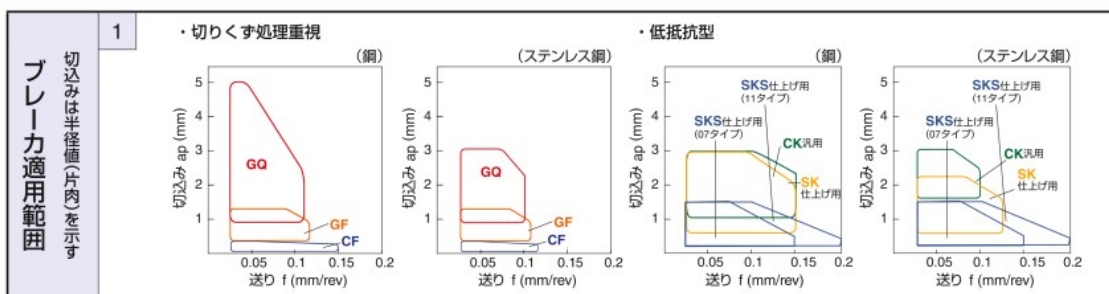

チップの販売個数は、1ケース10個入りです