


(mm)

型番	IC	S	D1	型番	IC	S	D1
TP_0802_	4.76	2.38	2.3	TP_H0902_	5.56	2.38	3.2
TP_T(X)0902_	5.56	2.38	2.8	TP_1103_	6.35	3.18	3.3
				TPMT1603_	9.525	3.18	4.4

■ 三角形60°・ポジ・穴付き

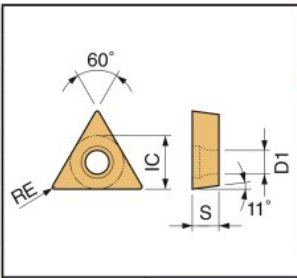

形状	型番	サーメット				PVDサーメット				CVDコーティング										PVDコーティング					DLC	超硬	適合ホルダ参照ページ	ブレード適用範囲														
		RE	TN610	TN620	TN60	CCX	PV710	PV720	PV730	PV90	PV7005	CA510	CA515	CA025P	CA525	CA530	CA5505	CA5515	CA5525	CA5535	CA6515	CA6525	CA310	CA315					CA320	CA4505	CA4515	PR1705	PR1725	PR930	PR1225	PR005S	PR015S	PR1535	PDL010	PDL025	KW10	SW05
		寸法 (mm)	サーメット		CVD		PVDサーメット		CVDコーティング										PVDコーティング																							
仕上げ	TPMT 090202GP 090204GP	0.2 0.4	● ●	● ●	● ●		● ●	● ●				● ●	● ●	● ●																												
	TPMT 110304GP 110308GP	0.4 0.8	● ●	● ●	● ●		● ●	● ●	▲ ▲	● ●	● ●	● ●	● ●																													
	TPMT 160304GP	0.4	●	●	●		●	●	▲	●	●	●	●																													
仕上げ中	TPMT 090202HQ 090204HQ	0.2 0.4	● ●	● ●	● ●		● ●	● ●	▲ ▲	● ●	● ●	● ●	● ●							● ●	● ●																					
	TPMT 110302HQ 110304HQ 110308HQ	0.2 0.4 0.8	● ● ●	● ● ●	● ● ●		● ● ●	● ● ●	▲ ▲ ▲	● ● ●	● ● ●	● ● ●	● ● ●							● ● ●	● ● ●																					
	TPMT 160302HQ 160304HQ 160308HQ	0.2 0.4 0.8	● ● ●	● ● ●	● ● ●		● ● ●	● ● ●	▲ ▲ ▲	● ● ●	● ● ●	● ● ●	● ● ●							● ● ●	● ● ●																					
軟質	TPMT 090204XP	0.4	●	●	●		●	●				●	●																													
	TPMT 110304XP 110308XP	0.4 0.8	● ●	● ●	● ●		● ●	● ●	▲ ▲	● ●	● ●	● ●	● ●							● ●	● ●																					
	TPMT 160304XP 160308XP	0.4 0.8	● ●	● ●	● ●		● ●	● ●	▲ ▲	● ●	● ●	● ●	● ●							● ●	● ●																					
軟質	TPMT 110304XQ 110308XQ	0.4 0.8	● ●	● ●	● ●		● ●	● ●	▲ ▲	● ●	● ●	● ●	● ●																													
	TPMT 160304XQ 160308XQ	0.4 0.8	● ●	● ●	● ●		● ●	● ●	▲ ▲	● ●	● ●	● ●	● ●							● ●	● ●																					

B80 下表参照

チップ材種  
旋削チップ  
ICBダイヤモンド  
外径  
スモールツール  
内径  
溝入れ  
突切り  
ねじ切り  
ドリル  
ソリッドツール  
ミーリング  
ツーリング  
機器  
イシオヤシマ  
部品  
技術資料  
SUKSEMIN  
索引

● : 標準在庫 ▲ : 将来、新製品に置換予定

チップの販売個数は、1ケース10個入りです