

# 旋削用チップ


「旋削用チップ」カタログの見方 **B15** 参照

(mm)

型番	IC	S	D1
TP_0902_	5.56	2.38	-
TP_1103_	6.35	3.18	-
TP_1603_	9.525	3.18	-

## 三角形60°・ポジ・穴なし

B  
旋削チップ

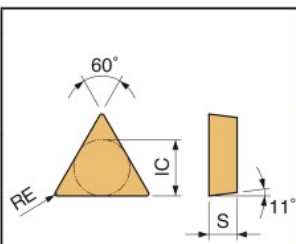

ブレード  
特長

ポジ

C

D

R

S

T

V

W

セラミック

形状	型番	寸法 (mm)		サーメット		CVDコーティング		PVDコーティング		DLC	超硬	適合ホルダ参照ページ	ブレード適用範囲
		RE	サ-メット	CVDコーティング	PVDサーメット	CVDコーティング	PVDコーティング						
仕上げ仕上げ中中切削 	TPGR 110302R-A	0.2	●	●	●	●							
	110302L-A	0.2	●	●	●	●							
	110304R-A	0.4	●	●	●	●							
	110304L-A	0.4	●	●	●	●							
	TPGR 110304R-B	0.4	●	●	●	●							
	110304L-B	0.4	●	●	●	●							
	110308R-B	0.8	●	●	●	●							
	110308L-B	0.8	●	●	●	●							
	TPGR 160302R-B	0.2	●	●	●	●							
	160302L-B	0.2	●	●	●	●							
	160304R-B	0.4	●	●	●	●							
	160304L-B	0.4	●	●	●	●							
160308R-B	0.8	●	●	●	●								
160308L-B	0.8	●	●	●	●								
TPGR 160304R-C	0.4	●	●	●	●								
160304L-C	0.4	●	●	●	●								
160308R-C	0.8	●	●	●	●								
160308L-C	0.8	●	●	●	●								
銹鉄 ブレードなし	TPGN 090202	0.2											
	090204	0.4											
	090208	0.8											
	TPGN 110302	0.2											
	110304	0.4	●	●	●	●							
	110308	0.8	●	●	●	●							
	TPGN 160304	0.4	●	●	●	●							
	160308	0.8	●	●	●	●							
	TPMN 110304	0.4											
	110308	0.8											
TPMN 160304	0.4												
160308	0.8												
160312	1.2												

ブレード適用範囲

