

# 旋削用チップ

「旋削用チップ」カタログの見方 **B15** 参照


## ■ひし形35°・ポジ・穴付き

型番	IC	S	D1
VB_1103_	6.35	3.18	2.8
VB_1604_	9.525	4.76	4.4

形状	型番	寸法 (mm)	サーメット		CVD		CVDコーティング													PVDコーティング		DLC	超硬	適合ホルダ参照ページ	ブレーカ適用範囲																	
			TN610	TN620	TN60	CCX	PV710	PV720	PV730	PV90	PV7005	CA510	CA515	CA025P	CA525	CA530	CA5505	CA5515	CA5525	CA5535	CA6515					CA6525	CA310	CA315	CA320	CA4505	CA4515	PR1705	PR1725	PR1725	PR1225	PR005S	PR015S	PR1535	PDL010	PDL025	KW10	SW05
仕上げ シャープエッジ	VBET 1103005MR-F	<0.05																																								
	1103005ML-F	<0.05																																								
	110301MR-F	<0.1	●					●	●																																	
	110301ML-F	<0.1																																								
	110302MR-F	<0.2	●	●				●	●																																	
	110302ML-F	<0.2	●	●				●	●																																	
仕上げ シャープエッジ	VBGT 1103003R-F	0.03																																								
	1103003L-F	0.03																																								
	110301R-F	0.1	●	●				●	●																																	
	110301L-F	0.1																																								
	110302R-F	0.2	●	●				●	●																																	
	110302L-F	0.2																																								
仕上げ中 シャープエッジ	VBET 1103005MR-Y	<0.05																																								
	1103005ML-Y	<0.05																																								
	110301MR-Y	<0.1																																								
	110301ML-Y	<0.1																																								
	110302MR-Y	<0.2	●	●				●	●																																	
	110302ML-Y	<0.2	●	●				●	●																																	

・ コーナR(RE)寸法が不等号(例 : <0.05, <0.1, <0.2 など)で表示されていますチップは、コーナR(RE)がマイナス公差の製品を示します。

チップ型番	適合ホルダ参照ページ
VB..1103 タイプ	E36,E37,E38,E45,F54,F56,F59
VB..1604 タイプ	E37,E38,F54,F56,F59

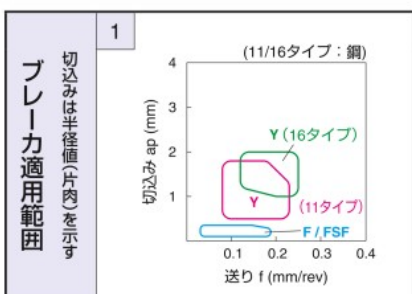

チップの販売個数は、1ケース10個入りです