

ひし形35°, ネガ, 穴付き

「旋削用インサート」カタログの見方 B15 参照

B

旋削用インサート

ブレーカ
特長

ネガ

C

D

R


S

T


V

W

セラミック

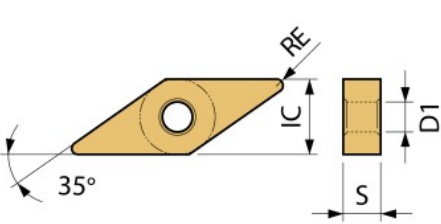			快削鋼																		P					
			炭素鋼・合金鋼																		M					
			ステンレス鋼																		K					
			ねずみ鋳鉄																		N					
			ダクタイル鋳鉄																		S					
			非鉄金属																		H					
			耐熱合金																							
			チタン合金																							
			高硬度材																							
形 状	型 番	ブ レ ー カ 適 用 範 囲	寸 法 (mm)				超 硬										サーメット				適 合 ホルダ					
			コー ナ 数	IC	S	D1	RE	CVD										CVD	PVD	-						
								CA02SP	CA11SP	CA12SP	CA310	CA315	CA320	CA4505	CA4515	CA510	CA515	CA525	CA530	CA6515		CA6525	CCX	PV7005	PV710	PV720
仕 上 げ		VNMG 160402PP 160404PP 160408PP 160412PP	1	4	9.525	4.76	3.81	0.2	●	●						○	○	●	●	●	●	●	●	●	●	D30~D39
							0.4	●	●							○	○	●	●	●	●	●	●	●	●	
							0.8	●	●							○	○	●	●	●	●	●	●	●	●	
							1.2	●	●							○	○	●	●	●	●	●	●	●	●	
仕 上 げ		VNMG 160402GP 160404GP 160408GP	1	4	9.525	4.76	3.81	0.2	●	●						○	○	●	●	●	●	●	●	●	●	
							0.4	●	●							○	○	●	●	●	●	●	●	●	●	
							0.8	●	●							○	○	●	●	●	●	●	●	●	●	
仕 上 げ 中		VNMG 160404R-VC 160404L-VC 160408R-VC 160408L-VC 160412R-VC 160412L-VC	2	4	9.525	4.76	3.81	0.4	●	●						○	○	●	●	●	●	●	●	●	●	
							0.4	●	●							○	○	●	●	●	●	●	●	●	●	
							0.8	●	●							○	○	●	●	●	●	●	●	●	●	
							0.8	●	●							○	○	●	●	●	●	●	●	●	●	
							1.2	●	●							○	○	●	●	●	●	●	●	●	●	
							1.2	●	●							○	○	●	●	●	●	●	●	●	●	
仕 上 げ 中		VNMG 160404VF 160408VF 160412VF	3	4	9.525	4.76	3.81	0.4	●	●						○	○	●	●	●	●	●	●	●	●	
							0.8	●	●							○	○	●	●	●	●	●	●	●	●	
							1.2	●	●							○	○	●	●	●	●	●	●	●	●	
仕 上 げ 中		VNMG 160404PQ 160408PQ 160412PQ	1	4	9.525	4.76	3.81	0.4	●	●						○	○	●	●	●	●	●	●	●	●	
							0.8	●	●							○	○	●	●	●	●	●	●	●	●	
							1.2	●	●							○	○	●	●	●	●	●	●	●	●	
仕 上 げ 中		VNMG 160404HQ 160408HQ 160412HQ	1	4	9.525	4.76	3.81	0.4	●	●						○	○	●	●	●	●	●	●	●	●	
							0.8	●	●							○	○	●	●	●	●	●	●	●	●	
							1.2	●	●							○	○	●	●	●	●	●	●	●	●	
中 切 削		VNMG 160404TN-V 160408TN-V 160412TN-V	3	4	9.525	4.76	3.81	0.4															●			
							0.8																●			
							1.2																●			
荒 加 工		VNMG 160404 160408	3	4	9.525	4.76	3.81	0.4	●	●	●	●	●	●	●	○	○	●	●	●	●	●	●	●	●	
							0.8	●	●	●	●	●	●	●	●	○	○	●	●	●	●	●	●	●	●	

ブレーカ適用範囲

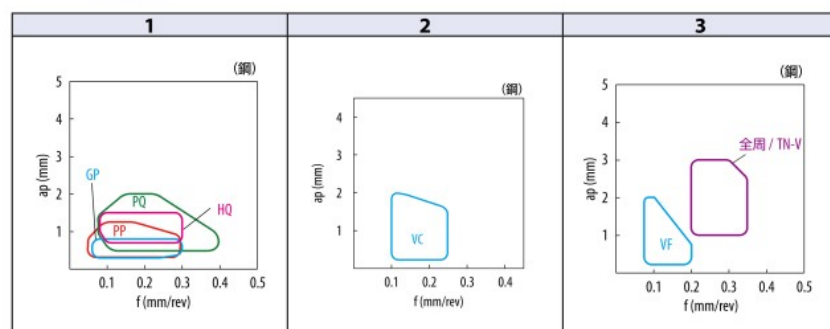

●: 標準在庫 ○: 新製品へ置換予定(在庫をご確認ください)