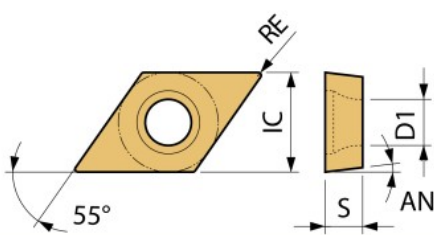


ひし形55°, ポジ, 穴付き

「旋削用インサート」カタログの見方 B15 参照

			快削鋼																						P				
			炭素鋼・合金鋼																										
			ステンレス鋼																						M				
			ねずみ鋳鉄																						K				
		ダクタイル鋳鉄																											
		非鉄金属																						N					
		耐熱合金																						S					
		チタン合金																											
		高硬度材																						H					
形 状	型 番	ブ レ ー カ 適 用 範 囲	コー ナ 数	寸法 (mm)				角度 (°)	超硬										サーメット				適 合 ホル ダ						
				IC	S	D1	RE		AN	CVD					PVD					CVD	PVD	-							
										CA025P	CA115P	CA125P	CA510	CA515	CA525	CA530	PR115S	PR120S	PR122S					PR153S	PR170S	PR172S	PR930	CCX	PV710
 鏡面仕様 / シャープエッジ	DCGT 070201MFP-GQ 070202MFP-GQ 070204MFP-GQ	B68 1	2	6.35	2.38	3	< 0.1 < 0.2 < 0.4	7									●	●	●	●	●	●	●	●	●	●	●	●	*1
	DCGT 11T301MFP-GQ 11T302MFP-GQ 11T304MFP-GQ	B68 1	2	9.525	3.97	4.7	< 0.1 < 0.2 < 0.4	7									●	●	●	●	●	●	●	●	●	●	●	●	*2
 ワイパー切れ刃付き	DCMX 070202WP 070204WP 070208WP	1	2	6.35	2.38	3	0.2 0.4 0.8	7	●	●	●	○	○	○	○	○	●		●	●	●	●	●	●	●	●	●	●	*3
	DCMX 11T302WP 11T304WP 11T308WP	1	2	9.525	3.97	4.7	0.2 0.4 0.8	7	●	●	●	○	○	○	○	○	●	●	●	●	●	●	●	●	●	●	●	●	*4
 ワイパー切れ刃付き	DCMX 070204R-WP 070204L-WP	1	2	6.35	2.38	3	0.4	7									●		●	●	●	●	●	●	●	●	●	●	*3
	DCMX 11T304R-WP 11T304L-WP	1	2	9.525	3.97	4.7	0.4	7									●		●	●	●	●	●	●	●	●	●	●	*4
 ワイパー切れ刃付き	DCMT 070202PP 070204PP	2	2	6.35	2.38	3	0.2 0.4	7	●	●	●	○	○	○	○	○	●	●	●	●	●	●	●	●	●	●	●	●	*1
	DCMT 11T302PP 11T304PP 11T308PP	2	2	9.525	3.97	4.7	0.2 0.4 0.8	7	●	●	●	○	○	○	○	○	●	●	●	●	●	●	●	●	●	●	●	●	*2
 ワイパー切れ刃付き	DCMT 070202GP 070204GP	3	2	6.35	2.38	2.8	0.2 0.4	7	●	●	●	○	○	○	○	○	●	●	●	●	●	●	●	●	●	●	●	●	*1
	DCMT 11T304GP 11T308GP	4	2	9.525	3.97	4.4	0.4 0.8	7	●	●	●	○	○	○	○	○	●	●	●	●	●	●	●	●	●	●	●	●	*2

コーナR(RE)寸法が不等号 (例: <0.05, <0.1, <0.2 など) で表示されていますインサートは、コーナR(RE)がマイナス公差の製品を示します。

WPブレカについては、R36, R37の「ワイパーインサート使用時の注意」をご参照ください。


*1: DC..07タイプ E29, E31, E34, E35, E55, E56, F66~F68, F70~F72, F74~F76, F125

*2: DC..11タイプ E23, E29~E32, E34, E35, E55, E56, F66~F68, F70~F72, F74~F76, F125

*3: DC..07タイプ WP E29, E31, E55, F66~F68, F74~F76, F125

*4: DC..11タイプ WP E23, E29~E32, E55, F66~F68, F74~F76, F125

ブレカ適用範囲

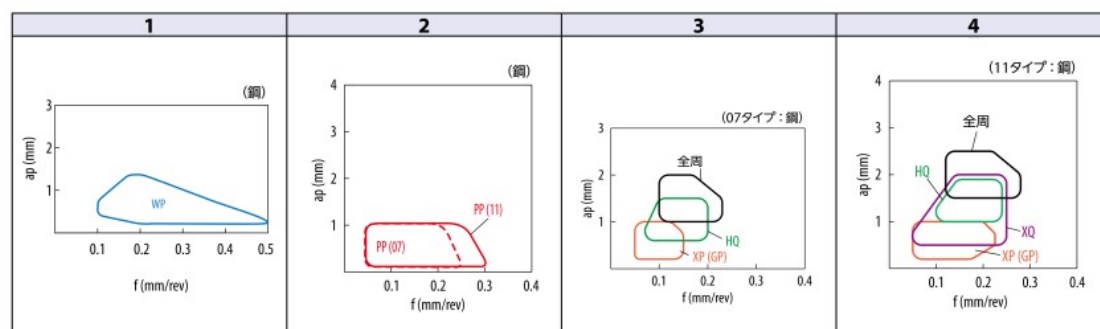

●: 標準在庫 ○: 新製品へ置換予定(在庫をご確認ください)

B



旋削用インサート