




Blind Rivet

## ブラインドリベット(アルミ/スチール製)




同商品群 在庫数 748アイテム

- 特長** ●片側から複数の母材をワン・アクションで締結できます。  
**用途** ●自動車板金、電機板金など。  
**材質** ●リベット本体(フランジ):アルミ(A5154)  
 ●マンドレル(シャフト):スチール(炭素鋼)  
**製造国** ●日本

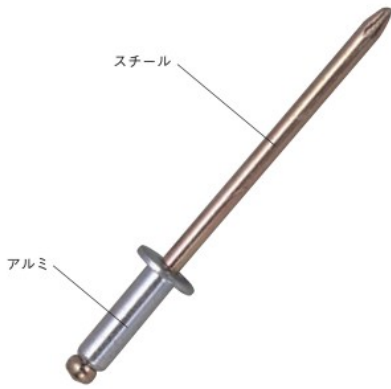

NSAタイプ

寸法図

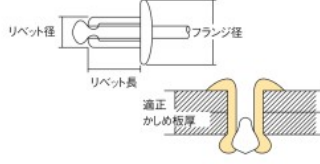

品番	フランジ径(mm)	リベット径(mm)	下穴径(mm)
NSA3	4.8	2.4	2.5~2.6
NSA4	6.4	3.2	3.3~3.4
NSA5	8.0	4.0	4.1~4.2
NSA6	9.6	4.8	4.9~5.0
NSA8	12.8	6.4	6.5~6.6

### 箱入

発注単位1箱

開口ボックス[996306]

発注コード	品番	税抜価格(1箱)	メーカー標準の規格(1箱)	かめ板厚(mm)	リベット長(mm)	せん断荷重(N)	引張荷重(N)	箱入数(本)	質量(g)	実績(前年比%)
125-8231	NSA32	¥3,894	¥4,450	1.0~3.2	5.6	480	700	1000	0.66	469(75)
125-8265	NSA33	¥4,125	¥4,710	1.6~4.8	7.6	480	700	1000	0.62	45(72)
125-8281	NSA34	¥4,194	¥4,790	3.2~6.4	9.1	480	700	1000	0.66	39(68)
125-8311	NSA41	¥3,306	¥3,780	1.0~1.6	4.8	960	1350	1000	1.07	152(108)
125-8338	NSA42	¥3,419	¥3,910	1.0~3.2	6.5	960	1350	1000	1.07	366(84)
125-8362	NSA43	¥3,556	¥4,060	1.6~4.8	8.2	960	1350	1000	1.29	513(96)
125-8397	NSA44	¥3,744	¥4,280	3.2~6.4	9.9	960	1350	1000	1.12	339(129)
125-8427	NSA45	¥4,288	¥4,900	4.8~8.0	11.6	960	1350	1000	1.29	65(60)
125-8451	NSA46	¥4,950	¥5,660	6.4~9.5	13.3	960	1350	1000	1.29	36(66)
125-8486	NSA48	¥5,550	¥6,340	9.5~12.7	16.7	960	1350	1000	1.34	33(184)
372-3941	NSA410	¥8,581	¥9,810	12.7~15.9	19.0	870	1340	1000	0.83	20(77)
372-3950	NSA412	¥9,750	¥11,140	15.9~19.1	23.0	870	1340	1000	0.84	4(400)
125-8508	NSA52	¥4,338	¥4,960	1.2~3.2	7.2	1550	2200	1000	1.98	197(73)
125-8532	NSA53	¥4,700	¥5,370	1.6~4.8	8.9	1550	2200	1000	1.79	418(83)
125-8567	NSA54	¥4,775	¥5,460	3.2~6.4	10.5	1550	2200	1000	1.68	741(108)
125-8591	NSA55	¥5,288	¥6,040	4.8~8.0	12.2	1550	2200	1000	1.71	73(45)
125-8621	NSA56	¥5,700	¥6,510	6.4~9.5	13.9	1550	2200	1000	2.28	121(79)
125-8656	NSA58	¥6,138	¥7,010	9.5~12.7	17.2	1550	2200	1000	2.28	52(109)
372-4042	NSA510	¥12,069	¥13,790	12.7~15.9	19.7	1550	2200	1000	2.50	10(33)
372-4051	NSA512	¥12,919	¥14,760	15.9~19.1	23.0	1550	2200	1000	2.57	7(70)
125-8681	NSA62	¥6,900	¥7,890	1.6~3.2	7.6	2200	3300	1000	3.27	75(105)
125-8702	NSA63	¥7,175	¥8,200	1.6~4.8	9.3	2200	3300	1000	2.85	204(136)
125-8737	NSA64	¥7,456	¥8,520	3.2~6.4	11.0	2200	3300	1000	3.27	568(38)
125-8761	NSA65	¥8,231	¥9,410	4.8~8.0	12.8	2200	3300	1000	2.93	139(110)
125-8796	NSA66	¥8,925	¥10,200	6.4~9.5	14.5	2200	3300	1000	3.88	235(124)
125-8826	NSA68	¥9,863	¥11,270	9.5~12.7	17.9	2200	3300	1000	3.88	104(117)
125-8851	NSA610	¥10,875	¥12,430	12.7~15.9	21.3	2200	3300	1000	4.02	71(89)
125-8885	NSA612	¥6,306	¥7,210	15.9~19.1	24.8	2200	3300	500	2.03	39(64)
125-8907	NSA614	¥10,475	¥11,970	19.1~22.3	28.2	2200	3300	500	2.24	21(117)
125-8923	NSA616	¥11,888	¥13,590	22.3~25.4	29.7	2200	3300	500	2.29	22(62)
372-4689	NSA82	¥14,213	¥16,240	1.6~3.2	9.2	3400	5300	500	3.62	8(800)
372-4701	NSA84	¥15,069	¥17,220	3.2~6.4	12.4	3400	5300	500	3.70	102(113)
750-8735	NSA86	¥16,213	¥18,530	6.4~9.5	15.6	3400	5300	500	3.76	94(94)
372-4735	NSA88	¥20,019	¥22,880	9.5~12.7	18.9	3400	5300	500	3.88	60(99)
372-4620	NSA810	¥23,263	¥26,590	12.7~15.9	22.1	3400	5300	500	4.38	27(208)
372-4646	NSA812	¥25,931	¥29,640	15.9~19.1	25.4	3400	5300	500	4.49	7(64)
372-4662	NSA814	¥30,706	¥35,090	19.1~22.3	28.6	3400	5300	500	4.58	2(200)

### エコパック入

発注単位1パック

発注コード	品番	税抜価格(1パック)	メーカー標準の規格(1パック)	かめ板厚(mm)	リベット長(mm)	せん断荷重(N)	引張荷重(N)	パック入数(本)	質量(g)	実績(前年比%)
202-7761	NSA32MP	¥525	¥600	1.0~3.2	5.6	480	700	80	74	34(-)
202-7746	NSA33MP	¥525	¥600	1.6~4.8	7.6	480	700	80	74	10(999)
202-7748	NSA34MP	¥525	¥600	3.2~6.4	9.1	480	700	80	74	19(-)
202-7741	NSA41MP	¥525	¥600	1.0~1.6	4.8	960	1350	80	106	6(-)
202-9270	NSA42MP	¥525	¥600	1.0~3.2	6.5	960	1350	80	106	49(817)
202-7692	NSA43MP	¥525	¥600	1.6~4.8	8.2	960	1350	80	106	65(999)
202-6200	NSA44MP	¥525	¥600	3.2~6.4	9.9	960	1350	80	114	62(-)
202-9300	NSA45MP	¥525	¥600	4.8~8.0	11.6	960	1350	75	116	30(999)
202-9304	NSA46MP	¥525	¥600	6.4~9.5	13.3	960	1350	65	104	17(850)
202-7720	NSA48MP	¥525	¥600	9.5~12.7	16.7	960	1350	55	98	15(750)
202-7739	NSA410MP	¥525	¥600	12.7~15.9	19.0	870	1340	30	74	7(175)
202-7702	NSA412MP	¥525	¥600	15.9~19.1	23.0	870	1340	30	74	6(300)
202-6189	NSA52MP	¥525	¥600	1.2~3.2	7.2	1550	2200	65	137	51(-)
202-6195	NSA53MP	¥525	¥600	1.6~4.8	8.9	1550	2200	60	134	39(-)
202-7694	NSA54MP	¥525	¥600	3.2~6.4	10.5	1550	2200	60	134	63(999)
202-7729	NSA55MP	¥525	¥600	4.8~8.0	12.2	1550	2200	50	116	22(-)
202-7764	NSA56MP	¥525	¥600	6.4~9.5	13.9	1550	2200	45	116	28(467)
202-7716	NSA58MP	¥525	¥600	9.5~12.7	17.2	1550	2200	45	121	7(-)
202-6174	NSA510MP	¥525	¥600	12.7~15.9	19.7	1550	2200	25	86	4(-)
202-7700	NSA512MP	¥525	¥600	15.9~19.1	23.0	1550	2200	25	86	9(900)
202-9288	NSA62MP	¥525	¥600	1.6~3.2	7.6	2200	3300	35	121	34(-)
202-7770	NSA63MP	¥525	¥600	1.6~4.8	9.3	2200	3300	35	124	31(194)
202-7744	NSA64MP	¥525	¥600	3.2~6.4	11.0	2200	3300	35	124	89(890)
202-9276	NSA65MP	¥525	¥600	4.8~8.0	12.8	2200	3300	35	128	20(-)
202-7743	NSA66MP	¥525	¥600	6.4~9.5	14.5	2200	3300	30	128	56(999)
202-9302	NSA68MP	¥525	¥600	9.5~12.7	17.9	2200	3300	25	114	12(400)
202-9283	NSA610MP	¥525	¥600	12.7~15.9	21.3	2200	3300	25	116	21(700)
202-7688	NSA612MP	¥525	¥600	15.9~19.1	24.8	2200	3300	20	102	13(434)
202-7774	NSA614MP	¥525	¥600	19.1~22.3	28.2	2200	3300	12	77	9(300)
202-7776	NSA616MP	¥525	¥600	22.3~25.4	29.7	2200	3300	12	77	8(200)

☆商品のお問い合わせ: 072-980-1111 <http://www.lobtex.co.jp/>