


12F31


単位重量：0.491kg/m

1:1.5

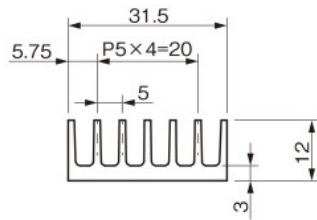

L寸	熱抵抗(°C/W)
L50	12.7
L100	7.3
L150	5.3


— L=50
— L=100
— L=150

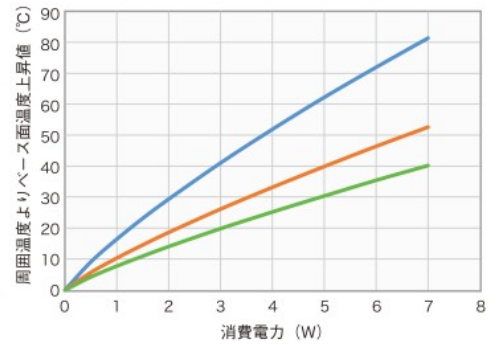

12F46


単位重量：0.715kg/m

1:1.5

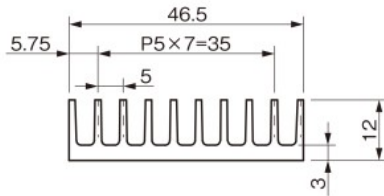

L寸	熱抵抗(°C/W)
L50	8.4
L100	5
L150	3.5


— L=50
— L=100
— L=150

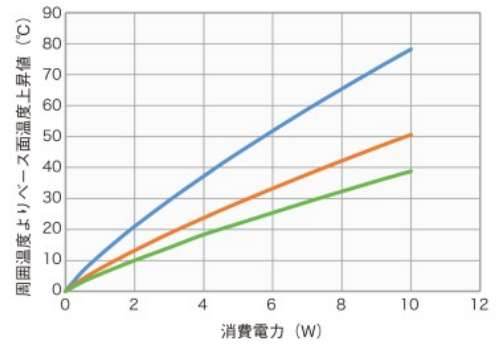

12F51


単位重量：0.789kg/m

1:1.5

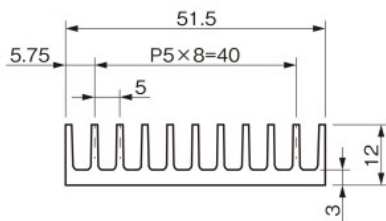

L寸	熱抵抗(°C/W)
L50	7.6
L100	4.4
L150	3.2


— L=50
— L=100
— L=150

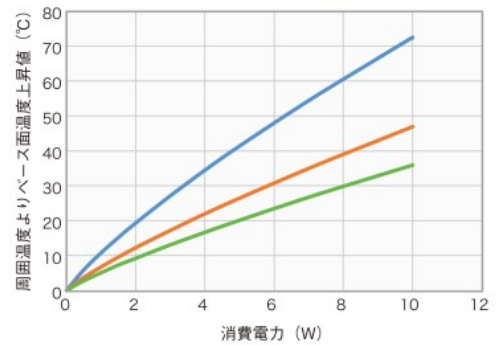

12F66

単位重量：1.012kg/m

1:1.5

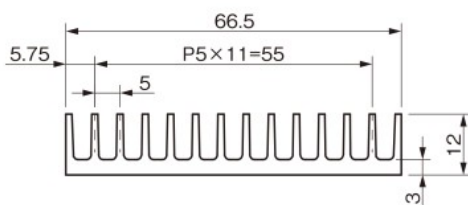

L寸	熱抵抗(°C/W)
L50	6
L100	3.5
L150	2.5

— L=50
— L=100
— L=150

