


## 12F101


単位重量：1.533kg/m

1:1.8

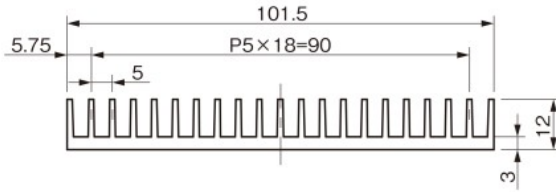

L寸	熱抵抗 (°C/W)
L50	4
L100	2.4
L150	1.7


— L=50  
— L=100  
— L=150

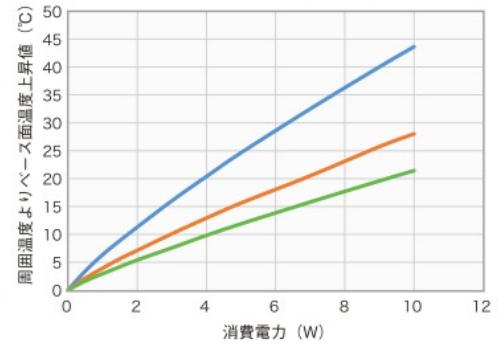

## 12F151


単位重量：2.425kg/m

1:1.8

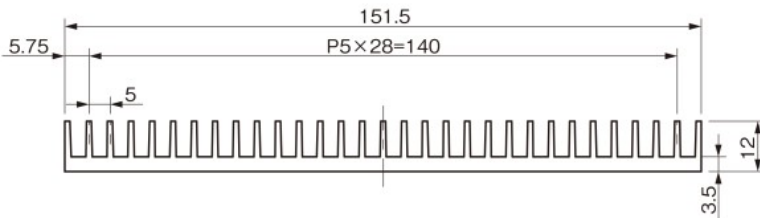

L寸	熱抵抗 (°C/W)
L50	2.8
L100	1.6
L150	1.2


— L=50  
— L=100  
— L=150

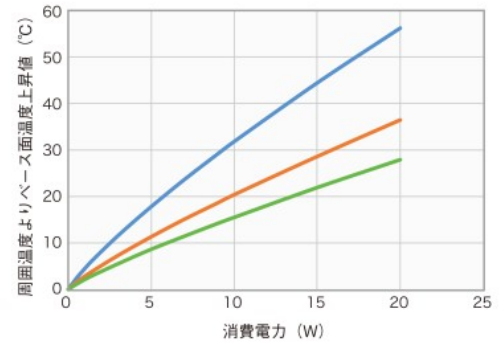

## 17F50A


単位重量：1.005kg/m

1:1.5

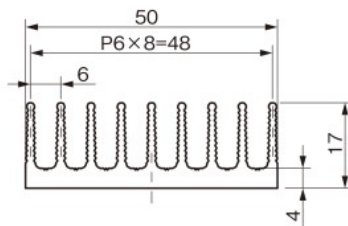

L寸	熱抵抗 (°C/W)
L50	6.8
L100	4
L150	2.9

— L=50  
— L=100  
— L=150

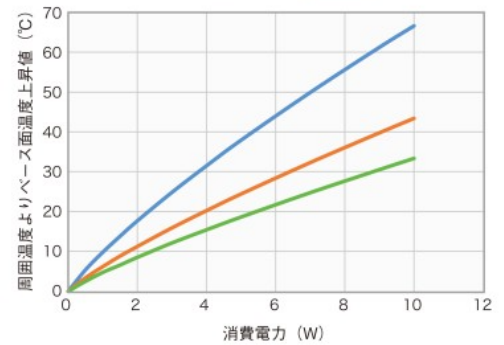


ローレット付

## 17F50B

単位重量：1.109kg/m

1:1.5

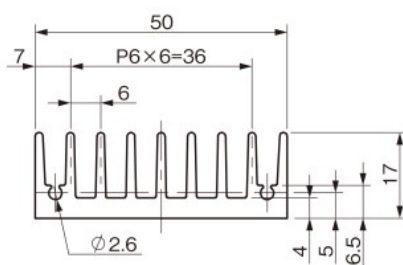

L寸	熱抵抗 (°C/W)
L50	6.8
L100	4
L150	2.9

— L=50  
— L=100  
— L=150

