


■ ネオジム磁石 Nd-Fe-B Magnet


ネオジム磁石標準品

Nd-Fe-B Magnet

丸 型

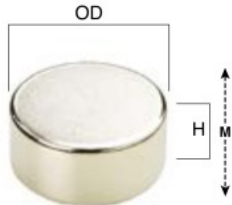

単位：mm

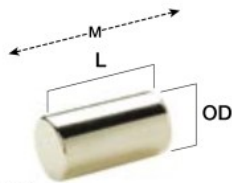

単位：mm

OD × H	表面磁束密度		吸着力		OD × H	表面磁束密度		吸着力	
	mT	kG	N	kgf		mT	kG	N	kgf
1φ × 5	150	1.5	0.49	0.05	8φ × 4	360	3.6	12.26	1.25
1) 1.2φ × 2	130	1.3	0.39	0.04	8φ × 5	400	4.0	13.73	1.4
1.4φ × 5	150	1.5	0.78	0.08	8φ × 8	420	4.2	17.65	1.8
1.5φ × 1.5	280	2.8	0.49	0.05	9φ × 3	320	3.2	11.77	1.2
1.5φ × 8	200	2.0	0.88	0.09	9φ × 10	420	4.2	21.57	2.2
2φ × 2	270	2.7	0.69	0.07	9.4φ × 0.8	150	1.5	3.92	0.4
2φ × 3	320	3.2	0.78	0.08	10φ × 2	260	2.6	12.75	1.3
2φ × 5.5	350	3.5	1.18	0.12	10φ × 3	350	3.5	19.61	2.0
2φ × 7	380	3.8	1.96	0.2	10φ × 4	380	3.8	23.54	2.4
2.3φ × 4.5	330	3.3	1.47	0.15	10φ × 5	420	4.2	25.50	2.6
2.5φ × 6	360	3.6	2.26	0.23	10φ × 10	480	4.8	35.79	3.65
3φ × 1.5	310	3.1	1.67	0.17	12φ × 1.3	200	2.0	14.22	1.45
3φ × 1.8	320	3.2	2.45	0.25	12.5φ × 1.5	200	2.0	17.65	1.8
3φ × 2	350	3.5	2.94	0.3	12.5φ × 2	200	2.0	18.63	1.9
3φ × 2.5	330	3.3	2.94	0.3	13φ × 10	480	4.8	59.82	6.1
3φ × 3	340	3.4	3.43	0.35	13φ × 20	550	5.5	93.16	9.5
3φ × 4	350	3.5	3.73	0.38	14φ × 10	450	4.5	62.76	6.4
3φ × 5	340	3.4	3.92	0.4	15φ × 1.5	180	1.8	10.79	1.1
3φ × 6	360	3.6	4.12	0.42	15φ × 1.7	200	2.0	12.75	1.3
3φ × 10	400	4.0	4.90	0.5	15φ × 3	320	3.2	36.28	3.7
4φ × 1.5	270	2.7	2.45	0.25	15φ × 4	330	3.3	39.23	4.0
4φ × 2	300	3.0	2.94	0.3	15φ × 5	330	3.3	44.13	4.5
4φ × 3	350	3.5	3.92	0.4	15φ × 10	420	4.2	66.69	6.8
4φ × 4	390	3.9	4.90	0.5	16φ × 10	420	4.2	70.61	7.2
4φ × 5	420	4.2	5.39	0.55	16φ × 30	500	5.0	147.10	15.0
4φ × 8	400	4.0	6.86	0.7	17.5φ × 20	470	4.7	166.71	17.0
5φ × 1	150	1.5	1.96	0.2	17.9φ × 2.5	270	2.7	24.52	2.5
2) 5φ × 1.5	200	2.0	2.94	0.3	19φ × 10	400	4.0	96.11	9.8
5φ × 2	320	3.2	3.43	0.35	19φ × 40	520	5.2	186.33	19.0
5φ × 3	350	3.5	4.31	0.44	20φ × 5	280	2.8	61.78	6.3
5φ × 4	380	3.8	5.49	0.56	21φ × 4.6	320	3.2	68.65	7.0
5φ × 5	400	4.0	6.37	0.65	22φ × 10	450	4.5	150.04	15.3
5φ × 8	370	3.7	7.85	0.8	22.5φ × 25	500	5.0	235.36	24.0
5φ × 10	400	4.0	8.83	0.9	23.5φ × 3.4	200	2.0	39.23	4.0
5.5φ × 1.7	210	2.1	2.94	0.3	23.5φ × 4.5	220	2.2	47.07	4.8
5.5φ × 8	390	3.9	9.81	1.0	23.5φ × 5	240	2.4	54.92	5.6
6φ × 2	220	2.2	3.92	0.4	23.5φ × 25	500	5.0	264.78	27.0
6φ × 3	290	2.9	5.88	0.6	25φ × 3.4	180	1.8	41.19	4.2
6φ × 5	350	3.5	7.35	0.75	25φ × 5	250	2.5	73.55	7.5
6φ × 10	400	4.0	10.79	1.1	25φ × 6	300	3.0	78.45	8.0
6φ × 23	500	5.0	24.52	2.5	25φ × 9.8	350	3.5	137.29	14.0
7φ × 2	300	3.0	6.86	0.7	30φ × 15	500	5.0	215.75	22.0
7φ × 3	350	3.5	7.55	0.77	32φ × 10.5	400	4.0	254.97	26.0
8φ × 1	180	1.8	4.90	0.5	40φ × 10	380	3.8	343.23	35.0
8φ × 2	220	2.2	6.37	0.65	50φ × 20	510	5.1	519.75	53.0
8φ × 3	350	3.5	10.79	1.1	100φ × 15	370	3.7	735.50	75.0

1) 金メッキ

2) 金メッキ、ニッケルメッキ両方に対応