


90° エルボ <90E>

材質：SCS13A

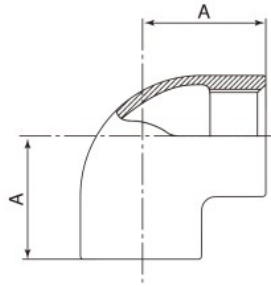


単位：mm

呼び径		中心から端面 までの距離	
(A)	(B)	A	
6	1/8	17	
8	1/4	19	
10	3/8	23	
15	1/2	27	
20	3/4	32	
25	1	38	
32	1 1/4	46	
40	1 1/2	48	
50	2	57	

45° エルボ <45E>

材質：SCS13A

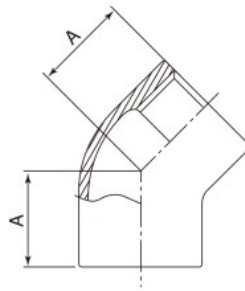


単位：mm

呼び径		中心から端面 までの距離	
(A)	(B)	A	
8	1/4	17	
10	3/8	19	
15	1/2	21	
20	3/4	25	
25	1	29	
32	1 1/4	34	
40	1 1/2	37	
50	2	42	

ストリートエルボ <SE>

材質：SCS13A

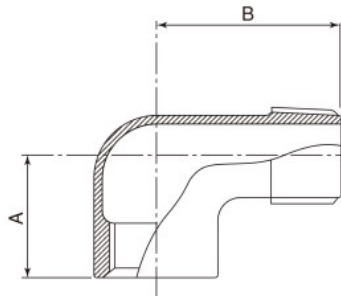


単位：mm

呼び径		中心から端面 までの距離	
(A)	(B)	A	B
8	1/4	19	30
10	3/8	23	35
15	1/2	27	40
20	3/4	32	47
25	1	38	54
32	1 1/4	46	62
40	1 1/2	48	68
50	2	57	79

異径エルボ <ER>

材質：SCS13A

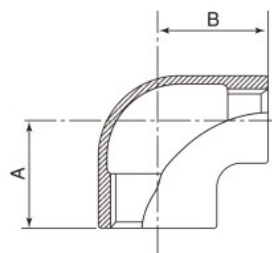

単位：mm

呼び径		中心から端面 までの距離	
(A)	(B)	A	B
8×6	1/4×1/8	18	18
10×8	3/8×1/4	20	22
15×8	1/2×1/4	24	24
15×10	1/2×3/8	26	25
20×10	3/4×3/8	28	28
20×15	3/4×1/2	29	30
25×15	1×1/2	32	33
25×20	1×3/4	34	35
32×20	1 1/4×3/4	38	40
32×25	1 1/4×1	40	42
40×25	1 1/2×1	41	45
40×32	1 1/2×1 1/4	45	48
50×25	2×1	44	51
50×32	2×1 1/4	48	54
50×40	2×1 1/2	52	55