


ティー〈T〉

材質：SCS13A

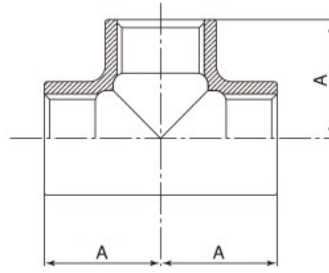


単位：mm

呼び径		中心から端面 までの距離 A
(A)	(B)	
6	1/8	17
8	1/4	19
10	3/8	23
15	1/2	27
20	3/4	32
25	1	38
32	1 1/4	46
40	1 1/2	48
50	2	57

異径ティー〈TR〉

材質：SCS13A

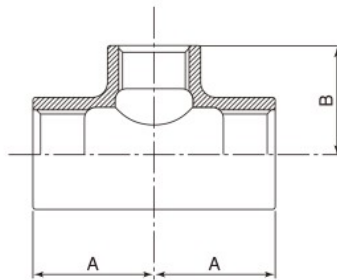


単位：mm

呼び径		中心から端面 までの距離	
(A)	(B)	A	B
8×6	1/4×1/8	18	18
10×8	3/8×1/4	20	22
15×8	1/2×1/4	24	24
15×10	1/2×3/8	26	25
20×10	3/4×3/8	28	28
20×15	3/4×1/2	29	30
25×15	1×1/2	32	33
25×20	1×3/4	34	35
32×20	1 1/4×3/4	38	40
32×25	1 1/4×1	40	42
40×20	1 1/2×3/4	38	43
40×25	1 1/2×1	41	45
40×32	1 1/2×1 1/4	45	48
50×25	2×1	44	51
50×32	2×1 1/4	48	54
50×40	2×1 1/2	52	55

クロス〈X〉

材質：SCS13A

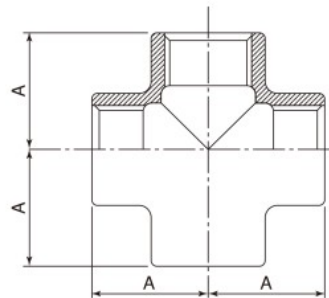


単位：mm

呼び径		中心から端面 までの距離 A
(A)	(B)	
8	1/4	19
10	3/8	23
15	1/2	27
20	3/4	32
25	1	38
32	1 1/4	46
40	1 1/2	48
50	2	57

ユニオン〈U〉

材質：SCS13A (パッキン…ノンアスベストシート)

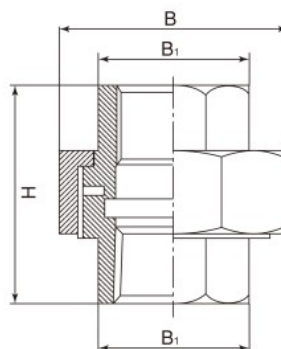

単位：mm

呼び径		高さ H	二面幅	
(A)	(B)		*B	B ₁
6	1/8	29.5	26	14
8	1/4	33.5	32	19
10	3/8	37	38	23
15	1/2	40	41	27
20	3/4	47.5	50	33
25	1	52	59	41
32	1 1/4	56.5	69	50
40	1 1/2	60	78	56
50	2	67	93	69

*B, B₁ : 1/8…六角、1/4~3/4…八角、1~2…十角