


旋削用インサート[ネガ]

**TNGG 16 04 08 R**切れ刃長 厚さ コーナR R/L
* 詳細はA002ページをご参照ください。

被削材別切りくず有効範囲

仕上げ切削..... 軽切削..... 中切削..... 荒切削..... 重切削.....

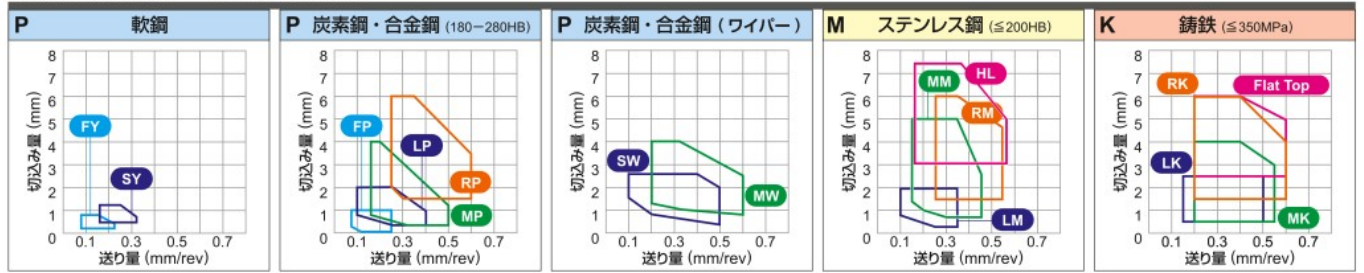

切削状態(目安) : ● : 安定切削 ● : 一般切削 ✳ : 不安定切削

被削材	呼び記号	RE (mm)	コーティング																		サーメット	コーテッドサーメット	超硬合金	参照ホルダ																		
			UE6105	UE6110	UE6020	MC6015	MC6025	MC6035	UH6400	MS6015	MC7015	MC7025	MP7035	US7020	US735	US905	MC5005	MC5015	UC5105	UC5115	MH5115	MP9005	MP9015		MP9025	VP05RT	VP10RT	VP15TF	UP20M	NX2525	NX3035	MP3025	AP25N	VP25N	HTI20T	HTI05T	HTI10	RT9010	MT9015			
R/L	TNGG160408R	0.8																									●						●									
	TNGG160408L	0.8																										●						●								
	TNGG220404R	0.4																										●						●								
	TNGG220404L	0.4																										●						●								
	TNGG220408R	0.8																										●						●								
中切削	TNGG220408L	0.8																									●						●									
	RP		●	●	●	●																																				
RP	TNMG160412-RP	1.2	●	●	●	●																																				
	TNMG220408-RP	0.8	●	●	●	●																																				
	TNMG220412-RP	1.2	●	●	●	●																																				
	TNMG220416-RP	1.6	●	●	●	●																																				
	TNMG270612-RP	1.2	●	●	●	●																																				
	TNMG270616-RP	1.6	●	●	●	●																																				
荒切削	RM							●	●	●																																
	TNMG160412-RM	1.2					●	●	●																																	
	TNMG220408-RM	0.8					●	●	●																																	
	TNMG220412-RM	1.2					●	●	●																																	
	TNMG220416-RM	1.6					●	●	●																																	
荒切削	RK														●	●																										
	TNMG160412-RK	1.2													●	●																										
	TNMG160416-RK	1.6													●	●																										
	TNMG220408-RK	0.8													●	●																										
	TNMG220412-RK	1.2													●	●																										
	TNMG220416-RK	1.6													●	●																										
荒切削	RS																		●	●																						
	TNMG160412-RS	1.2																	●	●																						
	TNMG220408-RS	0.8																	●	●																						
	TNMG220412-RS	1.2																	●	●																						
荒切削	GH		●	●	▲								▲	●					●	●																						
	TNMG160412-GH	1.2	●	●																●																						
	TNMG220408-GH	0.8	●	●	▲								●							●																						
	TNMG220412-GH	1.2	●	●	▲								●							●	●																					
	TNMG220416-GH	1.6	●	●																																						
	TNMG270612-GH	1.2	●	●	▲								●																													
TNMG270616-GH	1.6	●	●																																							

● : 標準在庫品 ▲ : 現在標準在庫品で将来新製品と置き換わる製品
(1ケース10個入りです)

● = NEW