


被削材別切りくず有効範囲

仕上げ切削..... 軽切削..... 中切削.....

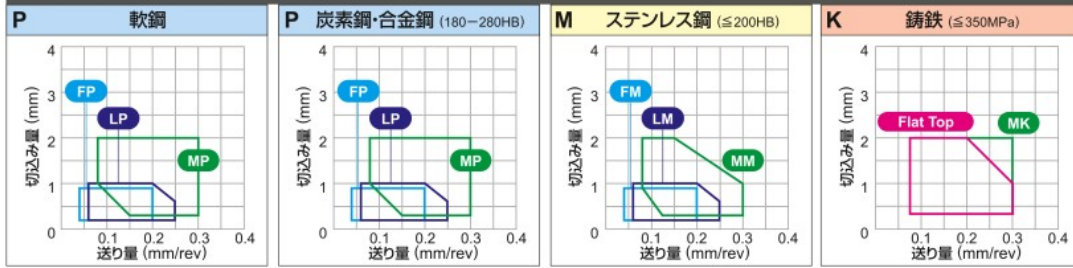

A 旋削用インサート

切削状態(目安) : ●: 安定切削 ●: 一般切削 * : 不安定切削

被削材	P 鋼	M ステンレス鋼	K 鋳鉄	N 非鉄金属	S 耐熱合金、チタン合金																																						
	●●●●●●●●	●●●●●●●●	●●●●●●●●	●●●●●●●●	●●●●●●●●																																						
	●●●●●●●●	●●●●●●●●	●●●●●●●●	●●●●●●●●	●●●●●●●●																																						
インサート 外觀	呼び記号	RE (mm)	コーティング										サーム	コーテッド サーム	超硬合金		参照 ホルダ サイズ																										
			UE6105	UE6110	UE6020	MC6015	MC6025	UH6400	MS6015	MC7025	MP7035	US7020	US735	US905	MC5005	MC5015		UC5105	UC5115	MH5115	MP9005	MP9015	VP05RT	VP10RT	VP15TF	UP20M	NX2525	NX3035	MP3025	AP25N	VP25N	VP45N	UTi20T	HTi05T	HTi10	RT9010	MT9005	TF15					
	VCMT110302-FP	0.2	●●●●●●●●																																					C028			
	VCMT110304-FP	0.4	●●●●●●●●																																					C029			
	VCMT160404-FP	0.4	●●●●●●●●																																					D011			
	VCMT160408-FP	0.8	●●●●●●●●																																					E032			
	VCMT110302-FM	0.2																																						C028			
	VCMT110304-FM	0.4																																						C029			
	VCMT160404-FM	0.4																																						D011			
	VCMT160408-FM	0.8																																						E032			
	VCMT080202-FV	0.2		▲	●																																			C028			
	VCMT080204-FV	0.4		▲	●																																			C029			
	VCMT160404-FV	0.4		●	▲																																				E011		
	VCMT160408-FV	0.8		●	▲																																				E012		
	VCGT160404-AZ	0.4																																						C028			
	VCGT160408-AZ	0.8																																						C029			
	VCGT160412-AZ	1.2																																							E032		
																																									E033		
	VCGT080202R-F	0.2																																									
	VCGT080202L-F	0.2																																									
	VCGT080204R-F	0.4																																									
	VCGT080204L-F	0.4																																									
	VCMT110304-LP	0.4		●	●																																					C028	
	VCMT110308-LP	0.8		●	●																																					C029	
	VCMT160404-LP	0.4		●	●																																					D011	
	VCMT160408-LP	0.8		●	●																																					E032	
	VCMT110304-LM	0.4								●	●																															C028	
	VCMT110308-LM	0.8								●	●																															C029	
	VCMT160404-LM	0.4								●	●																															D011	
	VCMT160408-LM	0.8								●	●																															E032	
																																										E033	

● = NEW

●: 標準在庫品 ▲: 現在標準在庫品で将来新製品と置き換わる製品
(1ケース10個入りです)