
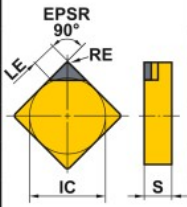

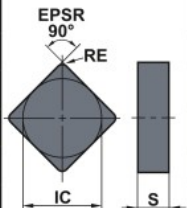


# 90° SN 穴なし 形

被削材	H	高硬度材	● ○ ◎ ☆												切削状態(目安) :									
	K	鋳鉄													●	○	◎	☆	● : 安定切削 ○ : 一般切削 ◎ : 不安定切削					
インサート 外観	呼び記号	コーテッド CBN		CBN						ソリッド CBN	寸法 (mm)				形状	対応ホルダ 参照ページ								
		BC8105	BC8110	BC8120	BC8130	MBC010	MBC020	NEW MB8110	NEW MB8120	MB8130	MB8025	MB810	MB825	MB835			NEW MB4120	MB4020	MB710	MB730	MBS140	IC	S	RE
	SNGN090304																		9.525	3.18	0.4	4.0		-
	SNGN090308																		9.525	3.18	0.8	4.1		
	SNGN120404																		12.7	4.76	0.4	4.0		
	SNGN120408																		12.7	4.76	0.8	4.1		
	SNGN120412																		12.7	4.76	1.2	4.1		
	SNGN090308																●	9.525	3.18	0.8	-		-	
	SNGN090312																●	9.525	3.18	1.2	-			
	SNGN090316																●	9.525	3.18	1.6	-			
	SNGN090408																●	9.525	4.76	0.8	-			
	SNGN090412																●	9.525	4.76	1.2	-			
	SNGN120408																●	12.7	4.76	0.8	-			
	SNGN120412																●	12.7	4.76	1.2	-			
	SNGN120416																●	12.7	4.76	1.6	-			

● = NEW

CBN

B

CBNインサート

ネガ

穴なし

C

D

R

S

T

V

W