



インサート

| 呼び記号 | 在庫 | | | | | | | 寸法(mm) | | | | | 形状 | |
|-------------|--------|---|--------|---|--------|---|--------|--------|-----|-------|------|-----|-----------|-------|
| | コーティング | | サーメット | | 超硬 | | CBN | | CW | CDX | IC | S | | RER/L |
| | VP20MF | | NX2525 | | UTi20T | | MB8025 | | | | | | | |
| | R | L | R | L | R | L | R | L | | | | | | |
| MGTR/L33125 | ● | ● | ● | | ● | ● | | 1.25 | 1.2 | 9.525 | 4.76 | 0.2 | MGTR/L... | |
| MGTR/L33145 | ● | ● | ● | | ● | ● | | 1.45 | 1.5 | 9.525 | 4.76 | 0.2 | | |
| MGTR/L33150 | ● | ● | ● | ● | ● | ● | | 1.5 | 3 | 9.525 | 4.76 | 0.2 | | |
| MGTR/L33175 | ● | ● | ● | ● | ● | ● | | 1.75 | 3 | 9.525 | 4.76 | 0.2 | | |
| MGTR/L33200 | ● | ● | ● | ● | ● | ● | | 2 | 3 | 9.525 | 4.76 | 0.2 | | |
| MGTR/L33230 | ● | ● | | | ● | ● | | 2.3 | 3 | 9.525 | 4.76 | 0.2 | | |
| MGTR/L33250 | ● | ● | ● | ● | ● | ● | | 2.5 | 3 | 9.525 | 4.76 | 0.3 | | |
| MGTR/L33270 | ● | ● | | | ● | ● | | 2.7 | 3 | 9.525 | 4.76 | 0.3 | | |
| MGTR/L33280 | ● | ● | | | ● | ● | | 2.8 | 3 | 9.525 | 4.76 | 0.3 | | |
| MGTR/L33300 | ● | ● | ● | ● | ● | ● | | 3 | 3 | 9.525 | 4.76 | 0.3 | | |
| MGTR/L33320 | ● | ● | | | ● | | | 3.2 | 3 | 9.525 | 4.76 | 0.3 | | |
| MGTR/L33330 | | ● | | | ● | ● | | 3.3 | 3 | 9.525 | 4.76 | 0.3 | | |
| MGTR/L33350 | ● | ● | ● | | ● | ● | | 3.5 | 3 | 9.525 | 4.76 | 0.3 | | |
| MGTR/L33400 | ● | ● | ● | ● | ● | ● | | 4 | 3 | 9.525 | 4.76 | 0.3 | | |
| MGTR/L43125 | ● | ● | ● | ● | ● | ● | ●* | 1.25 | 1.2 | 12.7 | 4.76 | 0.2 | | |
| MGTR/L43145 | ● | ● | | | ● | ● | | 1.45 | 1.5 | 12.7 | 4.76 | 0.2 | | |
| MGTR/L43150 | ● | ● | ● | ● | ● | ● | ●* | 1.5 | 3 | 12.7 | 4.76 | 0.2 | | |
| MGTR/L43175 | ● | ● | ● | ● | ● | ● | | 1.75 | 3 | 12.7 | 4.76 | 0.2 | | |
| MGTR/L43200 | ● | ● | ● | ● | ● | ● | ●* | 2 | 3.5 | 12.7 | 4.76 | 0.2 | | |
| MGTR/L43230 | ● | ● | ● | ● | ● | ● | | 2.3 | 3 | 12.7 | 4.76 | 0.2 | | |
| MGTR/L43250 | ● | ● | ● | ● | ● | ● | ●* | 2.5 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43260 | ● | ● | ● | | ● | ● | | 2.6 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43270 | ● | ● | | | ● | ● | | 2.7 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43280 | | ● | | ● | ● | ● | | 2.8 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43300 | ● | ● | ● | ● | ● | ● | ●* | 3 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43320 | ● | | | | ● | ● | | 3.2 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43330 | | ● | | ● | ● | ● | | 3.3 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43350 | ● | ● | ● | ● | ● | ● | ●* | 3.5 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43400 | ● | ● | ● | | ● | ● | ●* | 4 | 4.5 | 12.7 | 4.76 | 0.3 | | |
| MGTR/L43420 | ● | ● | ● | | ● | ● | | 4.2 | 4.5 | 12.7 | 4.76 | 0.4 | | |
| MGTR/L43430 | ● | ● | ● | | ● | ● | | 4.3 | 4.5 | 12.7 | 4.76 | 0.4 | | |
| MGTR/L43450 | ● | ● | ● | ● | ● | ● | | 4.5 | 4.5 | 12.7 | 4.76 | 0.4 | | |
| MGTR/L43470 | ● | ● | ● | ● | ● | ● | | 4.7 | 4.5 | 12.7 | 4.76 | 0.4 | | |
| MGTR/L44500 | ● | ● | | | ● | ● | | 5 | 4.5 | 12.7 | 6.35 | 0.4 | | |
| MGTR/L44550 | ● | | | | ● | | | 5.5 | 4.5 | 12.7 | 6.35 | 0.4 | | |
| MGTR/L44600 | ● | | | | ● | ● | | 6 | 4.5 | 12.7 | 6.35 | 0.4 | | |

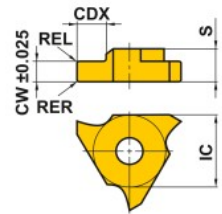

本図は右勝手(R)を示す。

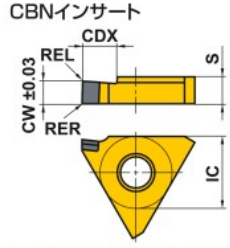

規格は右勝手(R)のみです。
*RER=0.2 REL=0.2

F

溝入れ・突切り加工