
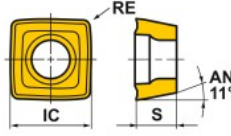

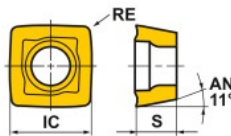


対応ドリル インサート 外觀	呼び記号	精度	コーティング				寸法 (mm)				形状
			DP8020	TF15			IC	L	S	RE	
MVX P230 	SOMX062905-UH	M	●				6	—	2.9	0.5	
	SOMX073405-UH	M	●				7	—	3.4	0.5	
	SOMX083905-UH	M	●				8.3	—	3.9	0.5	
	SOMX094406-UH	M	●				9.7	—	4.4	0.6	
	SOMX115406-UH	M	●				11.6	—	5.4	0.6	
	SOMX135908-UH	M	●				13.8	—	5.9	0.8	
	SOMX166408-UH	M	●				16.5	—	6.4	0.8	
	SOMX186908-UH	M	●				18.2	—	6.9	0.8	
MVX P230 	SOGX063005-UN	G	●				6	—	3	0.5	
	SOGX073505-UN	G	●				7	—	3.5	0.5	
	SOGX084005-UN	G	●				8.3	—	4	0.5	
	SOGX094506-UN	G	●				9.7	—	4.5	0.6	
	SOGX115506-UN	G	●				11.6	—	5.5	0.6	
	SOGX136008-UN	G	●				13.8	—	6	0.8	
	SOGX166508-UN	G	●				16.5	—	6.5	0.8	
	SOGX187008-UN	G	●				18.2	—	7	0.8	