
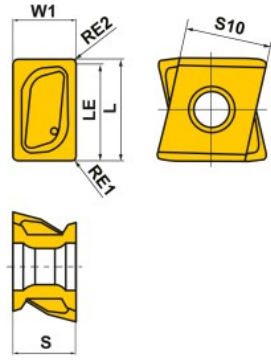




インサート

被削材	P	銅	コーティング	寸法(mm)	寸法(mm)							形状	
	K	鋳鉄			MP6120	VP15TF	L	LE	S	S10	RE1		RE2
低抵抗形 Mブレード 	LNGU130804PNER-M	R	G	E	●	13.0	12.2	8.0	11.0	0.4	0.8	8.0	
	LNGU130804PNEL-M	L	G	E	●	13.0	12.2	8.0	11.0	0.4	0.8	8.0	
	LNGU130808PNER-M	R	G	E	●	13.0	12.2	8.0	11.0	0.8	0.8	8.0	
	LNGU130808PNEL-M	L	G	E	●	13.0	12.2	8.0	11.0	0.8	0.8	8.0	
	LNGU130812PNER-M	R	G	E	●	13.0	12.2	8.0	11.0	1.2	0.8	8.0	
	LNGU130812PNEL-M	L	G	E	●	13.0	12.2	8.0	11.0	1.2	0.8	8.0	
	LNGU130816PNER-M	R	G	E	●	13.0	12.2	8.0	11.0	1.6	0.8	8.0	
	LNGU130816PNEL-M	L	G	E	●	13.0	12.2	8.0	11.0	1.6	0.8	8.0	
	LNGU130820PNER-M	R	G	E	●	13.0	12.2	8.0	11.0	2.0	0.8	8.0	
	LNGU130820PNEL-M	L	G	E	●	13.0	12.2	8.0	11.0	2.0	0.8	8.0	
	LNGU130824PNER-M	R	G	E	●	13.0	12.2	8.0	11.0	2.4	0.8	8.0	
	LNGU130824PNEL-M	L	G	E	●	13.0	12.2	8.0	11.0	2.4	0.8	8.0	
	LNGU130830PNER-M	R	G	E	●	13.0	11.4	8.0	11.0	3.0	1.6	8.0	
	LNGU130830PNEL-M	L	G	E	●	13.0	11.4	8.0	11.0	3.0	1.6	8.0	
	LNGU130840PNER-M	R	G	E	●	13.0	11.4	8.0	11.0	4.0	1.6	8.0	
	LNGU130840PNEL-M	L	G	E	●	13.0	11.4	8.0	11.0	4.0	1.6	8.0	
	LNGU130850PNER-M	R	G	E	●	13.0	11.4	8.0	11.0	5.0	1.6	8.0	
	LNGU130850PNEL-M	L	G	E	●	13.0	11.4	8.0	11.0	5.0	1.6	8.0	
刃先強化形 Rブレード NEW 	LNGU130804PNER-R	R	G	E	●●	13.0	12.2	8.0	11.0	0.4	0.8	8.0	
	LNGU130804PNEL-R	L	G	E	●●	13.0	12.2	8.0	11.0	0.4	0.8	8.0	
	LNGU130808PNER-R	R	G	E	●●	13.0	12.2	8.0	11.0	0.8	0.8	8.0	
	LNGU130808PNEL-R	L	G	E	●●	13.0	12.2	8.0	11.0	0.8	0.8	8.0	
	LNGU130812PNER-R	R	G	E	●●	13.0	12.2	8.0	11.0	1.2	0.8	8.0	
	LNGU130812PNEL-R	L	G	E	●●	13.0	12.2	8.0	11.0	1.2	0.8	8.0	
	LNGU130816PNER-R	R	G	E	●●	13.0	12.2	8.0	11.0	1.6	0.8	8.0	
	LNGU130816PNEL-R	L	G	E	●●	13.0	12.2	8.0	11.0	1.6	0.8	8.0	
	LNGU130820PNER-R	R	G	E	●●	13.0	12.2	8.0	11.0	2.0	0.8	8.0	
	LNGU130820PNEL-R	L	G	E	●●	13.0	12.2	8.0	11.0	2.0	0.8	8.0	
	LNGU130824PNER-R	R	G	E	●●	13.0	12.2	8.0	11.0	2.4	0.8	8.0	
	LNGU130824PNEL-R	L	G	E	●●	13.0	12.2	8.0	11.0	2.4	0.8	8.0	
	LNGU130830PNER-R	R	G	E	●●	13.0	11.4	8.0	11.0	3.0	1.6	8.0	
	LNGU130830PNEL-R	L	G	E	●●	13.0	11.4	8.0	11.0	3.0	1.6	8.0	
	LNGU130840PNER-R	R	G	E	●●	13.0	11.4	8.0	11.0	4.0	1.6	8.0	
	LNGU130840PNEL-R	L	G	E	●●	13.0	11.4	8.0	11.0	4.0	1.6	8.0	
	LNGU130850PNER-R	R	G	E	●●	13.0	11.4	8.0	11.0	5.0	1.6	8.0	
	LNGU130850PNEL-R	L	G	E	●●	13.0	11.4	8.0	11.0	5.0	1.6	8.0	

本図は右勝手(R)を示す。

M
カッタ

●：標準在庫品(インサートは、1ケース 10 個入りです)