
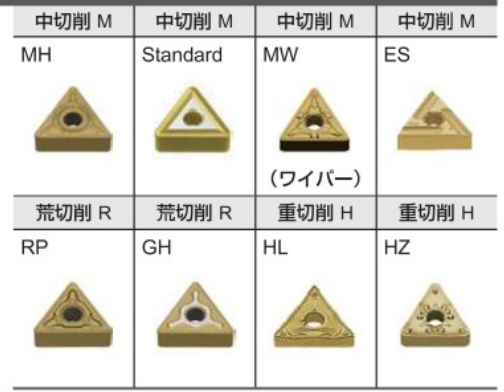


MC6100シリーズ

ネガティブインサート(穴つき)

M級精度

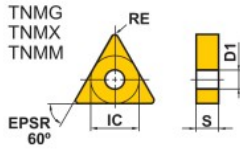

(mm)

呼び記号	切削領域	NEW			IC	S	RE	D1
		MC6115	MC6125	MC6135				
TNMG160404-MH	M	●	●	○	9.525	4.76	0.4	3.81
TNMG160408-MH	M	●	●	●	9.525	4.76	0.8	3.81
TNMG160412-MH	M	●	●	●	9.525	4.76	1.2	3.81
TNMG220408-MH	M	●	●	●	12.7	4.76	0.8	5.16
TNMG220412-MH	M	●	●	●	12.7	4.76	1.2	5.16
TNMG110304	M	●	○	○	6.35	4.76	0.4	2.26
TNMG110308	M	●	○	○	6.35	4.76	0.8	2.26
TNMG160304	M	●	○	●	9.525	3.18	0.4	3.81
TNMG160308	M	●	○	●	9.525	3.18	0.8	3.81
TNMG160404	M	●	●	●	9.525	4.76	0.4	3.81
TNMG160408	M	●	●	●	9.525	4.76	0.8	3.81
TNMG160412	M	●	●	●	9.525	4.76	1.2	3.81
TNMG160416	M	●	○	●	9.525	4.76	1.6	3.81
TNMG220404	M	●	●	●	12.7	4.76	0.4	5.16
TNMG220408	M	●	●	●	12.7	4.76	0.8	5.16
TNMG220412	M	●	●	●	12.7	4.76	1.2	5.16
TNMG220416	M	●	○	●	12.7	4.76	1.6	5.16
TNMG270608	M	●	○	●	15.875	6.35	0.8	6.35
TNMG270612	M	●	○	●	15.875	6.35	1.2	6.35
TNMG270616	M	●	○	○	15.875	6.35	1.6	6.35
TNMX160408-MW	M	●	○		9.525	4.76	0.8	3.81
TNMX160412-MW	M	●	○		9.525	4.76	1.2	3.81
TNMG160404R-ES	M	●	○		9.525	4.76	0.4	3.81
TNMG160404L-ES	M	●	○		9.525	4.76	0.4	3.81
TNMG160408R-ES	M	●	○		9.525	4.76	0.8	3.81
TNMG160408L-ES	M	●	○		9.525	4.76	0.8	3.81
TNMG220408R-ES	M	●	○		12.7	4.76	0.8	5.16
TNMG220408L-ES	M	●	○		12.7	4.76	0.8	5.16

呼び記号	切削領域	NEW			IC	S	RE	D1
		MC6115	MC6125	MC6135				
TNMG160408-RP	R	●	●	●	9.525	4.76	0.8	3.81
TNMG160412-RP	R	●	●	●	9.525	4.76	1.2	3.81
TNMG220408-RP	R	●	●	●	12.7	4.76	0.8	5.16
TNMG220412-RP	R	●	●	●	12.7	4.76	1.2	5.16
TNMG220416-RP	R	●	●	●	12.7	4.76	1.6	5.16
TNMG270612-RP	R	●	●	●	15.875	6.35	1.2	6.35
TNMG270616-RP	R	●	●	●	15.875	6.35	1.6	6.35
TNMG160408-GH	R	●	●	○	9.525	4.76	0.8	3.81
TNMG160412-GH	R	●	●		9.525	4.76	1.2	3.81
TNMG220408-GH	R	●	●	○	12.7	4.76	0.8	5.16
TNMG220412-GH	R	●	●	○	12.7	4.76	1.2	5.16
TNMG220416-GH	R	●	●		12.7	4.76	1.6	5.16
TNMG270612-GH	R	●	●	○	15.875	6.35	1.2	6.35
TNMG270616-GH	R	●	●		15.875	6.35	1.6	6.35
TNMM160408-HL	H		○	●	9.525	4.76	0.8	3.81
TNMM160412-HL	H		○	●	9.525	4.76	1.2	3.81
TNMM220408-HL	H		○	●	12.7	4.76	0.8	5.16
TNMM220412-HL	H		○	●	12.7	4.76	1.2	5.16
TNMM220416-HL	H		○	●	12.7	4.76	1.6	5.16
TNMM160408-HZ	H	●	○	●	9.525	4.76	0.8	3.81
TNMM160412-HZ	H		○	●	9.525	4.76	1.2	3.81
TNMM220408-HZ	H	●	○	○	12.7	4.76	0.8	5.16
TNMM220412-HZ	H	●	○	○	12.7	4.76	1.2	5.16
TNMM220416-HZ	H	●	○	○	12.7	4.76	1.6	5.16

● = NEW