
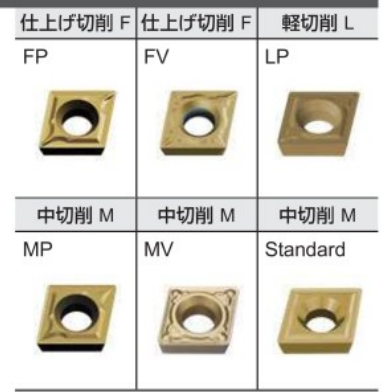


MC6100シリーズ

11°ポジティブインサート(穴つき)

M級精度

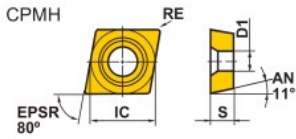

(mm)

| 呼び記号 | 切削領域 | NEW | | | IC | S | RE | D1 |
|---------------|------|--------|--------|--------|-------|------|-----|-----|
| | | MC6115 | MC6125 | MC6135 | | | | |
| CPMH080202-FP | F | ○ | ○ | ○ | 7.94 | 2.38 | 0.2 | 3.5 |
| CPMH080204-FP | F | ○ | ○ | ○ | 7.94 | 2.38 | 0.4 | 3.5 |
| CPMH090302-FP | F | ○ | ○ | ○ | 9.525 | 3.18 | 0.2 | 4.5 |
| CPMH090304-FP | F | ○ | ○ | ○ | 9.525 | 3.18 | 0.4 | 4.5 |
| CPMH090308-FP | F | ○ | ○ | ○ | 9.525 | 3.18 | 0.8 | 4.5 |
| CPMH080202-FV | F | ● | ○ | ○ | 7.94 | 2.38 | 0.2 | 3.5 |
| CPMH080204-FV | F | ● | ○ | ○ | 7.94 | 2.38 | 0.4 | 3.5 |
| CPMH090302-FV | F | ● | ○ | ○ | 9.525 | 3.18 | 0.2 | 4.5 |
| CPMH090304-FV | F | ● | ○ | ○ | 9.525 | 3.18 | 0.4 | 4.5 |
| CPMH090308-FV | F | ● | ○ | ○ | 9.525 | 3.18 | 0.8 | 4.5 |
| CPMH080202-LP | L | ● | ○ | ○ | 7.94 | 2.38 | 0.2 | 3.5 |
| CPMH080204-LP | L | ● | ○ | ○ | 7.94 | 2.38 | 0.4 | 3.5 |
| CPMH080208-LP | L | ● | ○ | ○ | 7.94 | 2.38 | 0.8 | 3.5 |
| CPMH090302-LP | L | ● | ○ | ○ | 9.525 | 3.18 | 0.2 | 4.5 |
| CPMH090304-LP | L | ● | ○ | ○ | 9.525 | 3.18 | 0.4 | 4.5 |
| CPMH090308-LP | L | ● | ○ | ○ | 9.525 | 3.18 | 0.8 | 4.5 |

| 呼び記号 | 切削領域 | NEW | | | IC | S | RE | D1 |
|---------------|------|--------|--------|--------|-------|------|-----|-----|
| | | MC6115 | MC6125 | MC6135 | | | | |
| CPMH080204-MP | M | ● | ○ | ○ | 7.94 | 2.38 | 0.4 | 3.5 |
| CPMH080208-MP | M | ● | ○ | ○ | 7.94 | 2.38 | 0.8 | 3.5 |
| CPMH090304-MP | M | ● | ○ | ○ | 9.525 | 3.18 | 0.4 | 4.5 |
| CPMH090308-MP | M | ● | ○ | ○ | 9.525 | 3.18 | 0.8 | 4.5 |
| CPMH080204-MV | M | ● | ○ | ○ | 7.94 | 2.38 | 0.4 | 3.5 |
| CPMH080208-MV | M | ● | ○ | ○ | 7.94 | 2.38 | 0.8 | 3.5 |
| CPMH090304-MV | M | ● | ○ | ○ | 9.525 | 3.18 | 0.4 | 4.5 |
| CPMH090308-MV | M | ● | ○ | ○ | 9.525 | 3.18 | 0.8 | 4.5 |
| CPMH080204 | M | ● | ● | ○ | 7.94 | 2.38 | 0.4 | 3.5 |
| CPMH080208 | M | ● | ● | ○ | 7.94 | 2.38 | 0.8 | 3.5 |
| CPMH090304 | M | ● | ● | ○ | 9.525 | 3.18 | 0.4 | 4.5 |
| CPMH090308 | M | ● | ● | ○ | 9.525 | 3.18 | 0.8 | 4.5 |

● = NEW

●: 標準在庫品

(インサートは、1ケース 10個入りです)