


インサート

呼び記号	勝手	コーティング		超硬		インサート寸法 (mm)					形状	
		NEW MS7025	VP15TF	VP15KZ	NEW MT2015	TF15	CW	CDX	RER/L	IC		S
GTAT03306V3R-E	R	●					0.33	0.27	0.03	9.525	3.18	Eプレーカ(リング溝入れ用)
GTAT03306V3L-E	L	●					0.33	0.27	0.03	9.525	3.18	
GTAT04312V3R-E	R	●					0.43	0.9	0.03	9.525	3.18	
GTAT04312V3L-E	L	●					0.43	0.9	0.03	9.525	3.18	
GTAT05312V5R-E	R	●					0.53	0.9	0.05	9.525	3.18	
GTAT05312V5L-E	L	●					0.53	0.9	0.05	9.525	3.18	
GTAT07520V5R-E	R	●					0.75	1.8	0.05	9.525	3.18	
GTAT07520V5L-E	L	●					0.75	1.8	0.05	9.525	3.18	
GTAT09520V5R-E	R	●					0.95	1.8	0.05	9.525	3.18	
GTAT09520V5L-E	L	●					0.95	1.8	0.05	9.525	3.18	
GTAT10020V5R-E	R	●					1.00	1.8	0.05	9.525	3.18	
GTAT10020V5L-E	L	●					1.00	1.8	0.05	9.525	3.18	
GTAT1002001R-E	R	●					1.00	1.8	0.1	9.525	3.18	
GTAT1002001L-E	L	●					1.00	1.8	0.1	9.525	3.18	
GTAT12020V5R-E	R	●					1.20	1.8	0.05	9.525	3.18	
GTAT12020V5L-E	L	●					1.20	1.8	0.05	9.525	3.18	
GTAT1202001R-E	R	●					1.20	1.8	0.1	9.525	3.18	
GTAT1202001L-E	L	●					1.20	1.8	0.1	9.525	3.18	
GTAT14020V5R-E	R	●					1.40	1.8	0.05	9.525	3.18	
GTAT14020V5L-E	L	●					1.40	1.8	0.05	9.525	3.18	
NEW GTBT14530V5R-E	R	●			●		1.45	2.8	0.05	9.525	3.18	
NEW GTBT14530V5L-E	L	●			●		1.45	2.8	0.05	9.525	3.18	
GTBT15030V5R-E	R	●	●		●		1.50	2.8	0.05	9.525	3.18	
GTBT15030V5L-E	L	●	●		●		1.50	2.8	0.05	9.525	3.18	
GTBT1503001R-E	R	●	●				1.50	2.8	0.1	9.525	3.18	
GTBT1503001L-E	L	●	●				1.50	2.8	0.1	9.525	3.18	
NEW GTBT17030V5R-E	R	●			●		1.70	2.8	0.05	9.525	3.18	
NEW GTBT17030V5L-E	L	●			●		1.70	2.8	0.05	9.525	3.18	
NEW GTBT17530V5R-E	R	●			●		1.75	2.8	0.05	9.525	3.18	
NEW GTBT17530V5L-E	L	●			●		1.75	2.8	0.05	9.525	3.18	
GTBT18030V5R-E	R	●	●		●		1.80	2.8	0.05	9.525	3.18	
GTBT18030V5L-E	L	●	●		●		1.80	2.8	0.05	9.525	3.18	
GTBT20030V5R-E	R	●	●		●		2.00	2.8	0.05	9.525	3.18	
GTBT20030V5L-E	L	●	●		●		2.00	2.8	0.05	9.525	3.18	
GTBT2003001R-E	R	●	●				2.00	2.8	0.1	9.525	3.18	
GTBT2003001L-E	L	●	●				2.00	2.8	0.1	9.525	3.18	
GTBT22530V5R-E	R	●	●		●		2.25	2.8	0.05	9.525	3.18	
GTBT22530V5L-E	L	●	●		●		2.25	2.8	0.05	9.525	3.18	
NEW GTBT2253001R-E	R	●					2.25	2.8	0.1	9.525	3.18	
NEW GTBT2253001L-E	L	●					2.25	2.8	0.1	9.525	3.18	
GTCT25030V5R-E	R	●	●		●		2.50	2.8	0.05	9.525	3.18	
GTCT25030V5L-E	L	●	●		●		2.50	2.8	0.05	9.525	3.18	
NEW GTCT2503001R-E	R	●					2.50	2.8	0.1	9.525	3.18	
NEW GTCT2503001L-E	L	●					2.50	2.8	0.1	9.525	3.18	
GTCT27530V5R-E	R	●	●		●		2.75	2.8	0.05	9.525	3.18	
GTCT27530V5L-E	L	●	●		●		2.75	2.8	0.05	9.525	3.18	
GTCT30030V5R-E	R	●	●		●		3.00	2.8	0.05	9.525	3.18	
GTCT30030V5L-E	L	●	●		●		3.00	2.8	0.05	9.525	3.18	
NEW GTCT3003001R-E	R	●					3.00	2.8	0.1	9.525	3.18	
NEW GTCT3003001L-E	L	●					3.00	2.8	0.1	9.525	3.18	

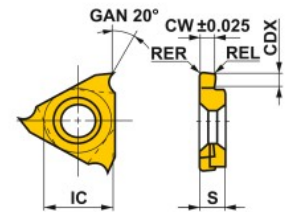

本図は右勝手(R)を示す。

* CDXは加工径 φ42以下を想定した数値です。
使用ホルダにより最大加工深さが制限されますのでご注意ください。