


ステッキツイン

CG

(内径溝加工用)

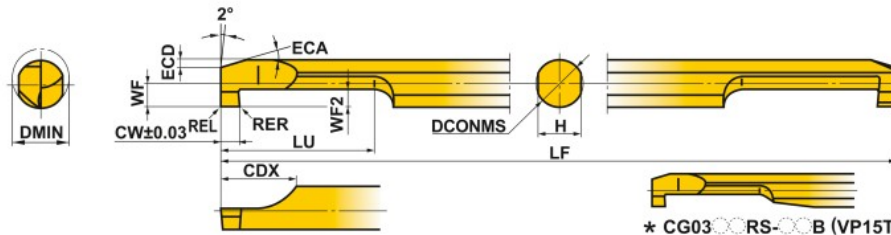

呼び記号	在庫				ブレード	DMIN	寸法 (mm)										
	コーティング		超硬				CW	WF2	RER/L	DCONMS	LF	LU	CDX	WF	H	ECA	ECD
	NEW	NEW	VP15TF	TF15													
MS7025	MS9025																
CG0305RS-10			●	●	なし	3	1	1.0	0.05	3	50	5	6	1.3	2.7	15°	0.3
CG0305RS-10B	●	●	●	●	付き	3	1	1.0	0.05	3	50	5	6	1.3	2.7	15°	0.3
CG0306RS-20			●	●	なし	3	2	1.0	0.1	3	50	6	6	1.3	2.7	15°	0.3
CG0306RS-20B	●	●	●	●	付き	3	2	1.0	0.1	3	50	6	6	1.3	2.7	15°	0.3
CG03RS-10			●	●	なし	3	1	1.0	0.05	3	50	10	6	1.3	2.7	15°	0.3
CG03RS-10B	●	●	●	●	付き	3	1	1.0	0.05	3	50	10	6	1.3	2.7	15°	0.3
CG03RS-20			●	●	なし	3	2	1.0	0.1	3	50	11	6	1.3	2.7	15°	0.3
CG03RS-20B	●	●	●	●	付き	3	2	1.0	0.1	3	50	11	6	1.3	2.7	15°	0.3
CG0407RS-10			●	●	なし	4	1	1.5	0.05	4	60	7	7	1.8	3.6	15°	0.5
CG0407RS-10B	●	●	●	●	付き	4	1	1.5	0.05	4	60	7	7	1.8	3.6	15°	0.5
CG0408RS-20			●	●	なし	4	2	1.5	0.1	4	60	8	7	1.8	3.6	15°	0.5
CG0408RS-20B	●	●	●	●	付き	4	2	1.5	0.1	4	60	8	7	1.8	3.6	15°	0.5
CG04RS-10			●	●	なし	4	1	1.5	0.05	4	60	15	7	1.8	3.6	15°	0.5
CG04RS-10B	●	●	●	●	付き	4	1	1.5	0.05	4	60	15	7	1.8	3.6	15°	0.5
CG04RS-20			●	●	なし	4	2	1.5	0.1	4	60	16	7	1.8	3.6	15°	0.5
CG04RS-20B	●	●	●	●	付き	4	2	1.5	0.1	4	60	16	7	1.8	3.6	15°	0.5
CG0510RS-10			●	●	なし	5	1	2.0	0.05	5	70	10	8	2.3	4.5	15°	0.7
CG0510RS-10B	●	●	●	●	付き	5	1	2.0	0.05	5	70	10	8	2.3	4.5	15°	0.7
CG0511RS-20			●	●	なし	5	2	2.0	0.1	5	70	11	8	2.3	4.5	15°	0.7
CG0511RS-20B	●	●	●	●	付き	5	2	2.0	0.1	5	70	11	8	2.3	4.5	15°	0.7
CG05RS-10			●	●	なし	5	1	2.0	0.05	5	70	20	8	2.3	4.5	15°	0.7
CG05RS-10B	●	●	●	●	付き	5	1	2.0	0.05	5	70	20	8	2.3	4.5	15°	0.7
CG05RS-20			●	●	なし	5	2	2.0	0.1	5	70	21	8	2.3	4.5	15°	0.7
CG05RS-20B	●	●	●	●	付き	5	2	2.0	0.1	5	70	21	8	2.3	4.5	15°	0.7
CG0610RS-10			●	●	なし	6	1	2.0	0.05	6	75	10	8	2.8	5.4	15°	0.7
CG0610RS-10B	●	●	●	●	付き	6	1	2.0	0.05	6	75	10	8	2.8	5.4	15°	0.7
CG0611RS-20			●	●	なし	6	2	2.0	0.1	6	75	11	8	2.8	5.4	15°	0.7
CG0611RS-20B	●	●	●	●	付き	6	2	2.0	0.1	6	75	11	8	2.8	5.4	15°	0.7
CG06RS-10			●	●	なし	6	1	2.0	0.05	6	75	20	8	2.8	5.4	15°	0.7
CG06RS-10B	●	●	●	●	付き	6	1	2.0	0.05	6	75	20	8	2.8	5.4	15°	0.7
CG06RS-20			●	●	なし	6	2	2.0	0.1	6	75	21	8	2.8	5.4	15°	0.7
CG06RS-20B	●	●	●	●	付き	6	2	2.0	0.1	6	75	21	8	2.8	5.4	15°	0.7
CG0712RS-10			●	●	なし	7	1	2.0	0.05	7	85	12	8	3.3	6.4	15°	0.7
CG0712RS-10B	●	●	●	●	付き	7	1	2.0	0.05	7	85	12	8	3.3	6.4	15°	0.7
CG0713RS-20			●	●	なし	7	2	2.0	0.1	7	85	13	8	3.3	6.4	15°	0.7
CG0713RS-20B	●	●	●	●	付き	7	2	2.0	0.1	7	85	13	8	3.3	6.4	15°	0.7
CG07RS-10			●	●	なし	7	1	2.0	0.05	7	85	25	8	3.3	6.4	15°	0.7
CG07RS-10B	●	●	●	●	付き	7	1	2.0	0.05	7	85	25	8	3.3	6.4	15°	0.7
CG07RS-20			●	●	なし	7	2	2.0	0.1	7	85	26	8	3.3	6.4	15°	0.7
CG07RS-20B	●	●	●	●	付き	7	2	2.0	0.1	7	85	26	8	3.3	6.4	15°	0.7

最大溝入れ深さは、WF2-0.1 mmにて算出してください。

●：標準在庫品

(ステッキツインは、1ケース 1 個入りです)