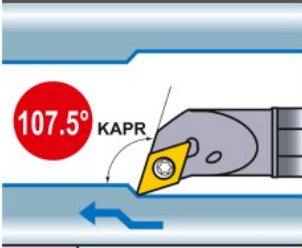
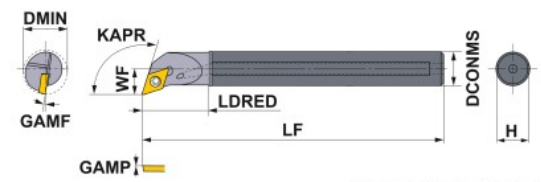
 
 
 


C-SDQC-C				(クランク穴あり超長シャンク) DC〇〇インサート対応							仕上げ		仕上げ		軽切削		軽切削	
				 本図は右勝手(R)を示す。							FS		FS-P		LS		LS-P	
																		
											(07,11)		(07,11)		(07,11)		(07,11)	
											中切削		中切削		中切削		ブレーカなし	
											MP		MM		Standard			
																		
										(07,11)		(07,11)		(07,11)		(07,11)		
DMIN	呼 び 記 号	勝手	在庫	DCONMS	LF	LDRED	WF	H	GAMF	GAMP	対応インサート							
13	C13-10SDQCR07-140-C	R	●	10	140	18	7.5	9	10°	0°	DC〇〇	0702〇〇						
13	C13-10SDQCL07-140-C	L	●	10	140	18	7.5	9	10°	0°		0702〇〇						
16	C16-12SDQCR07-140-C	R	●	12	140	23	9.25	11	8°	0°		0702〇〇						
16	C16-12SDQCL07-140-C	L	●	12	140	23	9.25	11	8°	0°		0702〇〇						
20	C20-16SDQCR07-180-C	R	●	16	180	28	11.3	15	6°	0°		0702〇〇						
20	C20-16SDQCL07-180-C	L	●	16	180	28	11.3	15	6°	0°		0702〇〇						
23	C23-16SDQCR07-180-C	R	●	16	180	28	12.8	15	5°	0°		0702〇〇						
23	C23-16SDQCL07-180-C	L	●	16	180	28	12.8	15	5°	0°		0702〇〇						
25	C25-20SDQCR11-180-C	R	●	20	180	32	14.4	19	5°	0°		11T3〇〇						
25	C25-20SDQCL11-180-C	L	●	20	180	32	14.4	19	5°	0°		11T3〇〇						
30	C30-25SDQCR11-180-C	R	●	25	180	38	16.9	24	4°	0°		11T3〇〇						
30	C30-25SDQCL11-180-C	L	●	25	180	38	16.9	24	4°	0°		11T3〇〇						

付属部品

ボーリングバータイプ	*	
		
	クランプねじ	レンチ
C〇〇-〇〇SDQCR/L07	TS25	TKY08F
C〇〇-〇〇SDQCR/L11	TS4	TKY15F

* 締付けトルク(N・m) : TS25=1.0, TS4=3.5