



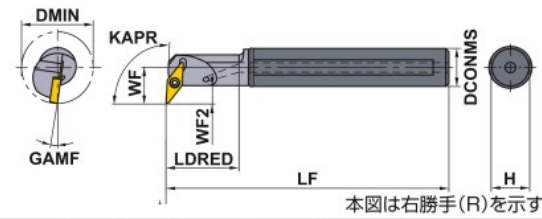

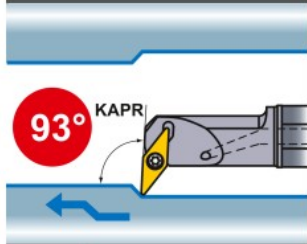





# C-SVUC/B-C

(クーラント穴あり超長シャンク)

VC/VB $\circ\circ$ インサート対応





本図は右勝手(R)を示す。

仕上げ	仕上げ	軽切削	軽切削
FP  (11,16)	FM  (08,11,16)	LP  (08,11,16)	LM  (08,11,16)
中切削	中切削	中切削	CBN
MP  (16)	MM  (16)	Standard  (16)	 (11,16)

DMIN	呼び記号	勝手	在庫	DCONMS	LF	LDRED	WF	WF2	H	GAMF	GAMP	対応インサート	
16	C16-12SVUCR08-140-C	R	●	12	140	23	11.5	5.6	11	8°	0°	VC $\circ\circ$	0802 $\circ\circ$
20	C20-16SVUBR11-180-C	R	●	16	180	28	16.0	8.1	15	8°	0°		1103 $\circ\circ$
20	C20-16SVUBL11-180-C	L	●	16	180	28	16.0	8.1	15	8°	0°		1103 $\circ\circ$
25	C25-20SVUBR11-180-C	R	●	20	180	32	18.0	8.1	19	7°	0°		VB $\circ\circ$
30	C30-20SVUBR11-180-C	R	●	20	180	32	18.0	8.1	19	6°	0°	1103 $\circ\circ$	
34	C34-25SVUBR16-180-C	R	●	25	180	38	20.5	8.4	24	13°	0°	1604 $\circ\circ$	

## 付属部品

ボーリングバータイプ	*	
	 クランプねじ	 レンチ
C16-12SVUCR08	TS202	TKY06F
C $\circ\circ$ - $\circ\circ$ SVUBR/L11	TS255	TKY08F
C34-25SVUBR16	TS35D	TKY15F

\* 締付けトルク(N・m) : TS202=0.6, TS255=1.0, TS35D=3.5