


ネガティブインサート(穴つき)

G級精度

TNGA, TNGM

ニューブチカット	ニューブチカット	ニューブチカット
NP_○○6	NP_○○3	BL_
		
		(ブレーカ付)

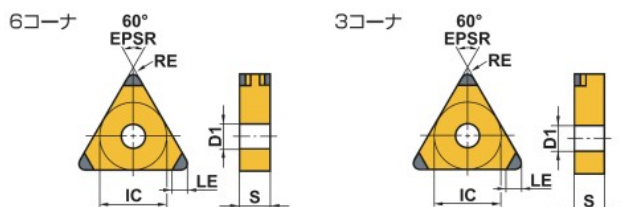

																	(mm)				
呼 び 記 号	コーテッドCBN		CBN		使用コーナ	IC	S	RE	D1	LE	呼 び 記 号	コーテッドCBN		CBN		使用コーナ	IC	S	RE	D1	LE
	BC8210	BC8220	MB8210	NEW MB8220								BC8210	BC8220	MB8210	NEW MB8220						
NP-TNGA160404GA6	●				6	9.525	4.76	0.4	3.81	1.6	NP-TNGA160402FS3	●				3	9.525	4.76	0.2	3.81	1.5
NP-TNGA160408GA6	●				6	9.525	4.76	0.8	3.81	1.7	NP-TNGA160404FS3	●		●		3	9.525	4.76	0.4	3.81	1.6
NP-TNGA160412GA6	●				6	9.525	4.76	1.2	3.81	1.9	NP-TNGA160408FS3	●		●		3	9.525	4.76	0.8	3.81	1.7
NP-TNGA160404GS6	●				6	9.525	4.76	0.4	3.81	1.6	NP-TNGA160412FS3	●		●		3	9.525	4.76	1.2	3.81	1.9
NP-TNGA160408GS6	●				6	9.525	4.76	0.8	3.81	1.7	NP-TNGA160404VA3		●			3	9.525	4.76	0.4	3.81	1.6
NP-TNGA160412GS6	●				6	9.525	4.76	1.2	3.81	1.9	NP-TNGA160408VA3		●			3	9.525	4.76	0.8	3.81	1.7
NP-TNGA160404GH6		●			6	9.525	4.76	0.4	3.81	1.6	NP-TNGA160412VA3		●			3	9.525	4.76	1.2	3.81	1.9
NP-TNGA160408GH6		●			6	9.525	4.76	0.8	3.81	1.7	NP-TNGA160404TA3		●			3	9.525	4.76	0.4	3.81	1.6
NP-TNGA160412GH6		●			6	9.525	4.76	1.2	3.81	1.9	NP-TNGA160408TA3		●			3	9.525	4.76	0.8	3.81	1.7
NP-TNGA160404FS6	●				6	9.525	4.76	0.4	3.81	1.6	NP-TNGA160412TA3		●			3	9.525	4.76	1.2	3.81	1.9
NP-TNGA160408FS6	●				6	9.525	4.76	0.8	3.81	1.7	NP-TNGA160404TS3	●				3	9.525	4.76	0.4	3.81	1.6
NP-TNGA160412FS6	●				6	9.525	4.76	1.2	3.81	1.9	NP-TNGA160408TS3	●				3	9.525	4.76	0.8	3.81	1.7
NP-TNGA160404VA6		●			6	9.525	4.76	0.4	3.81	1.6	NP-TNGA160412TS3	●				3	9.525	4.76	1.2	3.81	1.9
NP-TNGA160408VA6		●			6	9.525	4.76	0.8	3.81	1.7	NP-TNGA160408TH3		●			3	9.525	4.76	0.8	3.81	1.7
NP-TNGA160412VA6		●			6	9.525	4.76	1.2	3.81	1.9	NP-TNGA160412TH3		●			3	9.525	4.76	1.2	3.81	1.9
NP-TNGA160404TA6		●			6	9.525	4.76	0.4	3.81	1.6	BL-TNGM160404TN3		●			3	9.525	4.76	0.4	3.81	1.6
NP-TNGA160408TA6		●			6	9.525	4.76	0.8	3.81	1.7	BL-TNGM160408TN3		●			3	9.525	4.76	0.8	3.81	1.7
NP-TNGA160412TA6		●			6	9.525	4.76	1.2	3.81	1.9	BL-TNGM160412TN3		●			3	9.525	4.76	1.2	3.81	1.9
NP-TNGA160404TS6	●				6	9.525	4.76	0.4	3.81	1.6	● = NEW										
NP-TNGA160408TS6	●				6	9.525	4.76	0.8	3.81	1.7											
NP-TNGA160412TS6	●				6	9.525	4.76	1.2	3.81	1.9											
NP-TNGA160408TH6		●			6	9.525	4.76	0.8	3.81	1.7											
NP-TNGA160412TH6		●			6	9.525	4.76	1.2	3.81	1.9											
NP-TNGA160402GA3		●			3	9.525	4.76	0.2	3.81	1.5											
NP-TNGA160404GA3		●		●	3	9.525	4.76	0.4	3.81	1.6											
NP-TNGA160408GA3		●		●	3	9.525	4.76	0.8	3.81	1.7											
NP-TNGA160412GA3		●		●	3	9.525	4.76	1.2	3.81	1.9											
NP-TNGA160402GS3	●				3	9.525	4.76	0.2	3.81	1.5											
NP-TNGA160404GS3	●				3	9.525	4.76	0.4	3.81	1.6											
NP-TNGA160408GS3	●				3	9.525	4.76	0.8	3.81	1.7											
NP-TNGA160412GS3	●				3	9.525	4.76	1.2	3.81	1.9											
NP-TNGA160404GH3		●			3	9.525	4.76	0.4	3.81	1.6											
NP-TNGA160408GH3		●			3	9.525	4.76	0.8	3.81	1.7											
NP-TNGA160412GH3		●			3	9.525	4.76	1.2	3.81	1.9											

● = NEW