


BC8200/MB8200 シリーズ

ポジティブインサート(穴つき)

G級精度

DCGW, DCGT AN=7°

ニューブチカット	ニューブチカット	ニューブチカット
NP_○○2	BF_, BM_	BL_
		
	(ブレーカ付)	(ブレーカ付)

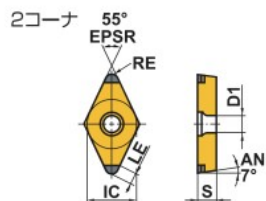

(mm)

呼び記号	コートッドCBN		CBN		使用コーナ	IC	S	RE	D1	LE
	BC8210	BC8220	MB8210	NEW						
				MB8220						
NP-DCGW070202GA2	●				2	6.35	2.38	0.2	2.8	2.2
NP-DCGW070204GA2	●			●	2	6.35	2.38	0.4	2.8	2.1
NP-DCGW070208GA2	●				2	6.35	2.38	0.8	2.8	2.0
NP-DCGW11T302GA2	●				2	9.525	3.97	0.2	4.4	2.2
NP-DCGW11T304GA2	●			●	2	9.525	3.97	0.4	4.4	2.1
NP-DCGW11T308GA2	●			●	2	9.525	3.97	0.8	4.4	2.0
NP-DCGW070202GS2	●				2	6.35	2.38	0.2	2.8	2.2
NP-DCGW070204GS2	●				2	6.35	2.38	0.4	2.8	2.1
NP-DCGW070208GS2	●				2	6.35	2.38	0.8	2.8	2.0
NP-DCGW11T302GS2	●				2	9.525	3.97	0.2	4.4	2.2
NP-DCGW11T304GS2	●				2	9.525	3.97	0.4	4.4	2.1
NP-DCGW11T308GS2	●				2	9.525	3.97	0.8	4.4	2.0
NP-DCGW070202FS2	●			●	2	6.35	2.38	0.2	2.8	2.2
NP-DCGW070204FS2	●			●	2	6.35	2.38	0.4	2.8	2.1
NP-DCGW070208FS2	●			●	2	6.35	2.38	0.8	2.8	2.0
NP-DCGW11T302FS2	●			●	2	9.525	3.97	0.2	4.4	2.2
NP-DCGW11T304FS2	●			●	2	9.525	3.97	0.4	4.4	2.1
NP-DCGW11T308FS2	●			●	2	9.525	3.97	0.8	4.4	2.0
NP-DCGW11T304VA2	●				2	9.525	3.97	0.4	4.4	2.1
NP-DCGW11T308VA2	●				2	9.525	3.97	0.8	4.4	2.0
NP-DCGW11T304TA2	●				2	9.525	3.97	0.4	4.4	2.1
NP-DCGW11T308TA2	●				2	9.525	3.97	0.8	4.4	2.0
BF-DCGT11T304TS2	●				2	9.525	3.97	0.4	4.4	2.1
BF-DCGT11T308TS2	●				2	9.525	3.97	0.8	4.4	2.0
BL-DCGT11T304TN2		●			2	9.525	3.97	0.4	4.4	2.1
BL-DCGT11T308TN2		●			2	9.525	3.97	0.8	4.4	2.0
BM-DCGT11T304TA2	●				2	9.525	3.97	0.4	4.4	2.1
BM-DCGT11T308TA2	●				2	9.525	3.97	0.8	4.4	2.0

● = NEW

● : 標準在庫品

(インサートは、1ケース 1個入りです)