


小物高精度部品内径加工用工具

丸ホルダ

NEW

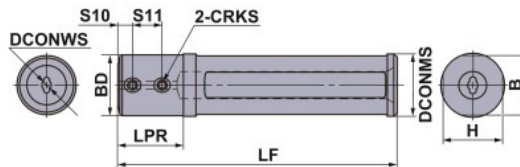

クーラント穴あり

呼 び 記 号	在庫	寸法(mm)								
		DCONMS	DCONWS	BD	LF	LPR	H	B	S10	S11
SLV190085030A	●	19.05	3.0	18.5	85	20	17.8	17.8	4.5	9
SLV190110030A	●	19.05	3.0	18.5	110	20	17.8	17.8	4.5	9
SLV190085035A	●	19.05	3.5	18.5	85	20	17.8	17.8	4.5	9
SLV190110035A	●	19.05	3.5	18.5	110	20	17.8	17.8	4.5	9
SLV190085040A	●	19.05	4.0	18.5	85	20	17.8	17.8	4.5	9
SLV190110040A	●	19.05	4.0	18.5	110	20	17.8	17.8	4.5	9
SLV190085045A	●	19.05	4.5	18.5	85	20	17.8	17.8	4.5	9
SLV190110045A	●	19.05	4.5	18.5	110	20	17.8	17.8	4.5	9
SLV190085050A	●	19.05	5.0	18.5	85	20	17.8	17.8	4.5	9
SLV190110050A	●	19.05	5.0	18.5	110	20	17.8	17.8	4.5	9
SLV190080060A	●	19.05	6.0	18.5	80	20	17.8	17.8	5.0	10
SLV190110060A	●	19.05	6.0	18.5	110	20	17.8	17.8	5.0	10
SLV190080070A	●	19.05	7.0	18.5	80	20	17.8	17.8	5.0	10
SLV190110070A	●	19.05	7.0	18.5	110	20	17.8	17.8	5.0	10
SLV190080080A	●	19.05	8.0	18.5	80	20	17.8	17.8	5.0	10
SLV190110080A	●	19.05	8.0	18.5	110	20	17.8	17.8	5.0	10
SLV200085030A	●	20.0	3.0	19.0	85	20	18.8	18.8	4.5	9
SLV200085035A	●	20.0	3.5	19.0	85	20	18.8	18.8	4.5	9
SLV200085040A	●	20.0	4.0	19.0	85	20	18.8	18.8	4.5	9
SLV200085045A	●	20.0	4.5	19.0	85	20	18.8	18.8	4.5	9
SLV200085050A	●	20.0	5.0	19.0	85	20	18.8	18.8	4.5	9
SLV200080060A	●	20.0	6.0	19.0	80	20	18.8	18.8	5.0	10
SLV200080070A	●	20.0	7.0	19.0	80	20	18.8	18.8	5.0	10
SLV200080080A	●	20.0	8.0	19.0	80	20	18.8	18.8	5.0	10
SLV220115030A	●	22.0	3.0	20.0	115	20	20.8	20.8	4.5	9
SLV220115035A	●	22.0	3.5	20.0	115	20	20.8	20.8	4.5	9
SLV220115040A	●	22.0	4.0	20.0	115	20	20.8	20.8	4.5	9
SLV220115045A	●	22.0	4.5	20.0	115	20	20.8	20.8	4.5	9
SLV220115050A	●	22.0	5.0	20.0	115	20	20.8	20.8	4.5	9
SLV220115060A	●	22.0	6.0	20.0	115	20	20.8	20.8	5.0	10
SLV220115070A	●	22.0	7.0	20.0	115	20	20.8	20.8	5.0	10
SLV220115080A	●	22.0	8.0	20.0	115	20	20.8	20.8	5.0	10
SLV250067030A	●	25.0	3.0	20.0	67	20	23.9	23.9	4.5	9
SLV250110030A	●	25.0	3.0	20.0	110	20	23.9	23.9	4.5	9
SLV250067035A	●	25.0	3.5	20.0	67	20	23.9	23.9	4.5	9
SLV250110035A	●	25.0	3.5	20.0	110	20	23.9	23.9	4.5	9
SLV250067040A	●	25.0	4.0	20.0	67	20	23.9	23.9	4.5	9
SLV250110040A	●	25.0	4.0	20.0	110	20	23.9	23.9	4.5	9
SLV250067045A	●	25.0	4.5	20.0	67	20	23.9	23.9	4.5	9
SLV250110045A	●	25.0	4.5	20.0	110	20	23.9	23.9	4.5	9
SLV250067050A	●	25.0	5.0	20.0	67	20	23.9	23.9	4.5	9
SLV250110050A	●	25.0	5.0	20.0	110	20	23.9	23.9	4.5	9
SLV250067060A	●	25.0	6.0	20.0	67	20	23.9	23.9	5.0	10
SLV250110060A	●	25.0	6.0	20.0	110	20	23.9	23.9	5.0	10
SLV250067070A	●	25.0	7.0	20.0	67	20	23.9	23.9	5.0	10
SLV250110070A	●	25.0	7.0	20.0	110	20	23.9	23.9	5.0	10
SLV250067080A	●	25.0	8.0	20.0	67	20	23.9	23.9	5.0	10
SLV250110080A	●	25.0	8.0	20.0	110	20	23.9	23.9	5.0	10

● = NEW

● : 標準在庫品