


 
旋削用CBNインサート[ネガ]



CBN
B
CBNインサート

ネガ
穴つき

C
D
R
S
T
V
W

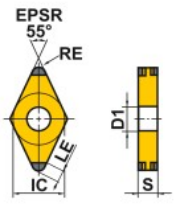

被削材	H 高硬度材	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	切削状態(目安) :																
	K 鋳鉄	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	● : 安定切削 ● : 一般切削 * : 不安定切削			
インサート 外観	S 耐熱合金、チタン合金	コーテッド CBN														CBN					ソリッド CBN	寸法 (mm)					形状													
	焼結合金	NEW	NEW																									IC	S	RE	LE	D1								
ニューブチカット	NP-DNGA150404FS4	●	●	▲	▲				●																		12.7	4.76	0.4	2.1	5.16									
	NP-DNGA150408FS4	●	●	▲	▲				●																			12.7	4.76	0.8	2.0	5.16								
	NP-DNGA150412FS4	●	●	▲	▲				●																			12.7	4.76	1.2	1.8	5.16								
	NP-DNGA150604FS4	●	●	▲					●																			12.7	6.35	0.4	2.1	5.16								
	NP-DNGA150608FS4	●	●	▲					●																			12.7	6.35	0.8	2.0	5.16								
	NP-DNGA150612FS4	●	●	▲					●																			12.7	6.35	1.2	1.8	5.16								
	NP-DNGA150404GS4	●	●	▲																								12.7	4.76	0.4	2.1	5.16								
	NP-DNGA150408GS4	●	●	▲																								12.7	4.76	0.8	2.0	5.16								
	NP-DNGA150412GS4	●	●	▲																								12.7	4.76	1.2	1.8	5.16								
	NP-DNGA150604GS4	●	●	▲																								12.7	6.35	0.4	2.1	5.16								
	NP-DNGA150608GS4	●	●	▲																								12.7	6.35	0.8	2.0	5.16								
	NP-DNGA150612GS4	●	●	▲																								12.7	6.35	1.2	1.8	5.16								
	NP-DNGA150404GA4	●	●		▲	●			●																			12.7	4.76	0.4	2.1	5.16								
	NP-DNGA150408GA4	●	●		▲	●			●																			12.7	4.76	0.8	2.0	5.16								
	NP-DNGA150412GA4	●	●		▲	●			●																			12.7	4.76	1.2	1.8	5.16								
	NP-DNGA150604GA4	●	●		▲	●			●																			12.7	6.35	0.4	2.1	5.16								
	NP-DNGA150608GA4	●	●		▲	●			●																			12.7	6.35	0.8	2.0	5.16								
	NP-DNGA150612GA4	●	●		▲	●			●																			12.7	6.35	1.2	1.8	5.16								
	NP-DNGA150404GH4	●	●		▲	▲	●																					12.7	4.76	0.4	2.1	5.16								
	NP-DNGA150408GH4	●	●		▲	▲	●																					12.7	4.76	0.8	2.0	5.16								
	NP-DNGA150412GH4	●	●		▲	▲	●																					12.7	4.76	1.2	1.8	5.16								
	NP-DNGA150604GH4	●	●		▲	▲	●																					12.7	6.35	0.4	2.1	5.16								
	NP-DNGA150608GH4	●	●		▲	▲	●																					12.7	6.35	0.8	2.0	5.16								
	NP-DNGA150612GH4	●	●		▲	▲	●																					12.7	6.35	1.2	1.8	5.16								
	NEW NP-DNGA150404VA4	●																										12.7	4.76	0.4	2.1	5.16								
	NEW NP-DNGA150408VA4	●																										12.7	4.76	0.8	2.0	5.16								
	NEW NP-DNGA150412VA4	●																										12.7	4.76	1.2	1.8	5.16								
	NEW NP-DNGA150604VA4	●																										12.7	6.35	0.4	2.1	5.16								
	NEW NP-DNGA150608VA4	●																										12.7	6.35	0.8	2.0	5.16								
	NEW NP-DNGA150612VA4	●																										12.7	6.35	1.2	1.8	5.16								
	NP-DNGA150404TS4	●			▲																							12.7	4.76	0.4	2.1	5.16								
	NP-DNGA150408TS4	●			▲																							12.7	4.76	0.8	2.0	5.16								
	NP-DNGA150412TS4	●			▲																							12.7	4.76	1.2	1.8	5.16								
	NP-DNGA150604TS4	●			▲																							12.7	6.35	0.4	2.1	5.16								
NP-DNGA150608TS4	●			▲																							12.7	6.35	0.8	2.0	5.16									
NP-DNGA150612TS4	●			▲																							12.7	6.35	1.2	1.8	5.16									
NP-DNGA150404TA4	●			▲	●			●	●																		12.7	4.76	0.4	2.1	5.16									
NP-DNGA150408TA4	●			▲	●			●	●																		12.7	4.76	0.8	2.0	5.16									
NP-DNGA150412TA4	●			▲	●			●	●																		12.7	4.76	1.2	1.8	5.16									

● = NEW

● : 標準在庫品
▲ : 現在標準在庫品で将来新製品と置き換わる製品
(1ケース1個入りです)

▲ 2023年3月受注終了予定材種 : MB710,MB730
代替材種はB008をご参照ください。