 
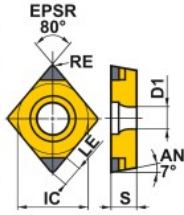

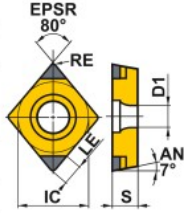

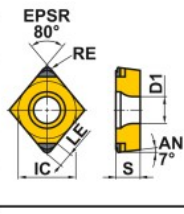

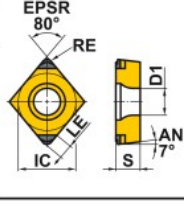

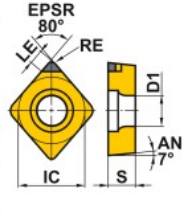


被削材	H	高硬度材	切削状態(目安) :												
	K	鋳鉄	● : 安定切削 ● : 一般切削 ✦ : 不安定切削												
インサート 外観	S	耐熱合金、チタン合金	ホーニング(呼び記号末尾) : B009ページをご参照ください。												
		焼結合金	コーテッド CBN		CBN			寸法 (mm)					形状		
	呼び記号	NEW BC8210 BC8220	BC8105 BC8110 BC8120 BC8130 NEW BC5110	MB8110 MB8120 MB8130 MB4120 MB710 MB730	IC	S	RE	LE	D1						
 ニューブチカット	NP-CCGW060202SE2				●					6.35	2.38	0.2	1.7	2.8	
	NP-CCGW060204SE2				●					6.35	2.38	0.4	1.8	2.8	
	NP-CCGW060208SE2				●					6.35	2.38	0.8	2.0	2.8	
	NP-CCGW09T302SE2				●					9.525	3.97	0.2	1.7	4.4	
	NP-CCGW09T304SE2				●					9.525	3.97	0.4	1.8	4.4	
 ニューブチカット (ワイパー) *1	NP-CCGW09T304FWS2	●	● ▲ ▲	●						9.525	3.97	0.4	1.8	4.4	
	NP-CCGW09T308FWS2	●	● ▲ ▲	●						9.525	3.97	0.8	2.0	4.4	
	NP-CCGW09T304FBWL2		● ▲ ▲	●						9.525	3.97	0.4	1.8	4.4	
	NP-CCGW09T308FBWL2		● ▲ ▲	●						9.525	3.97	0.8	2.0	4.4	
	NP-CCGW09T304GSWS2	●	● ▲							9.525	3.97	0.4	1.8	4.4	
	NP-CCGW09T308GSWS2	●	● ▲							9.525	3.97	0.8	2.0	4.4	
	NP-CCGW09T304GAWS2	●	▲ ●	●						9.525	3.97	0.4	1.8	4.4	
	NP-CCGW09T308GAWS2	●	▲ ●	●						9.525	3.97	0.8	2.0	4.4	
	NP-CCGW09T304GBWL2		● ▲ ▲	●						9.525	3.97	0.4	1.8	4.4	
 ニューブチカット (プレーカ付)	BF-CCGT09T304TS2	●	▲							9.525	3.97	0.4	1.8	4.4	
	BF-CCGT09T308TS2	●	▲							9.525	3.97	0.8	2.0	4.4	
 ニューブチカット (プレーカ付)	BM-CCGT09T304TA2	●	▲							9.525	3.97	0.4	1.8	4.4	
	BM-CCGT09T308TA2	●	▲							9.525	3.97	0.8	2.0	4.4	
 ニューブチカット	*2 NP-CCGW03S102FS	●	▲	●						3.57	1.39	0.2	1.1	2.0	
	*2 NP-CCGW03S104FS	●	▲	●						3.57	1.39	0.4	1.0	2.0	
	*2 NP-CCGW04T002FS	●	▲	●						4.37	1.79	0.2	1.5	2.4	
	*2 NP-CCGW04T004FS	●	▲	●						4.37	1.79	0.4	1.4	2.4	
	*2 NP-CCGW03S102GS		●							3.57	1.39	0.2	1.1	2.0	
	*2 NP-CCGW03S104GS		●							3.57	1.39	0.4	1.0	2.0	
	*2 NP-CCGW04T002GS		●							4.37	1.79	0.2	1.5	2.4	
	*2 NP-CCGW04T004GS		●							4.37	1.79	0.4	1.4	2.4	
	NP-CCGW09T302GS							▲ ▲		9.525	3.97	0.2	1.7	4.4	
	NP-CCGW09T304GS							▲ ▲		9.525	3.97	0.4	1.8	4.4	

*1 ワイパーインサートは、B012ページを参照の上、ご使用ください。

*2 内径円がISO規格に準拠しておりません。(スティックバー-SCLC形専用)

● = NEW