

旋削用CBNインサート[ポジ]



CBN

B

CBNインサート

ポジ
7°

穴つき

C

D

R


S

T

V

W

被削材	H	高硬度材										切削状態(目安):						
	K	鋳鉄										●: 安定切削 ●: 一般切削 ✦: 不安定切削						
インサート 外観	S	耐熱合金、チタン合金										ホーニング(呼び記号末尾): B009ページをご参照ください。						
		焼結合金																
呼び記号	コーテッド CBN					CBN					寸法 (mm)					形状		
	NEW BC8210	BC8220	BC8105	BC8110	BC8120	BC8130	NEW BC5110	MB8110	MB8120	MB8130	MB4120	MB710	MB730	IC	S		RE	LE
ニューブチカット	NP-DCGW070202FS2	●		▲				●						6.35	2.38	0.2	2.2	2.8
	NP-DCGW070204FS2	●		▲▲			●			●				6.35	2.38	0.4	2.1	2.8
	NP-DCGW070208FS2	●		▲			●			●				6.35	2.38	0.8	2.0	2.8
	NP-DCGW11T302FS2	●		●▲			●			●				9.525	3.97	0.2	2.2	4.4
	NP-DCGW11T304FS2	●		●▲▲			●			●				9.525	3.97	0.4	2.1	4.4
	NP-DCGW11T308FS2	●		●▲▲			●			●				9.525	3.97	0.8	2.0	4.4
	NP-DCGW11T304FA2									▲▲				9.525	3.97	0.4	1.5	4.4
	NP-DCGW11T308FA2									▲▲				9.525	3.97	0.8	1.7	4.4
	NP-DCGW070202GS2	●		●▲										6.35	2.38	0.2	2.2	2.8
	NP-DCGW070204GS2	●		●▲			●							6.35	2.38	0.4	2.1	2.8
	NP-DCGW070208GS2	●		●▲						●				6.35	2.38	0.8	2.0	2.8
	NP-DCGW11T302GS2	●		●▲						●				9.525	3.97	0.2	2.2	4.4
	NP-DCGW11T304GS2	●		●▲			●			●▲▲				9.525	3.97	0.4	2.1	4.4
	NP-DCGW11T308GS2	●		●▲			●			●▲▲				9.525	3.97	0.8	2.0	4.4
	NP-DCGW070202GA2	●		▲			●							6.35	2.38	0.2	2.2	2.8
	NP-DCGW070204GA2	●		▲●			●							6.35	2.38	0.4	2.1	2.8
	NP-DCGW070208GA2	●		●										6.35	2.38	0.8	2.0	2.8
	NP-DCGW11T302GA2	●		▲			●							9.525	3.97	0.2	2.2	4.4
	NP-DCGW11T304GA2	●		▲●			●							9.525	3.97	0.4	2.1	4.4
	NP-DCGW11T308GA2	●		▲●			●							9.525	3.97	0.8	2.0	4.4
	NP-DCGW11T304GH2			▲▲●										9.525	3.97	0.4	2.1	4.4
	NP-DCGW11T308GH2			▲▲●										9.525	3.97	0.8	2.0	4.4
	NEW NP-DCGW11T304VA2	●												9.525	3.97	0.4	2.1	4.4
	NEW NP-DCGW11T308VA2	●												9.525	3.97	0.8	2.0	4.4
	NP-DCGW070204TA2			▲●			●●							6.35	2.38	0.4	2.1	2.8
	NP-DCGW070208TA2			●			●							6.35	2.38	0.8	2.0	2.8
	NP-DCGW11T304TA2	●		▲●			●●							9.525	3.97	0.4	2.1	4.4
	NP-DCGW11T308TA2	●		▲●			●●							9.525	3.97	0.8	2.0	4.4
	NP-DCGW11T304TH2			▲●			●							9.525	3.97	0.4	2.1	4.4
	NP-DCGW11T308TH2			▲●			●							9.525	3.97	0.8	2.0	4.4
	NP-DCGW070204SF2									●				6.35	2.38	0.4	2.1	2.8
	NP-DCGW070208SF2									●				6.35	2.38	0.8	2.0	2.8
	NP-DCGW11T302SF2									●				9.525	3.97	0.2	2.2	4.4
	NP-DCGW11T304SF2									●				9.525	3.97	0.4	2.1	4.4
	NP-DCGW11T308SF2									●				9.525	3.97	0.8	2.0	4.4
	NP-DCGW070204SE2									●				6.35	2.38	0.4	2.1	2.8
	NP-DCGW070208SE2									●				6.35	2.38	0.8	2.0	2.8
	NP-DCGW11T302SE2									●				9.525	3.97	0.2	2.2	4.4
	NP-DCGW11T304SE2									●				9.525	3.97	0.4	2.1	4.4
	NP-DCGW11T308SE2									●				9.525	3.97	0.8	2.0	4.4

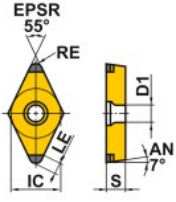

● = NEW

●: 標準在庫品 □: 受注生産品
 ▲: 現在標準在庫品で将来新製品と置き換わる製品
 □: 受注生産品をお求めになる場合、最低ロット数は10個となります(1ケース1個入りです)

▲ 2023年3月受注終了予定材種: MB710, MB730
 代替材種はB008をご参照ください。